


Product data sheet

Specifications

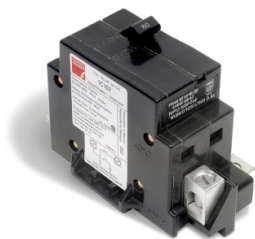

STAB-LOK CIRCUIT BREAKER 120/240V 40A 2P MAIN BREAKER

1C40

⚠ Discontinued on: Jan 26, 2021

⚠ Discontinued

Main

Range Of Product	Stab-lok
Product Or Component Type	Miniature circuit-breaker
[In] Rated Current	40 A
[Ue] Rated Operational Voltage	120/240 V AC
Poles Description	2P
Breaking Capacity	10 kA

Complementary

Mounting Mode	Plug-in
Electrical Connection	Screw terminal
Awg Gauge	AWG 4...AWG 2/0 aluminum/copper

Environment

Product Certifications	CSA
------------------------	-----

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	4.00 in (10.16 cm)
Package 1 Width	4.30 in (10.922 cm)
Package 1 Length	5.50 in (13.97 cm)
Package 1 Weight	19.52 oz (553.383 g)

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Sustainability





Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)

Well-being performance

	Reach Free Of Svhc	
	Toxic Heavy Metal Free	
	Mercury Free	
	Rohs Exemption Information	Yes
<hr/>		
Eu Rohs Directive		Compliant
		EU RoHS Declaration
<hr/>		
China Rohs Regulation		China RoHS declaration
<hr/>		