

Product data sheet

Specifications



Harmony XVC, Monolithic precabled tower light, plastic, red orange, Ø40, tube mounting, steady or flashing, buzzer, IP23, 24 V AC/DC

XVC4B25S

Main

Range Of Product	Harmony XVC4
Product Or Component Type	Complete pre-wired monolithic tower light
Beacon Or Indicator Bank Unit Type	2 illuminated units
Sound Signalling	Buzzer
Mounting Diameter	1.57 in (40 mm)
Component Name	XVC
Device Short Name	XVC
Light Source	LED steady or flashing red LED steady or flashing orange
Supply Circuit Type	AC/DC
Noise Level	70...85 dB continuous or intermittent tone)1 m

Complementary

Material	Polycarbonate: illuminated unit ABS (acrylonitrile butadiene-styrene): base unit PBT + ABS (UL94HB): top cover SGP (chromium-plated): support tube
Mounting Location	On support tube, 17 mm
Product Mounting	On support tube, 17 mm
[Us] Rated Supply Voltage	24 V
[Us] Rated Supply Voltage	24 V
Cable Cross Section	0.00 in² (0.33 mm²)
Awg Gauge	AWG 22
Cable Length	35.43 in (900 mm)
Marking	CE
[Uimp] Rated Impulse Withstand Voltage	0.8 kV
Current Consumption	90 mA
Fundamental Frequency	2.23 kHz
Flashing Frequency	1 Hz
Net Weight	1.37 lb(US) (0.62 kg)
Height	22.03 in (559.5 mm)

Environment

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Standards	EN/IEC 61000-6-2 EN/IEC 61000-6-3
Product Certifications	UL
Protective Treatment	TC
Ambient Air Temperature For Storage	-31...158 °F (-35...70 °C)
Ambient Air Temperature For Operation	14...122 °F (-10...50 °C)
Electrical Shock Protection Class	Class I EN/IEC 61140
Overvoltage Category	Class I EN/IEC 61140
Ip Degree Of Protection	IP23 vertical surface installation EN/IEC 60529

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2.60 in (6.600 cm)
Package 1 Width	2.60 in (6.600 cm)
Package 1 Length	29.53 in (75.000 cm)
Package 1 Weight	29.98 oz (850.000 g)
Unit Type Of Package 2	P06
Number Of Units In Package 2	10
Package 2 Height	17.72 in (45.000 cm)
Package 2 Width	23.62 in (60.000 cm)
Package 2 Length	31.50 in (80.000 cm)
Package 2 Weight	37.48 lb(US) (17.000 kg)

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency

Well-being performance


✓	Mercury Free	
✓	Rohs Exemption Information	Yes
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope)	
China Rohs Regulation	China RoHS declaration	
Environmental Disclosure	Product Environmental Profile	
Circularity Profile	End of Life Information	

Dimensions Drawings

Pre-assembled and Pre-wired Tower Light with Support Tube Mounting

Dimensions

Below drawing shows the maximum configuration of the product. Select the number of stages according to the product characteristics in order to get **b1** dimension.

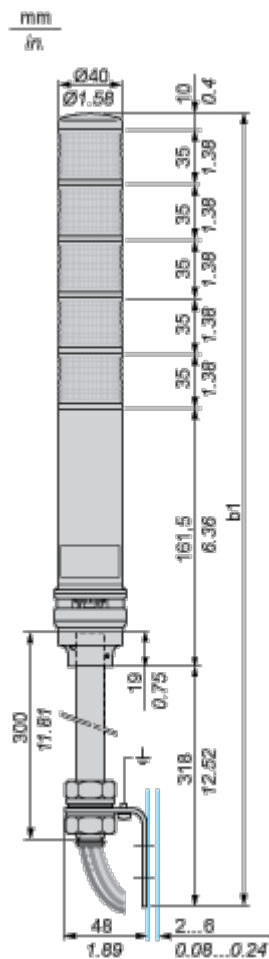

No. of illuminated units	b1 With buzzer (mm)	b1 With buzzer (in.)
1 stage	524.50	20.65
2 stages	559.50	22.03
3 stages	594.50	23.41
4 stages	629.50	24.78
5 stages	664.50	26.16

Mounting and Clearance

Pre-assembled and Pre-wired Tower Light

Support Tube Mounting

