


Product datasheet

Specifications

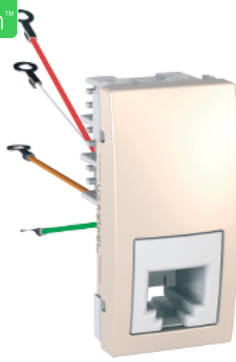

Unica - 1 telephone socket - RJ11 - ivory

MGU3.490.25

Main

Range	Unica
Aesthetic name	Unica (standard aesthetic)
Product or component type	Telephone socket
Device presentation	Mechanism
Colour tint	Ivory
Telephone socket type	RJ11 (4 contacts) - category 3 at 16 Mbit/s

Complementary

Socket number	1
Number of modules	1 module
Connections - terminals	Screw terminals twisted pair
Fixing mode	Clip-in
Material	ASA + PC: mechanism cover
Depth	23 mm
Width	22.5 mm
Height	45 mm
Embedding depth	12 mm
Net weight	0.013 kg
Ambient air temperature for operation	15...30 °C
Ambient air temperature for storage	0...35 °C

Environment

IP degree of protection	IP20
IK degree of protection	IK01
Environmental characteristic	Bleach Alcohol Liquid soap Petrol Window-cleaning fluid Acetone Oil UV resistant

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	16 g
Package 1 Height	6.7 cm
Package 1 width	4.4 cm
Package 1 Length	6.8 cm
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Weight	226 g
Package 2 Height	4.8 cm
Package 2 width	13.6 cm
Package 2 Length	33.5 cm
Unit Type of Package 3	S03
Number of Units in Package 3	120
Package 3 Weight	3.199 kg
Package 3 Height	30 cm
Package 3 width	30 cm
Package 3 Length	40 cm

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins

Contractual warranty

Warranty	18 months
----------	-----------