


Product datasheet

Specifications

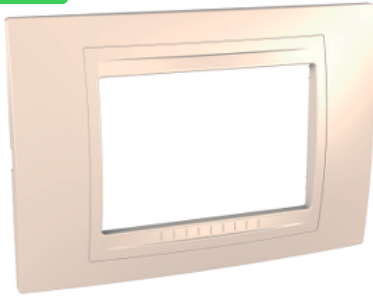

Unica Allegro - cover frame - 3 modules - cream

MGU4.103.59

Main

Range	Unica
Device application	Mounting
Product or component type	Cover frame
Aesthetic name	Unica Allegro
Number of modules	3 modules
Fixing mode	Clip-in
Cover frame colour tint	Cream

Complementary

Material	ABS (acrylonitrile butadiene-styrene): cover frame
Standards	EN 60669-1
Height	80 mm
Width	116 mm
Depth	14 mm
Net weight	0.019 kg
Market segment	Residential Small commercial

Environment

IK degree of protection	IK01
IP degree of protection	IP20
Environmental characteristic	Petrol Oil Acetone Window-cleaning fluid Alcohol Liquid soap UV resistant Bleach

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	18.0 g

Package 1 Height	0.9 cm
Package 1 width	0.7 cm
Package 1 Length	3.1 cm
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Weight	210.0 g
Package 2 Height	7 cm
Package 2 width	9 cm
Package 2 Length	31 cm
Unit Type of Package 3	S02
Number of Units in Package 3	30
Package 3 Weight	1.085 kg
Package 3 Height	15 cm
Package 3 width	30 cm
Package 3 Length	40 cm

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------