


Product datasheet

Specifications

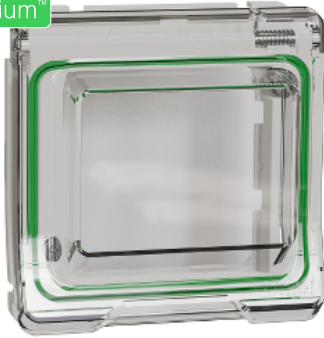

Mureva Styl - box cover with lid for Unica - white

MUR39106

Main

Range of product	Mureva Styl
Product or component type	Box cover
Range compatibility	fixing adaptor
Colour tint	White (RAL 9003)

Complementary

Device mounting	Flush Surface
Cover type	Lid
Condition of use	Indoor/outdoor
Material	PP (polypropylene) PC (polycarbonate)
Length	71 mm
Height	29 mm
Width	71 mm
Chemical and detergent products resistance	Resistant to alcohol (70 %) Resistant to alcohol (96 %) Resistant to A-Lactic Acid Resistant to diluted quaternary ammonium Resistant to diluted bleach Resistant to diluted ammonia Resistant to soapy water Resistant to crystal cleaner Resistant to hydrogen peroxide 10 volumes Resistant to hexane

Environment

IP degree of protection	IP55
IK degree of protection	IK06
Flame retardance	Self-extinguishing 650 °C conforming to IEC 60695-2-1
Ambient air temperature for operation	-5...40 °C
Ambient air temperature for storage	-25...55 °C

Packing Units

Unit Type of Package 1	PCE
------------------------	-----

Number of Units in Package 1	1
Package 1 Weight	35 g
Package 1 Height	3 cm
Package 1 width	7.5 cm
Package 1 Length	7.5 cm
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Weight	442 g
Package 2 Height	16 cm
Package 2 width	8 cm
Package 2 Length	40 cm
Unit Type of Package 3	S04
Number of Units in Package 3	60
Package 3 Weight	3.48 kg
Package 3 Height	30 cm
Package 3 width	40 cm
Package 3 Length	60 cm

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile