


Product datasheet

Specifications

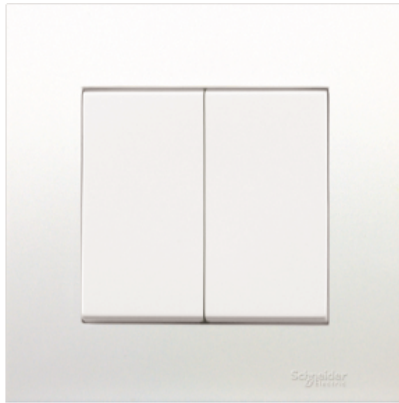

Vivace 10A 250V 2 Gang Bell Press Switch white

KB32BP_WE

Main

Range	Vivace
Product or component type	Bell press switch
Device short name	KB32
Device application	Control
Device presentation	Complete mechanism

Complementary

Switch function	1-way
Actuator	Push-button
Number of gangs	2 gangs
Colour tint	White
Material	Polycarbonate: grid plate Polycarbonate: surround Nylon: base
Projecting depth	8 mm
Device mounting	Flush
Mounting support	Wall mounted
Fixing mode	By screw M3.5
Fixing center	60.3 mm
Embedding depth	35 mm
Rated current	10 A at 250 V AC, inductive
[Ue] rated operational voltage	250 V AC
Network frequency	50 Hz
Contacts material	Brass and phosphor bronze
Connections - terminals	pillar terminal
Terminal identifier	COM L2
Tightening torque	0.4 N.m
Clamping connection capacity	<= 1.5 mm ²
Width	86 mm
Height	86 mm

Environment

Standards	MS IEC 60669-1 IEC 60669-1 SS 227
-----------	---

Ambient air temperature for operation	-5...40 °C
---------------------------------------	------------

Relative humidity	0...95 %
-------------------	----------

Environmental characteristic	Indoor use
------------------------------	------------

Packing Units

Unit Type of Package 1	PCE
------------------------	-----

Number of Units in Package 1	1
------------------------------	---

Package 1 Height	3.2 cm
------------------	--------

Package 1 Width	8.6 cm
-----------------	--------

Package 1 Length	8.6 cm
------------------	--------

Package 1 Weight	93.75 g
------------------	---------

Unit Type of Package 2	BB1
------------------------	-----

Number of Units in Package 2	8
------------------------------	---

Package 2 Height	15 cm
------------------	-------

Package 2 Width	19 cm
-----------------	-------

Package 2 Length	8 cm
------------------	------

Package 2 Weight	750 g
------------------	-------

Unit Type of Package 3	CAR
------------------------	-----

Number of Units in Package 3	80
------------------------------	----

Package 3 Height	21 cm
------------------	-------

Package 3 Width	31.5 cm
-----------------	---------

Package 3 Length	50 cm
------------------	-------

Package 3 Weight	7500 g
------------------	--------

Offer Sustainability

REACH Regulation	REACH Declaration
------------------	-----------------------------------

EU RoHS Directive	Compliant EU RoHS Declaration
-------------------	--

Mercury free	Yes
--------------	-----

RoHS exemption information	Yes
----------------------------	---------------------

China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information
-----------------------	---

Contractual warranty

Warranty	18 months
----------	-----------

Recommended replacement(s)