


# Product datasheet

Specifications

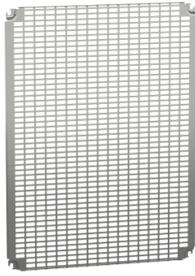

## Monobloc perforated plates H800xW600mm with universal perforations 11x26mm

NSYMR86

### Overview

Lead Time Usually Ships within 4 Weeks

### Main

Range	Spacial
Accessory / Separate Part Category	Mounting accessory
Product Or Component Type	Mounting plate
Device Application	Multi-purpose
Enclosure Nominal Dimensions	- H: 800 mm W: 600 mm - H: 800 mm W: 1200 mm
Mounting Location	Step slide Direct fixing on backstuds
Mounting Plate Description	Telequick perforated
Range Compatibility	Spacial Spacial S3D Spacial Spacial CRN Spacial Spacial S3X
Quantity Per Set	Set of 1
Material	Steel
Surface Finish	Zinc coated

### Complementary

Fixing Mode	Screwed on backstuds - screw type M8 By fixing element
Height	750 mm
Width	551 mm
Depth	15 mm
Thickness	2 mm
Net Weight	3.16 kg
Number Of Slots	867
Variant Particularity	With enclosures H800 x W1200 Installation in rear of enclosure
Cut-Out Dimensions	11 x 26 mm

### Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1

<b>Package 1 Height</b>	2.0 cm
<b>Package 1 Width</b>	55.5 cm
<b>Package 1 Length</b>	75.5 cm
<b>Package 1 Weight</b>	3.18 kg
<b>Unit Type Of Package 2</b>	PAM
<b>Number Of Units In Package 2</b>	126
<b>Package 2 Height</b>	90.0 cm
<b>Package 2 Width</b>	100.0 cm
<b>Package 2 Length</b>	120.0 cm
<b>Package 2 Weight</b>	429.0 kg

## Contractual warranty

<b>Warranty</b>	18 months
-----------------	-----------

## Sustainability

**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

## Well-being performance

✓ Reach Free Of Svhc

---

✓ Toxic Heavy Metal Free

---

✓ Mercury Free

---

✓ Rohs Exemption Information Yes

---

## Certifications & Standards

**Reach Regulation**

[REACH Declaration](#)

---

**Eu Rohs Directive**

Pro-active compliance (Product out of EU RoHS legal scope)

[EU RoHS Declaration](#)

---

**China Rohs Regulation**

[China RoHS declaration](#)

Pro-active China RoHS declaration (out of China RoHS legal scope)

---

**Environmental Disclosure**

[Product Environmental Profile](#)

---

**Circularity Profile**

No need of specific recycling operations

---