


Product datasheet

Specifications

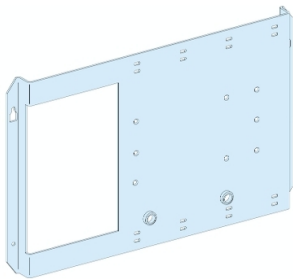

MOUNTING PLATE NSX/CVS/INS 630 HZ. FIX. TOGGLE

03070

Discontinued on: Jun 15, 2023

Discontinued

Main

Range	Prisma
Range Of Product	Prisma G
Product Or Component Type	Mounting plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma G enclosure
Installation Description	Floor-standing enclosure - width 850 mm Floor-standing enclosure + duct - width 600 + 300 mm Wall-mounted enclosure + duct - width 600 + 300 mm
Installed Device	EasyPact: fixed CVS400 without earth leakage protection - control: toggle - horizontal installation EasyPact: fixed CVS630 without earth leakage protection - control: toggle - horizontal installation EasyPact: fixed Ezc400 - control: toggle - horizontal installation EasyPact: fixed Ezc630 - control: toggle - horizontal installation ComPact: fixed INS320...400 - control: direct front rotary handle - horizontal installation ComPact: fixed INS500...630 - control: direct front rotary handle - horizontal installation ComPact: fixed INV320...400 - control: direct front rotary handle - horizontal installation ComPact: fixed INV500...630 - control: direct front rotary handle - horizontal installation ComPact: fixed NSX400 without earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX630 without earth leakage protection - control: toggle - horizontal installation
Poles Description	1 x 3P: fixed CVS400 horizontal installation 1 x 4P: fixed CVS400 horizontal installation 1 x 3P: fixed CVS630 horizontal installation 1 x 4P: fixed CVS630 horizontal installation 1 x 3P: fixed Ezc400 horizontal installation 1 x 4P: fixed Ezc400 horizontal installation 1 x 3P: fixed Ezc630 horizontal installation 1 x 4P: fixed Ezc630 horizontal installation 1 x 3P: fixed INS320...400 horizontal installation 1 x 4P: fixed INS320...400 horizontal installation 1 x 3P: fixed INS500...630 horizontal installation 1 x 4P: fixed INS500...630 horizontal installation 1 x 3P: fixed INV320...400 horizontal installation 1 x 4P: fixed INV320...400 horizontal installation 1 x 3P: fixed INV500...630 horizontal installation 1 x 4P: fixed INV500...630 horizontal installation 1 x 3P: fixed NSX400 horizontal installation 1 x 4P: fixed NSX400 horizontal installation 1 x 3P: fixed NSX630 horizontal installation 1 x 4P: fixed NSX630 horizontal installation
Condition Of Using Cable Tie	Need additional plate (2M high) when installation of device is in horizontal

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Number Of Vertical Modules [50 Mm]

[illegible]

Standards	IEC 61439-2
Product Certifications	ASEFA

Complementary

Cable Entry	Cut-out plates 0.38 mm top 217 mm Cut-out plates 0.32 mm bottom 67 mm
Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Surface Finish	Smooth Matt
Colour	White (RAL 9001)
Width	600 mm
Height	250 mm
Net Weight	2.24 kg

6 Life Is On | **Schneider** Electric Apr 19, 2024

600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontal 3P 1 connection block 6 0.32 mm
600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX630 without fixed toggle horizontal 3P 1 connection block 6 0.32 mm
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontal 4P 1 connection block 6 0.32 mm
600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX630 without fixed toggle horizontal 4P 1 connection block 6 0.32 mm
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontal 3P 1 direct with long terminal shield 9 0.38 mm
600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX630 without fixed toggle horizontal 3P 1 direct with long terminal shield 9 0.38 mm
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontal 4P 1 direct with long terminal shield 9 0.38 mm
600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX630 without fixed toggle horizontal 4P 1 direct with long terminal shield 9 0.38 mm
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontal 3P 1 direct with long terminal shield 6 0.32 mm
600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX630 without fixed toggle horizontal 3P 1 direct with long terminal shield 6 0.32 mm
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontal 4P 1 direct with long terminal shield 6 0.32 mm
600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX630 without fixed toggle horizontal 4P 1 direct with long terminal shield 6 0.32 mm
850 mm Prisma G floor-standing enclosure ComPact NSX630 without fixed toggle horizontal 3P 1 direct with long terminal shield 9 0.38 mm
850 mm Prisma G floor-standing enclosure ComPact NSX630 without fixed toggle horizontal 4P 1 direct with long terminal shield 9 0.38 mm
850 mm Prisma G floor-standing enclosure ComPact NSX630 without fixed toggle horizontal 3P 1 direct with long terminal shield 6 0.32 mm
850 mm Prisma G floor-standing enclosure ComPact NSX630 without fixed toggle horizontal 4P 1 direct with long terminal shield 6 0.32 mm

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2.900 cm
Package 1 Width	29.000 cm
Package 1 Length	47.000 cm
Package 1 Weight	2.300 kg
Unit Type Of Package 2	S04
Number Of Units In Package 2	8
Package 2 Height	30.000 cm
Package 2 Width	40.000 cm
Package 2 Length	60.000 cm
Package 2 Weight	19.050 kg
Unit Type Of Package 3	P12
Number Of Units In Package 3	96
Package 3 Height	105.000 cm
Package 3 Width	80.000 cm
Package 3 Length	120.000 cm
Package 3 Weight	225.840 kg

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes
✓	Halogen Free Plastic Parts Product	

Certifications & Standards

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile