


Product datasheet

Specifications



40mm Tower ROG Pole

XVC4B3

 **Discontinued on:** Aug 27, 2020

Price: 2,272,600.00 IDR

 **Discontinued**

Main

| | |
|------------------------------------|---|
| Range Of Product | Harmony XVC4 |
| Product Or Component Type | Complete pre-wired monolithic tower light |
| Beacon Or Indicator Bank Unit Type | 3 illuminated units |
| Sound Signalling | Without |
| Mounting Diameter | 40 mm |
| Component Name | XVC |
| Device Short Name | XVC |
| Light Source | LED steady red LED steady orange LED steady green |
| Supply Circuit Type | AC/DC |

Complementary

| | |
|--|---|
| Material | Polycarbonate: illuminated unit ABS (acrylonitrile butadiene-styrene): base unit PBT + ABS (UL94HB): top cover SGP (chromium-plated): support tube |
| Mounting Location | On support tube, 17 mm |
| Product Mounting | On support tube, 17 mm |
| [Us] Rated Supply Voltage | 24 V |
| [Us] Rated Supply Voltage | 24 V |
| Cable Cross Section | 0.33 mm ² |
| Awg Gauge | AWG 22 |
| Cable Length | 600 mm |
| Marking | CE |
| [Uimp] Rated Impulse Withstand Voltage | 0.8 kV |
| Current Consumption | 75 mA |
| Flashing Frequency | 1 Hz |
| Net Weight | 0.54 kg |
| Height | 473.5 mm |

Environment

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

| | |
|---------------------------------------|---|
| Standards | EN/IEC 61000-6-3 EN/IEC 61000-6-2 |
| Product Certifications | UL |
| Protective Treatment | TC |
| Ambient Air Temperature For Storage | -35...70 °C |
| Ambient Air Temperature For Operation | -10...50 °C |
| Electrical Shock Protection Class | Class I conforming to EN/IEC 61140 |
| Overvoltage Category | Class I conforming to EN/IEC 61140 |
| Ip Degree Of Protection | IP23 vertical surface installation conforming to EN/IEC 60529 |

Packing Units

| | |
|------------------------------|-----------|
| Unit Type Of Package 1 | PCE |
| Number Of Units In Package 1 | 1 |
| Package 1 Height | 6.800 cm |
| Package 1 Width | 6.800 cm |
| Package 1 Length | 75.200 cm |
| Package 1 Weight | 758.000 g |
| Unit Type Of Package 2 | BB1 |
| Number Of Units In Package 2 | 10 |
| Package 2 Height | 17.500 cm |
| Package 2 Width | 37.000 cm |
| Package 2 Length | 77.500 cm |
| Package 2 Weight | 8.684 kg |
| Unit Type Of Package 3 | P06 |
| Number Of Units In Package 3 | 20 |
| Package 3 Height | 75.000 cm |
| Package 3 Width | 60.000 cm |
| Package 3 Length | 80.000 cm |
| Package 3 Weight | 25.368 kg |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency

Well-being performance



Mercury Free



Rohs Exemption Information

[Yes](#)

Eu Rohs Directive

Pro-active compliance (Product out of EU RoHS legal scope)

China Rohs Regulation

[China RoHS declaration](#)

Environmental Disclosure

[Product Environmental Profile](#)

Circularity Profile


[End of Life Information](#)

Dimensions Drawings

Pre-assembled and Pre-wired Tower Light with Support Tube Mounting

Dimensions

Below drawing shows the maximum configuration of the product. Select the number of stages according to the product characteristics in order to get **b** dimension.

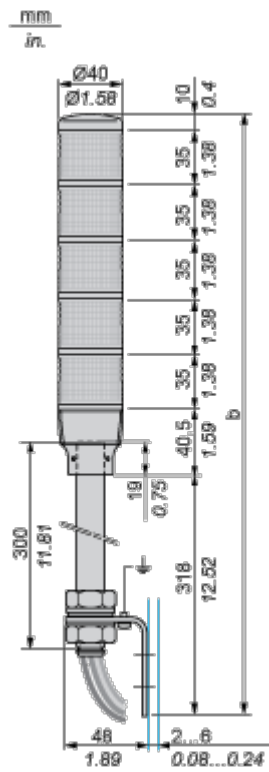

| No. of illuminated units | b Without buzzer (mm) | b Without buzzer (in.) |
|--------------------------|-----------------------|------------------------|
| 1 stage | 403.50 | 15.89 |
| 2 stages | 438.50 | 17.26 |
| 3 stages | 473.50 | 18.64 |
| 4 stages | 508.50 | 20.02 |
| 5 stages | 543.50 | 21.40 |

Mounting and Clearance

Pre-assembled and Pre-wired Tower Light

Support Tube Mounting

