


Lembar data produk

Spesifikasi

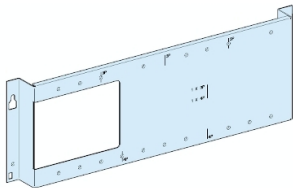

MOUNTING PLATE NSX/CVS/ VIGI 250 V. FIX.ROT.HANDLE

03041

⚠ Telah dihentikan pada: 15 Jun 2023

⚠ Dihentikan

Main

Range	Prisma
Range Of Product	Prisma G
Product Or Component Type	Mounting plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma G enclosure
Installation Description	Floor-standing enclosure - width 600 mm Wall-mounted enclosure - width 600 mm
Installed Device	EasyPact: fixed CVS100...160 without earth leakage protection - control: direct front rotary handle - vertical installation EasyPact: fixed CVS250 without earth leakage protection - control: direct front rotary handle - vertical installation ComPact: fixed NSX100...160 without earth leakage protection - control: direct front rotary handle - vertical installation ComPact: fixed NSX250 without earth leakage protection - control: direct front rotary handle - vertical installation EasyPact: fixed CVS100...160 with earth leakage protection - control: direct front rotary handle - vertical installation EasyPact: fixed CVS250 with earth leakage protection - control: direct front rotary handle - vertical installation ComPact: fixed NSX100...160 with earth leakage protection - control: direct front rotary handle - vertical installation ComPact: fixed NSX250 with earth leakage protection - control: direct front rotary handle - vertical installation
Poles Description	4 x 3P: fixed CVS100...160 vertical installation 3 x 4P: fixed CVS100...160 vertical installation 4 x 3P: fixed CVS250 vertical installation 3 x 4P: fixed CVS250 vertical installation 4 x 3P: fixed NSX100...160 vertical installation 3 x 4P: fixed NSX100...160 vertical installation 4 x 3P: fixed NSX250 vertical installation 3 x 4P: fixed NSX250 vertical installation
Condition Of Using Cable Tie	Need additional plate (1M high) when installation of device is in vertical

Disklaimer: Dokumentasi ini tidak ditujukan sebagai pengganti dan tidak untuk digunakan untuk menentukan kesesuaian atau keandalan produk ini untuk aplikasi pengguna

Number Of Vertical Modules [50 Mm]	9 module(s): CVS100...160 without earth leakage protection , direct with long terminal shield in 600 mm Widefloor-standing enclosure (cable coming from top or bottom of enclosure)
	9 module(s): CVS100...160 without earth leakage protection , direct with long terminal shield in 600 mm Widewall-mounted enclosure (cable coming from top or bottom of enclosure)
	11 module(s): CVS250 without earth leakage protection , direct with long terminal shield in 600 mm Widefloor-standing enclosure (cable coming from top or bottom of enclosure)
	11 module(s): CVS250 without earth leakage protection , direct with long terminal shield in 600 mm Widewall-mounted enclosure (cable coming from top or bottom of enclosure)
	9 module(s): NSX100...160 without earth leakage protection , direct with long terminal shield in 600 mm Widefloor-standing enclosure (cable coming from top or bottom of enclosure)
	9 module(s): NSX100...160 without earth leakage protection , direct with long terminal shield in 600 mm Widewall-mounted enclosure (cable coming from top or bottom of enclosure)
	11 module(s): NSX250 without earth leakage protection , direct with long terminal shield in 600 mm Widefloor-standing enclosure (cable coming from top or bottom of enclosure)
	11 module(s): NSX250 without earth leakage protection , direct with long terminal shield in 600 mm Widewall-mounted enclosure (cable coming from top or bottom of enclosure)
	10 module(s): CVS100...160 with earth leakage protection , direct with long terminal shield in 600 mm Widefloor-standing enclosure (cable coming from top or bottom of enclosure)
	10 module(s): CVS100...160 with earth leakage protection , direct with long terminal shield in 600 mm Widewall-mounted enclosure (cable coming from top or bottom of enclosure)
	13 module(s): CVS250 with earth leakage protection , direct with long terminal shield in 600 mm Widefloor-standing enclosure (cable coming from top or bottom of enclosure)
	13 module(s): CVS250 with earth leakage protection , direct with long terminal shield in 600 mm Widewall-mounted enclosure (cable coming from top or bottom of enclosure)
	10 module(s): NSX100...160 with earth leakage protection , direct with long terminal shield in 600 mm Widefloor-standing enclosure (cable coming from top or bottom of enclosure)
	10 module(s): NSX100...160 with earth leakage protection , direct with long terminal shield in 600 mm Widewall-mounted enclosure (cable coming from top or bottom of enclosure)
	13 module(s): NSX250 with earth leakage protection , direct with long terminal shield in 600 mm Widefloor-standing enclosure (cable coming from top or bottom of enclosure)
	13 module(s): NSX250 with earth leakage protection , direct with long terminal shield in 600 mm Widewall-mounted enclosure (cable coming from top or bottom of enclosure)
Standards	IEC 61439-2
Product Certifications	ASEFA

Complementary

Cable Entry	Cut-out plates 0.36 mm top or bottom 167 mm
	Cut-out plates 0.31 mm top or bottom 267 mm
Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Surface Finish	Matt
	Smooth
Colour	White (RAL 9001)
Width	600 mm
Height	150 mm
Net Weight	0.84 kg

Unit Type Of Package 2	S04
Number Of Units In Package 2	14
Package 2 Height	30.000 cm
Package 2 Width	40.000 cm
Package 2 Length	60.000 cm
Package 2 Weight	12.560 kg
Unit Type Of Package 3	P12
Number Of Units In Package 3	56
Package 3 Height	45.000 cm
Package 3 Width	80.000 cm
Package 3 Length	120.000 cm
Package 3 Weight	50.240 kg

Keberlanjutan

Green Premium™ label adalah komitmen Schneider Electric untuk memberikan produk dengan performa lingkungan terbaik di kelasnya. Green Premium menjanjikan kepatuhan pada peraturan terbaru, transparansi pada dampak lingkungan, serta produk melingkar dan rendah CO₂.

Panduan untuk menilai keberlanjutan produk adalah laporan resmi yang menjelaskan standar label lingkungan global dan bagaimana menafsirkan deklarasi lingkungan.

[Pelajari lebih lanjut tentang Green Premium >](#)

[Panduan untuk menilai keberlanjutan produk >](#)



Transparansi RoHS/REACH

Kinerja kesejahteraan

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes
✓	Halogen Free Plastic Parts Product	

Sertifikasi & Standar

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile