


Lembar data produk

Spesifikasi

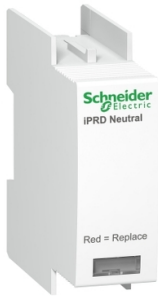

cartridge C neutral-350 for surge arrester iPRD

A9L00002

Main

Product Or Component Type	Cartridge
Device Short Name	C neutral-350
Surge Arrester Type	Electrical distribution network

Complementary

Surge Arrester Class Type	Type 2
Surge Arrester Technology	GDT
Product Destination	Surge protection device iPRD65r 1P + N Surge protection device iPRD65r 3P + N Surge protection device iPRD40r 1P + N Surge protection device iPRD40 1P + N Surge protection device iPRD40r 3P + N Surge protection device iPRD40 3P + N Surge protection device iPRD20r 1P + N Surge protection device iPRD20 1P + N Surge protection device iPRD20r 3P + N Surge protection device iPRD20 3P + N Surge protection device iPRD8r 1P + N Surge protection device iPRD8 1P + N Surge protection device iPRD8r 3P + N Surge protection device iPRD8 3P + N
Earthing System	TT TN
[Ue] Rated Operational Voltage	230 V AC 50 Hz
Nominal Discharge Current	20 kA
Maximum Discharge Current	65 kA
[Uc] Maximum Continuous Operating Voltage	260 V
Maximum [Up] Voltage Protection Level	<1.4 kV type 2
Local Signalling	Flag (white/red)
Mounting Mode	Plug-in
Mounting Support	Into SPD module
9 Mm Pitches	2
Height	57 mm
Width	18 mm
Depth	56 mm
Net Weight	0.044 kg
Colour	White (RAL 9003)
Material	PBT (polybutylene terephthalate)

Disklaimer: Dokumentasi ini tidak ditujukan sebagai pengganti dan tidak untuk digunakan untuk menentukan kesesuaian atau keandalan produk ini untuk aplikasi pengguna

Response Time	< 100 ns
---------------	----------

Environment

Standards	EN 61643-11 IEC 61643-11: 2011
Product Certifications	CE
Ip Degree Of Protection	IP20 front face:
Relative Humidity	5...90 %
Operating Altitude	0...2000 m
Ambient Air Temperature For Operation	-25...60 °C
Ambient Air Temperature For Storage	-40...85 °C

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2.1 cm
Package 1 Width	7.4 cm
Package 1 Length	9.2 cm
Package 1 Weight	69 g
Unit Type Of Package 2	BB1
Number Of Units In Package 2	12
Package 2 Height	10 cm
Package 2 Width	8 cm
Package 2 Length	27.5 cm
Package 2 Weight	899 g
Unit Type Of Package 3	S03
Number Of Units In Package 3	108
Package 3 Height	30 cm
Package 3 Width	30 cm
Package 3 Length	40 cm
Package 3 Weight	8.804 kg

Contractual warranty

Warranty	12 months
----------	-----------

Keberlanjutan

Green Premium™ label adalah komitmen Schneider Electric untuk memberikan produk dengan performa lingkungan terbaik di kelasnya. Green Premium menjanjikan kepatuhan pada peraturan terbaru, transparansi pada dampak lingkungan, serta produk melingkar dan rendah CO₂.

Panduan untuk menilai keberlanjutan produk adalah laporan resmi yang menjelaskan standar label lingkungan global dan bagaimana menafsirkan deklarasi lingkungan.

[Pelajari lebih lanjut tentang Green Premium >](#)

[Panduan untuk menilai keberlanjutan produk >](#)



Transparansi RoHS/REACH

Kinerja kesejahteraan

 Reach Free Of Svhc

 Rohs Exemption Information [Yes](#)

Sertifikasi & Standar

Reach Regulation [REACH Declaration](#)

Eu Rohs Directive Compliant
[EU RoHS Declaration](#)

China Rohs Regulation [China RoHS declaration](#)
Pro-active China RoHS declaration (out of China RoHS legal scope)

Environmental Disclosure [Product Environmental Profile](#)

Circularity Profile [End of Life Information](#)