

Lembar data produk

Spesifikasi



gearbox straight teeth GBX - Ø
120 mm - reduction 8:1 < 7 arc.min
- 120 N.m

GBX120008K

⚠ Telah dihentikan pada: 27 Agu 2020

⚠ Dihentikan

Main

Range Compatibility	Lexium 62 ILM Lexium 62 Lexium SD3 Lexium 52 Lexium 28 Lexium 32i Lexium 32
Product Or Component Type	Planetary gearbox
Gear Box Type	Straight teeth
Device Short Name	GBX
Product Compatibility	BMI (100 mm, 2 motor stacks) BMI (100 mm, 3 motor stacks) BMH (100 mm, 2 motor stacks) BMH (100 mm, 3 motor stacks) BSH (100 mm, 2 motor stacks) BSH (100 mm, 3 motor stacks) BSH (100 mm, 4 motor stacks) BRS3 BCH2 (100 mm, 1 motor stacks) BCH2 (100 mm, 2 motor stacks) BCH2 (130 mm, 1 motor stacks) BCH2 (130 mm, 2 motor stacks) BCH2 (130 mm, 3 motor stacks) BCH2 (130 mm, 4 motor stacks) SH3 MH3 ILM
Gearbox External Diameter	120 mm
Reduction Ratio	8:1

Complementary

Maximum Torsional Backlash	7 arc.min
Torsional Rigidity	12 N.m/arcmin
Housing Colour	Black
Housing Material	Black anodized aluminium
Shaft Material	C 45
Additional Information	Lubricated for life
Service Life In Hours	30000 h at 100 rpm at 30 °C
Mounting Position	Any position
Efficiency	96 %

Disklaimer: Dokumentasi ini tidak ditujukan sebagai pengganti dan tidak untuk digunakan untuk menentukan kesesuaian atau keandalan produk ini untuk aplikasi pengguna

Maximum Radial Force Fr	1500 N at 100 rpm, force applied at mid-distance from output shaft during 30000 hour at 30 °C
Maximum Axial Force Fa	2100 N at 100 rpm, during 30000 hour at 30°C
Moment Of Inertia	1.32 kg.cm²
Continuous Output Torque	120 N.m at 100 rpm at 30 °C
Maximum Output Torque	192 N.m at 100 rpm at 30 °C
Net Weight	6 kg
Input Diameter	24.0 mm

Environment

Noise Level	65 dB at 1 m, no-load
Ip Degree Of Protection	Shaft output: IP54
Ambient Temperature For Operation	-25...90 °C

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	18.0 cm
Package 1 Width	12.5 cm
Package 1 Length	12.5 cm
Package 1 Weight	5.3 kg
Unit Type Of Package 2	S02
Number Of Units In Package 2	2
Package 2 Height	15 cm
Package 2 Width	30 cm
Package 2 Length	40 cm
Package 2 Weight	10.98 kg

Contractual warranty

Warranty	18 months
----------	-----------

Keberlanjutan

Green Premium™ label adalah komitmen Schneider Electric untuk memberikan produk dengan performa lingkungan terbaik di kelasnya. Green Premium menjanjikan kepatuhan pada peraturan terbaru, transparansi pada dampak lingkungan, serta produk melingkar dan rendah CO₂.

Panduan untuk menilai keberlanjutan produk adalah laporan resmi yang menjelaskan standar label lingkungan global dan bagaimana menafsirkan deklarasi lingkungan.

[Pelajari lebih lanjut tentang Green Premium >](#)

[Panduan untuk menilai keberlanjutan produk >](#)



Transparansi RoHS/REACH

Kinerja kesejahteraan

 Mercury Free

 Rohs Exemption Information [Yes](#)


 Pvc Free

Sertifikasi & Standar

Reach Regulation	REACH Declaration
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope)
China Rohs Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations

Dimensions Drawings

Dimensions with Servo Motor Adaptation Kit

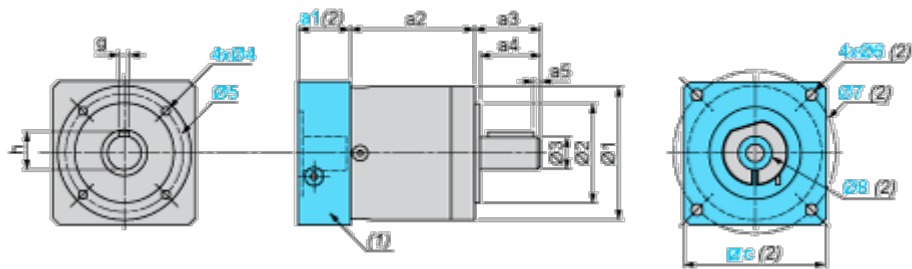

- (1) GBK adaptation kit
- (2) GBK adaptation kit related dimensions a1, c, Ø6, Ø7, Ø8 depend on the gearbox and servo motor combination
- Ø8 shaft end adaptor in case motor shaft diameter is smaller than gearbox input coupling diameter

Values in mm

a2	a3	a4	a5	h	g	Ø1	Ø2	Ø3	Ø4	Ø5
99.5	55	50	5	28	8	115	80 h7	25 h7	M10 x 16	100

Values in in.

a2	a3	a4	a5	h	g	Ø1	Ø2	Ø3	Ø4	Ø5
3.92	2.17	1.97	0.19	1.10	0.31	4.53	3.15 h7	0.98 h7	M10 x 0.63	3.94