


Lembar data produk

Spesifikasi

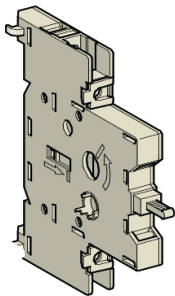

TeSys GV3 - auxiliary contact - 1 NO + 1 NC

GK2AX50

⚠ Telah dihentikan pada: 27 Agu 2020

⚠ Berakhirnya layanan pada: 29 Des 2022

⚠ Dihentikan

Main

Range	TeSys
Device Short Name	GK2AX
Product Or Component Type	Auxiliary contact block
Product Compatibility	GK3EF
Range Compatibility	TeSys GK3 GK3EF circuit breaker
Mounting Location	Right side
Pole Contact Composition	1 NO + 1 NC
Quantity Per Set	Set of 10

Complementary

[Ui] Rated Insulation Voltage	500 V conforming to IEC 60947-1
Control Type	Manual test
[Ue] Rated Operational Voltage	500 V
[Ith] Conventional Free Air Thermal Current	6 A
Protection Type	GB2CB... circuit breaker GG fuse 6 A
Rated Operational Power In Va	360 VA at 48 V AC-15 - electrical durability: 20000 cycles at 6 A 500 VA at 110...127 V AC-15 - electrical durability: 20000 cycles at 4.5 A 800 VA at 220...240 V AC-15 - electrical durability: 20000 cycles at 3.5 A 850 VA at 380...415 V AC-15 - electrical durability: 20000 cycles at 2.2 A 700 VA at 440 V AC-15 - electrical durability: 20000 cycles at 1.5 A 700 VA at 500 V AC-15 - electrical durability: 20000 cycles at 1.5 A
Rated Operational Power In W	180 W at 24 V DC-13 - electrical durability: 1000 cycles 240 W at 48 V DC-13 - electrical durability: 1000 cycles 180 W at 60 V DC-13 - electrical durability: 1000 cycles 140 W at 110 V DC-13 - electrical durability: 1000 cycles 120 W at 220 V DC-13 - electrical durability: 1000 cycles
Height	80 mm
Width	8.8 mm
Depth	105 mm
Net Weight	0.031 kg

Environment

Environmental Characteristic	Normal environment
------------------------------	--------------------

Packing Units

Disklaimer: Dokumentasi ini tidak ditujukan sebagai pengganti dan tidak untuk digunakan untuk menentukan kesesuaian atau keandalan produk ini untuk aplikasi pengguna

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	1.4 cm
Package 1 Width	8.0 cm
Package 1 Length	8.0 cm
Package 1 Weight	40.0 g
Unit Type Of Package 2	S01
Number Of Units In Package 2	30
Package 2 Height	15.0 cm
Package 2 Width	15.0 cm
Package 2 Length	40.0 cm
Package 2 Weight	1.425 kg

Contractual warranty

Warranty	18 months
----------	-----------

Keberlanjutan

Green Premium™ label adalah komitmen Schneider Electric untuk memberikan produk dengan performa lingkungan terbaik di kelasnya. Green Premium menjanjikan kepatuhan pada peraturan terbaru, transparansi pada dampak lingkungan, serta produk melingkar dan rendah CO₂.

Panduan untuk menilai keberlanjutan produk adalah laporan resmi yang menjelaskan standar label lingkungan global dan bagaimana menafsirkan deklarasi lingkungan.

[Pelajari lebih lanjut tentang Green Premium >](#)

[Panduan untuk menilai keberlanjutan produk >](#)



Transparansi RoHS/REACH

Kinerja kesejahteraan

 Mercury Free

 Rohs Exemption Information [Yes](#)

Sertifikasi & Standar

Reach Regulation	REACH Declaration
Eu Rohs Directive	Compliant with Exemptions
China Rohs Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information
Environmental Disclosure	Product Environmental Profile
Weee	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins
Circularity Profile	End of Life Information

Connections and Schema

GK2AX50

