


Lembar data produk

Spesifikasi

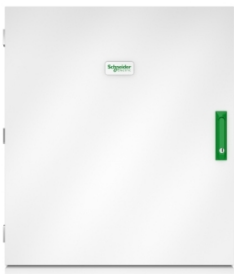

Parallel Maintenance Bypass Panel for 2 UPSs, 40-50kW 400V wallmount, for Galaxy VS and Easy UPS 3S

GVSBBPAR40K50H

Overview

Presentation	Maintenance bypass panel for complete isolation of two UPSs in parallel during service operations.
Lead Time	Usually Ships within 2 Weeks

Physical

Height	85 cm
Width	75 cm
Depth	25 cm
Net Weight	86 kg

Environmental

Ambient Air Temperature For Operation	0...40 °C
Ambient Air Temperature For Storage	-25...55 °C

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	58 cm
Package 1 Width	80 cm
Package 1 Length	120 cm
Package 1 Weight	96 kg

Disklaimer: Dokumentasi ini tidak ditujukan sebagai pengganti dan tidak untuk digunakan untuk menentukan kesesuaian atau keandalan produk ini untuk aplikasi pengguna

Keberlanjutan

Green Premium™ label adalah komitmen Schneider Electric untuk memberikan produk dengan performa lingkungan terbaik di kelasnya. Green Premium menjanjikan kepatuhan pada peraturan terbaru, transparansi pada dampak lingkungan, serta produk melingkar dan rendah CO₂.

Panduan untuk menilai keberlanjutan produk adalah laporan resmi yang menjelaskan standar label lingkungan global dan bagaimana menafsirkan deklarasi lingkungan.

[Pelajari lebih lanjut tentang Green Premium >](#)

[Panduan untuk menilai keberlanjutan produk >](#)



Efisien Energi Take-back Transparansi RoHS/REACH

Kinerja sumber daya

 Energy Efficient Product

 Take-Back Program Available

Kinerja kesejahteraan

 Mercury Free

 Rohs Exemption Information [Yes](#)

Sertifikasi & Standar

Reach Regulation [REACH Declaration](#)

Eu Rohs Directive Pro-active compliance (Product out of EU RoHS legal scope)

Environmental Disclosure [Product Environmental Profile](#)

Circularity Profile [End of Life Information](#)