


Lembar data produk

Spesifikasi

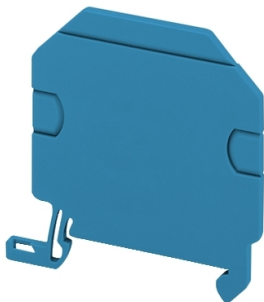

NSYTR partition plate for screw single-level terminal block 1x1 - 2.5 10mm² BL

NSYTRAP22BL

⚠ Telah dihentikan pada: 9 Okt 2023

⚠ Dihentikan

Main

Range	Linergy
Product Name	Linergy TR
Product Or Component Type	Partition
Device Short Name	TRA
Accessory / Separate Part Category	Insulation accessory
Product Compatibility	TRV screw terminal - passthrough terminal block, length = 47.7 mm TRV screw terminal - protective earth terminal block, length = 47.7 mm TRV screw terminal - blade disconnect terminal block, length = 55 mm
Thickness	2 mm

Complementary

Cable Cross Section	2.5 mm² 6 mm² 10 mm² 4 mm²
Number Of Connections	2
Number Of Measurement Input	1 2
Quantity Per Set	Set of 50
Net Weight	4.9 g
Colour	Blue

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	0.5 cm
Package 1 Width	5 cm
Package 1 Length	5.5 cm
Package 1 Weight	4 g
Unit Type Of Package 2	BAG
Number Of Units In Package 2	50
Package 2 Height	4 cm
Package 2 Width	17 cm

Disklaimer: Dokumentasi ini tidak ditujukan sebagai pengganti dan tidak untuk digunakan untuk menentukan kesesuaian atau keandalan produk ini untuk aplikasi pengguna

Package 2 Length	17 cm
Package 2 Weight	247 g
Unit Type Of Package 3	S01
Number Of Units In Package 3	400
Package 3 Height	15 cm
Package 3 Width	15 cm
Package 3 Length	40 cm
Package 3 Weight	2.181 kg

Contractual warranty

Warranty	18 months
----------	-----------

Keberlanjutan

Green Premium™ label adalah komitmen Schneider Electric untuk memberikan produk dengan performa lingkungan terbaik di kelasnya. Green Premium menjanjikan kepatuhan pada peraturan terbaru, transparansi pada dampak lingkungan, serta produk melingkar dan rendah CO₂.

Panduan untuk menilai keberlanjutan produk adalah laporan resmi yang menjelaskan standar label lingkungan global dan bagaimana menafsirkan deklarasi lingkungan.

[Pelajari lebih lanjut tentang Green Premium >](#)

[Panduan untuk menilai keberlanjutan produk >](#)

Kinerja kesejahteraan

	Reach Free Of Svhc	
	Toxic Heavy Metal Free	
	Mercury Free	
	Rohs Exemption Information	Yes
Reach Regulation		REACH Declaration
Eu Rohs Directive		Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation		China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)