

Lembar data produk

Spesifikasi



socket RXZ - mixed contact - 7 A -
250 V - screw clamp - for relay
RXM2..

RXZE1M2C

Main

Range Of Product	Harmony Electromechanical Relays
Device Short Name	RXZ
Product Or Component Type	Socket
Product Compatibility	Plug-in relay RXM with 2 C/O contact
Contacts Type And Composition	2 C/O
[Ith] Conventional Free Air Thermal Current	7 A

Complementary

[Ue] Rated Operational Voltage	250 V
Contact Terminal Arrangement	Mixed
Connections - Terminals	Screw clamp terminals, 1 x 0.2...1 x 1.0 mm ² (AWG 24...AWG 17) flexible with cable end Screw clamp terminals, 2 x 0.2...2 x 1.0 mm ² (AWG 24...AWG 17) flexible with cable end Screw clamp terminals, 1 x 0.5...1 x 1.5 mm ² (AWG 20...AWG 16) solid without cable end Screw clamp terminals, 2 x 0.5...2 x 1.5 mm ² (AWG 20...AWG 16) solid without cable end
Tightening Torque	< 0.8 N.m for M3 screw(s)
Fixing Mode	By screw (panel) Clip-on (35 mm symmetrical DIN rail)
[Uimp] Rated Impulse Withstand Voltage	4 kV
Overvoltage Category	III
Pollution Degree	3
Sale Per Indivisible Quantity	10
Width	22.5 mm
Net Weight	0.034 kg

Environment

Dielectric Strength	2500 V
Standards	IEC 61984
Marking	CE
Ambient Air Temperature For Storage	-55...85 °C
Ambient Air Temperature For Operation	-40...55 °C

Disklaimer: Dokumentasi ini tidak ditujukan sebagai pengganti dan tidak untuk digunakan untuk menentukan kesesuaian atau keandalan produk ini untuk aplikasi pengguna

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2.2 cm
Package 1 Width	3.1 cm
Package 1 Length	7.5 cm
Package 1 Weight	0.03 kg
Unit Type Of Package 2	BB1
Number Of Units In Package 2	10
Package 2 Height	6.4 cm
Package 2 Width	7.9 cm
Package 2 Length	11.2 cm
Package 2 Weight	0.38 kg
Unit Type Of Package 3	S02
Number Of Units In Package 3	180
Package 3 Height	15 cm
Package 3 Width	30 cm
Package 3 Length	40 cm
Package 3 Weight	7.1 kg

Contractual warranty

Warranty	12 months
----------	-----------

Keberlanjutan

Green Premium™ label adalah komitmen Schneider Electric untuk memberikan produk dengan performa lingkungan terbaik di kelasnya. Green Premium menjanjikan kepatuhan pada peraturan terbaru, transparansi pada dampak lingkungan, serta produk melingkar dan rendah CO₂.

Panduan untuk menilai keberlanjutan produk adalah laporan resmi yang menjelaskan standar label lingkungan global dan bagaimana menafsirkan deklarasi lingkungan.

[Pelajari lebih lanjut tentang Green Premium >](#)

[Panduan untuk menilai keberlanjutan produk >](#)



Transparansi RoHS/REACH

Kinerja kesejahteraan


✓ Reach Free Of Svhc	
✓ Toxic Heavy Metal Free	
✓ Mercury Free	
✓ Rohs Exemption Information	Yes

Sertifikasi & Standar

Reach Regulation	REACH Declaration
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation	China RoHS declaration
Environmental Disclosure	Product Environmental Profile
Weee	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins
Circularity Profile	No need of specific recycling operations

Dimensions Drawings

Dimensions

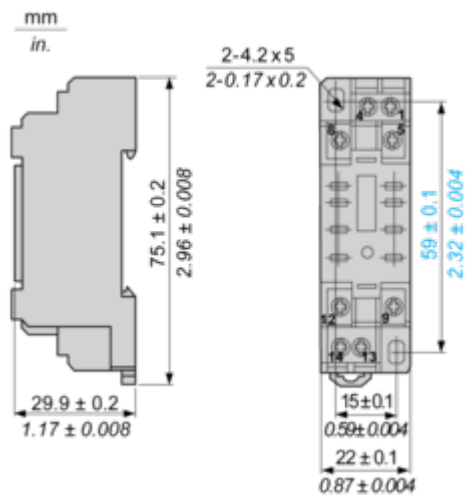

Connections and Schema

Wiring Diagram

