

Lembar data produk

Spesifikasi



Harmony XVC, Monolithic precabled tower light, plastic, red orange, Ø100, base mounting, steady or flashing, IP54, 24 V DC

XVC1B2K

! Dihentikan

! Telah dihentikan pada: 27 Agu 2020

Main

Range Of Product	Harmony XVC1
Product Or Component Type	Complete pre-wired monolithic tower light
Beacon Or Indicator Bank Unit Type	2 illuminated units
Sound Signalling	Without
Mounting Diameter	100 mm
Component Name	XVC
Light Source	LED steady or flashing red LED steady or flashing orange
[Us] Rated Supply Voltage	24 V
Supply Circuit Type	DC

Complementary

Material	Polycarbonate: illuminated unit ABS (acrylonitrile butadiene-styrene): base unit PBT + ABS (UL94-V0): top cover
Product Mounting	On base
Cable Cross Section	0.33 mm ² 0.83 mm ²
Awg Gauge	AWG 18 AWG 22
Cable Length	500 mm
Marking	CE
[Uimp] Rated Impulse Withstand Voltage	0.8 kV
Current Consumption	200 mA
Flashing Frequency	0.7...3 Hz
Net Weight	0.9 kg
Height	294 mm

Environment

Standards	EN/IEC 61000-6-2 EN/IEC 61000-6-3 EN/IEC 61000-6-4
Product Certifications	UL

Disklaimer: Dokumentasi ini tidak ditujukan sebagai pengganti dan tidak untuk digunakan untuk menentukan kesesuaian atau keandalan produk ini untuk aplikasi pengguna

Protective Treatment	TC
Ambient Air Temperature For Storage	-35...70 °C
Ambient Air Temperature For Operation	-30...50 °C
Electrical Shock Protection Class	Class II conforming to EN/IEC 61140
Ip Degree Of Protection	IP54 conforming to EN/IEC 60529

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	20.5 cm
Package 1 Width	20.0 cm
Package 1 Length	44.5 cm
Package 1 Weight	1.694 kg
Unit Type Of Package 2	S06
Number Of Units In Package 2	6
Package 2 Height	73.5 cm
Package 2 Width	60.0 cm
Package 2 Length	80.0 cm
Package 2 Weight	23.16 kg

Contractual warranty

Warranty	18 months
----------	-----------

Keberlanjutan

Green Premium™ label adalah komitmen Schneider Electric untuk memberikan produk dengan performa lingkungan terbaik di kelasnya. Green Premium menjanjikan kepatuhan pada peraturan terbaru, transparansi pada dampak lingkungan, serta produk melingkar dan rendah CO₂.

Panduan untuk menilai keberlanjutan produk adalah laporan resmi yang menjelaskan standar label lingkungan global dan bagaimana menafsirkan deklarasi lingkungan.

[Pelajari lebih lanjut tentang Green Premium >](#)

[Panduan untuk menilai keberlanjutan produk >](#)



Transparansi

Kinerja kesejahteraan

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope)
-------------------	--

China Rohs Regulation	China RoHS declaration
-----------------------	--

Environmental Disclosure	Product Environmental Profile
--------------------------	---


Circularity Profile	End of Life Information
---------------------	---

Dimensions Drawings

Pre-assembled and Pre-wired Tower Light

Dimensions

Below drawing shows the maximum configuration of the product. Select the number of stages according to the product characteristics in order to get **b** dimension.

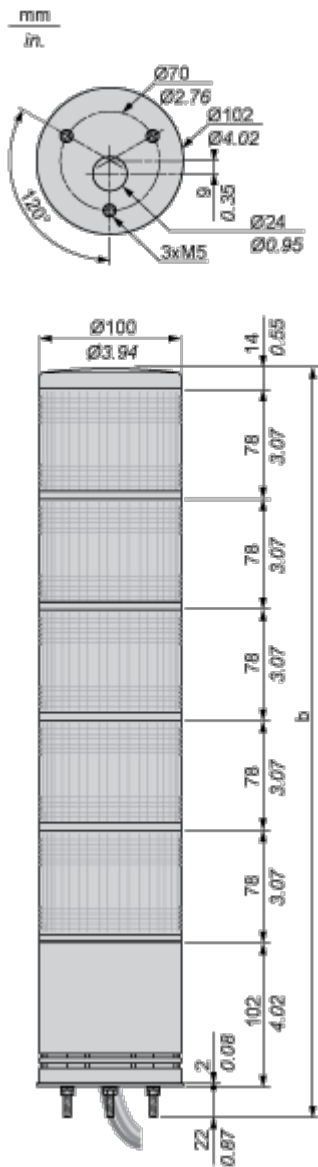

No. of illuminated units	b in mm	b in in.
1	216	8.50
2	294	11.57
3	372	14.65
4	450	17.72
5	528	20.79

Mounting and Clearance

Pre-assembled and Pre-wired Tower Light

Mounting on Horizontal Support (Direct or with Fixing Plate)

Panel cut-out

