

Lembar data produk

Spesifikasi



Complete pre wired monolithic tower light, Harmony XVC, plastic, red orange green, 100mm, base mounting, steady or flashing, IP54, 24V DC

XVC1B3K

! Dihentikan

! Telah dihentikan pada: 27 Agu 2020

Main

Range Of Product	Harmony XVC1
Product Or Component Type	Complete pre-wired monolithic tower light
Beacon Or Indicator Bank Unit Type	3 illuminated units
Sound Signalling	Without
Mounting Diameter	100 mm
Component Name	XVC
Light Source	LED steady or flashing red LED steady or flashing orange LED steady or flashing green
[Us] Rated Supply Voltage	24 V
Supply Circuit Type	DC

Complementary

Material	Polycarbonate: illuminated unit ABS (acrylonitrile butadiene-styrene): base unit PBT + ABS (UL94-V0): top cover
Product Mounting	On base
Cable Cross Section	0.33 mm ² 0.83 mm ²
Awg Gauge	AWG 18 AWG 22
Cable Length	500 mm
Marking	CE
[Uimp] Rated Impulse Withstand Voltage	0.8 kV
Current Consumption	300 mA
Flashing Frequency	0.7...3 Hz
Net Weight	1.1 kg
Height	372 mm

Environment

Standards	IEC 61000-6-3 IEC 61000-6-4 IEC 61000-6-2
-----------	---

Disklaimer: Dokumentasi ini tidak ditujukan sebagai pengganti dan tidak untuk digunakan untuk menentukan kesesuaian atau keandalan produk ini untuk aplikasi pengguna

Product Certifications	UL
Protective Treatment	TC
Ambient Air Temperature For Storage	-35...70 °C
Ambient Air Temperature For Operation	-30...50 °C
Electrical Shock Protection Class	Class II conforming to IEC 61140
Ip Degree Of Protection	IP54 conforming to IEC 60529

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	21.500 cm
Package 1 Width	22.000 cm
Package 1 Length	45.500 cm
Package 1 Weight	1.922 kg
Unit Type Of Package 2	P06
Number Of Units In Package 2	9
Package 2 Height	75.000 cm
Package 2 Width	60.000 cm
Package 2 Length	80.000 cm
Package 2 Weight	25.798 kg

Contractual warranty

Warranty	18 months
----------	-----------

Keberlanjutan

Green Premium™ label adalah komitmen Schneider Electric untuk memberikan produk dengan performa lingkungan terbaik di kelasnya. Green Premium menjanjikan kepatuhan pada peraturan terbaru, transparansi pada dampak lingkungan, serta produk melingkar dan rendah CO₂.

Panduan untuk menilai keberlanjutan produk adalah laporan resmi yang menjelaskan standar label lingkungan global dan bagaimana menafsirkan deklarasi lingkungan.

[Pelajari lebih lanjut tentang Green Premium >](#)

[Panduan untuk menilai keberlanjutan produk >](#)



Transparansi

Kinerja kesejahteraan

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope)
-------------------	--

China Rohs Regulation	China RoHS declaration
-----------------------	--

Environmental Disclosure	Product Environmental Profile
--------------------------	---


Circularity Profile	End of Life Information
---------------------	---

Dimensions Drawings

Pre-assembled and Pre-wired Tower Light

Dimensions

Below drawing shows the maximum configuration of the product. Select the number of stages according to the product characteristics in order to get **b** dimension.

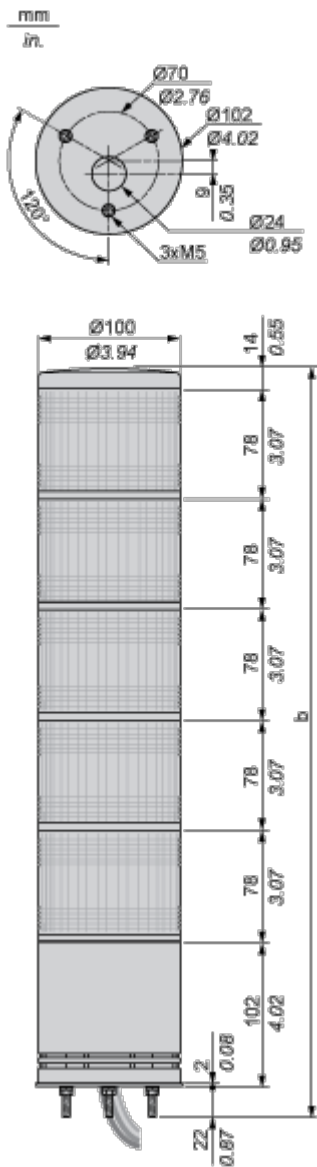

No. of illuminated units	b in mm	b in in.
1	216	8.50
2	294	11.57
3	372	14.65
4	450	17.72
5	528	20.79

Mounting and Clearance

Pre-assembled and Pre-wired Tower Light

Mounting on Horizontal Support (Direct or with Fixing Plate)

Panel cut-out

