

Lembar data produk

Spesifikasi



Monolithic precabled tower light,
Harmony XVC, plastic, red orange,
40mm, tube mounting, steady, IP23,
24V AC DC

XVC4B2

! Dihentikan

! Telah dihentikan pada: 27 Agu 2020

Main

Range Of Product	Harmony XVC4
Product Or Component Type	Complete pre-wired monolithic tower light
Beacon Or Indicator Bank Unit Type	2 illuminated units
Sound Signalling	Without
Mounting Diameter	40 mm
Component Name	XVC
Device Short Name	XVC
Light Source	LED steady red LED steady orange
Supply Circuit Type	AC/DC

Complementary

Material	Polycarbonate: illuminated unit ABS (acrylonitrile butadiene-styrene): base unit PBT + ABS (UL94HB): top cover SGP (chromium-plated): support tube
Mounting Location	On support tube, 17 mm
Product Mounting	On support tube, 17 mm
[Us] Rated Supply Voltage	24 V
[Us] Rated Supply Voltage	24 V
Cable Cross Section	0.33 mm ²
Awg Gauge	AWG 22
Cable Length	600 mm
Marking	CE
[Uimp] Rated Impulse Withstand Voltage	0.8 kV
Current Consumption	50 mA
Flashing Frequency	1 Hz
Net Weight	0.52 kg
Height	438.5 mm

Environment

Disklaimer: Dokumentasi ini tidak ditujukan sebagai pengganti dan tidak untuk digunakan untuk menentukan kesesuaian atau keandalan produk ini untuk aplikasi pengguna

Standards	IEC 61000-6-2 IEC 61000-6-3
Product Certifications	UL
Protective Treatment	TC
Ambient Air Temperature For Storage	-35...70 °C
Ambient Air Temperature For Operation	-10...50 °C
Electrical Shock Protection Class	Class I conforming to IEC 61140
Overvoltage Category	Class I conforming to IEC 61140
Ip Degree Of Protection	IP23 vertical surface installation conforming to IEC 60529

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	6.600 cm
Package 1 Width	6.600 cm
Package 1 Length	75.000 cm
Package 1 Weight	715.000 g
Unit Type Of Package 2	P06
Number Of Units In Package 2	10
Package 2 Height	75.000 cm
Package 2 Width	60.000 cm
Package 2 Length	80.000 cm
Package 2 Weight	16.150 kg

Contractual warranty

Warranty	18 months
----------	-----------

Keberlanjutan

Green Premium™ label adalah komitmen Schneider Electric untuk memberikan produk dengan performa lingkungan terbaik di kelasnya. Green Premium menjanjikan kepatuhan pada peraturan terbaru, transparansi pada dampak lingkungan, serta produk melingkar dan rendah CO₂.

Panduan untuk menilai keberlanjutan produk adalah laporan resmi yang menjelaskan standar label lingkungan global dan bagaimana menafsirkan deklarasi lingkungan.

[Pelajari lebih lanjut tentang Green Premium >](#)

[Panduan untuk menilai keberlanjutan produk >](#)



Transparansi

Kinerja kesejahteraan

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope)
-------------------	--

China Rohs Regulation	China RoHS declaration
-----------------------	--

Environmental Disclosure	Product Environmental Profile
--------------------------	---


Circularity Profile	End of Life Information
---------------------	---

Dimensions Drawings

Pre-assembled and Pre-wired Tower Light with Support Tube Mounting

Dimensions

Below drawing shows the maximum configuration of the product. Select the number of stages according to the product characteristics in order to get **b** dimension.

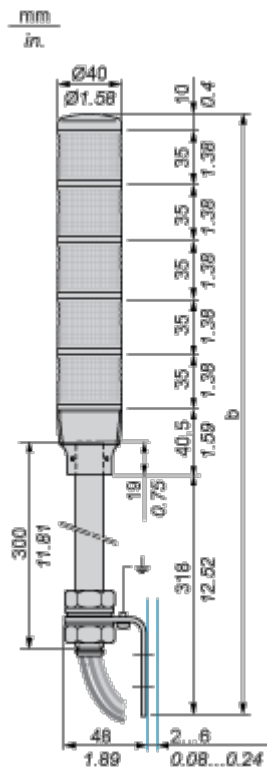

No. of illuminated units	b Without buzzer (mm)	b Without buzzer (in.)
1 stage	403.50	15.89
2 stages	438.50	17.26
3 stages	473.50	18.64
4 stages	508.50	20.02
5 stages	543.50	21.40

Mounting and Clearance

Pre-assembled and Pre-wired Tower Light

Support Tube Mounting

