

Lembar data produk

Spesifikasi



40mm Tower RO Pole Buzzer Flash

XVC4B25S

⚠ Telah dihentikan pada: 27 Agu 2020

Harga: 2.856.700,00 IDR

⚠ Dihentikan

Main

Range Of Product	Harmony XVC4
Product Or Component Type	Complete pre-wired monolithic tower light
Beacon Or Indicator Bank Unit Type	2 illuminated units
Sound Signalling	Buzzer
Mounting Diameter	40 mm
Component Name	XVC
Device Short Name	XVC
Light Source	LED steady or flashing red LED steady or flashing orange
Supply Circuit Type	AC/DC
Noise Level	70...85 dB (continuous or intermittent tone) at 1 m

Complementary

Material	Polycarbonate: illuminated unit ABS (acrylonitrile butadiene-styrene): base unit PBT + ABS (UL94HB): top cover SGP (chromium-plated): support tube
Mounting Location	On support tube, 17 mm
Product Mounting	On support tube, 17 mm
[Us] Rated Supply Voltage	24 V
[Us] Rated Supply Voltage	24 V
Cable Cross Section	0.33 mm²
Awg Gauge	AWG 22
Cable Length	900 mm
Marking	CE
[Uimp] Rated Impulse Withstand Voltage	0.8 kV
Current Consumption	90 mA
Fundamental Frequency	2.23 kHz
Flashing Frequency	1 Hz
Net Weight	0.62 kg
Height	559.5 mm

Disklaimer: Dokumentasi ini tidak ditujukan sebagai pengganti dan tidak untuk digunakan untuk menentukan kesesuaian atau keandalan produk ini untuk aplikasi pengguna

Environment

Standards	EN/IEC 61000-6-2 EN/IEC 61000-6-3
Product Certifications	UL
Protective Treatment	TC
Ambient Air Temperature For Storage	-35...70 °C
Ambient Air Temperature For Operation	-10...50 °C
Electrical Shock Protection Class	Class I conforming to EN/IEC 61140
Overvoltage Category	Class I conforming to EN/IEC 61140
Ip Degree Of Protection	IP23 vertical surface installation conforming to EN/IEC 60529

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	6.600 cm
Package 1 Width	6.600 cm
Package 1 Length	75.000 cm
Package 1 Weight	850.000 g
Unit Type Of Package 2	P06
Number Of Units In Package 2	10
Package 2 Height	45.000 cm
Package 2 Width	60.000 cm
Package 2 Length	80.000 cm
Package 2 Weight	17.000 kg

Contractual warranty

Warranty	18 months
----------	-----------

Keberlanjutan

Green Premium™ label adalah komitmen Schneider Electric untuk memberikan produk dengan performa lingkungan terbaik di kelasnya. Green Premium menjanjikan kepatuhan pada peraturan terbaru, transparansi pada dampak lingkungan, serta produk melingkar dan rendah CO₂.

Panduan untuk menilai keberlanjutan produk adalah laporan resmi yang menjelaskan standar label lingkungan global dan bagaimana menafsirkan deklarasi lingkungan.

[Pelajari lebih lanjut tentang Green Premium >](#)

[Panduan untuk menilai keberlanjutan produk >](#)



Transparansi

Kinerja kesejahteraan



Mercury Free



Rohs Exemption Information

[Yes](#)

Eu Rohs Directive

Pro-active compliance (Product out of EU RoHS legal scope)

China Rohs Regulation

[China RoHS declaration](#)

Environmental Disclosure

[Product Environmental Profile](#)

Circularity Profile


[End of Life Information](#)

Dimensions Drawings

Pre-assembled and Pre-wired Tower Light with Support Tube Mounting

Dimensions

Below drawing shows the maximum configuration of the product. Select the number of stages according to the product characteristics in order to get **b1** dimension.

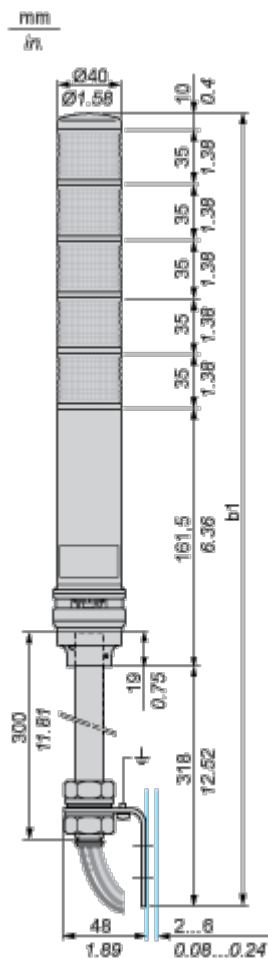

No. of illuminated units	b1 With buzzer (mm)	b1 With buzzer (in.)
1 stage	524.50	20.65
2 stages	559.50	22.03
3 stages	594.50	23.41
4 stages	629.50	24.78
5 stages	664.50	26.16

Mounting and Clearance

Pre-assembled and Pre-wired Tower Light

Support Tube Mounting

