

Lembar data produk

Spesifikasi



indicator bank XVD with LED - G-R steady - 24 V AC/DC - IP 40

XVDB2GR

- ⚠️ Telah dihentikan pada: 27 Agu 2020
- ⚠️ Berakhirnya layanan pada: 31 Des 2015

⚠️ Dihentikan

Main

Range Of Product	Harmony XVD Application
Product Or Component Type	Complete pre-cabled indicator bank
Beacon Or Indicator Bank Unit Type	2 illuminated units
Component Name	XVD
Light Source	Green LED with BA 15d base steady signalling Red LED with BA 15d base steady signalling
Light Block Color	Green/red
[Us] Rated Supply Voltage	24 V AC/DC

Complementary

Material	Glass reinforced polyamide: base unit Polycarbonate: cover Polycarbonate: illuminated unit
Mounting Diameter	70 mm
Connections - Terminals	Screw clamp terminals, 1 x 0.82 mm ² with bared wire ends
[Ui] Rated Insulation Voltage	250 V conforming to IEC 60947-1
Nominal Voltage Limit	0.85...1.1 Un conforming to IEC 60947-5-1
Current Consumption	< 47 mA on LED unit
[Uimp] Rated Impulse Withstand Voltage	4 kV conforming to IEC 60947-1
Net Weight	0.553 kg

Environment

Standards	EN/IEC 60947-5-1
Product Certifications	GOST CSA UL
Protective Treatment	TC
Ambient Air Temperature For Storage	-40...70 °C
Ambient Air Temperature For Operation	-25...50 °C
Electrical Shock Protection Class	Class I on support tube, with metal fixing plate conforming to IEC 60536 Class II on support tube, with plastic fixing plate conforming to IEC 60536
Ip Degree Of Protection	IP40 conforming to IEC 60529

Disklaimer: Dokumentasi ini tidak ditujukan sebagai pengganti dan tidak untuk digunakan untuk menentukan kesesuaian atau keandalan produk ini untuk aplikasi pengguna

Contractual warranty


Warranty	18 months
----------	-----------

Dimensions Drawings

Complete pre-Cabled Indicator Bank without “Flash” Discharge Tube

Dimensions

Below drawing shows the minimum configuration of the product. Select the number of stages according to the product characteristics in order to get **b** dimension.

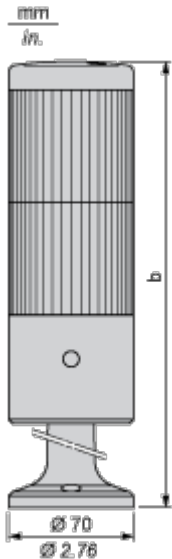


Number of illuminated or audible signalling units (no “flash”)	b in mm	b in in.
2	302	11.89
3	365	14.37
4	428	16.85

Connections and Schema

Complete pre-Cabled Indicator Bank

Wiring Diagram

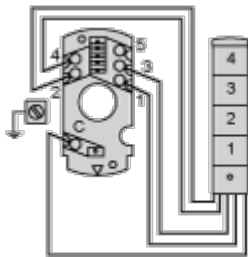

Wire colors:

- C: black
- 1: brown
- 2: grey
- 3: violet
- 4: blue