

# Lembar data produk

Spesifikasi



## Tower Light - RG - 24V - LED - Direct tube mounting

XVGB2T

### Main

|                                    |                                                                    |
|------------------------------------|--------------------------------------------------------------------|
| Range Of Product                   | Harmony XVG                                                        |
| Product Or Component Type          | Complete pre-wired monolithic tower light                          |
| Beacon Or Indicator Bank Unit Type | 2 illuminated units                                                |
| Material                           | PC (UL94 V-2): globe<br>ABS (UL94HB): tube body<br>Aluminium: tube |
| Mounting Diameter                  | 60 mm                                                              |
| Component Name                     | XVG                                                                |
| Device Mounting                    | Direct tube mounting                                               |
| Light Source                       | LED steady red<br>LED steady green                                 |
| Light Block Color                  | Red/green                                                          |
| Indicator Bank Base Type           | Base without buzzer                                                |

### Complementary

|                                        |             |
|----------------------------------------|-------------|
| Rated Supply Voltage                   | 24 V AC/DC  |
| Cable Cross Section                    | 0.33 mm²    |
| Discrete Output Type                   | PNP and NPN |
| [Uimp] Rated Impulse Withstand Voltage | 0.5 kV      |
| Current Consumption                    | 68 mA       |
| Power Consumption In W                 | 1.6 W       |
| Fundamental Frequency                  | 2.64 kHz    |
| Net Weight                             | 0.35 kg     |

### Environment

|                                       |             |
|---------------------------------------|-------------|
| Product Certifications                | CE<br>EAC   |
| Ambient Air Temperature For Storage   | -35...70 °C |
| Ambient Air Temperature For Operation | -10...50 °C |
| Ip Degree Of Protection               | IP23        |

### Packing Units

|                        |     |
|------------------------|-----|
| Unit Type Of Package 1 | PCE |
|------------------------|-----|

Disklaimer: Dokumentasi ini tidak ditujukan sebagai pengganti dan tidak untuk digunakan untuk menentukan kesesuaian atau keandalan produk ini untuk aplikasi pengguna

|                              |          |
|------------------------------|----------|
| Number Of Units In Package 1 | 1        |
| Package 1 Height             | 15.8 cm  |
| Package 1 Width              | 13.0 cm  |
| Package 1 Length             | 8.5 cm   |
| Package 1 Weight             | 454.0 g  |
| Unit Type Of Package 2       | S06      |
| Number Of Units In Package 2 | 30       |
| Package 2 Height             | 73.5 cm  |
| Package 2 Width              | 60.0 cm  |
| Package 2 Length             | 80.0 cm  |
| Package 2 Weight             | 13.62 kg |

## Contractual warranty

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

Keberlanjutan



**Green Premium™** label adalah komitmen Schneider Electric untuk memberikan produk dengan performa lingkungan terbaik di kelasnya. Green Premium menjanjikan kepatuhan pada peraturan terbaru, transparansi pada dampak lingkungan, serta produk melingkar dan rendah CO<sub>2</sub>.

**Panduan untuk menilai keberlanjutan produk** adalah laporan resmi yang menjelaskan standar label lingkungan global dan bagaimana menafsirkan deklarasi lingkungan.

[Pelajari lebih lanjut tentang Green Premium >](#)

[Panduan untuk menilai keberlanjutan produk >](#)



Transparansi   RoHS/REACH

### Kinerja kesejahteraan

 Mercury Free

 Rohs Exemption Information   [Yes](#)

### Sertifikasi & Standar

Reach Regulation   [REACH Declaration](#)

Eu Rohs Directive   Pro-active compliance (Product out of EU RoHS legal scope)


China Rohs Regulation   [China RoHS declaration](#)

Environmental Disclosure   [Product Environmental Profile](#)

Circularity Profile   [End of Life Information](#)

Dimensions Drawings


Dimensions

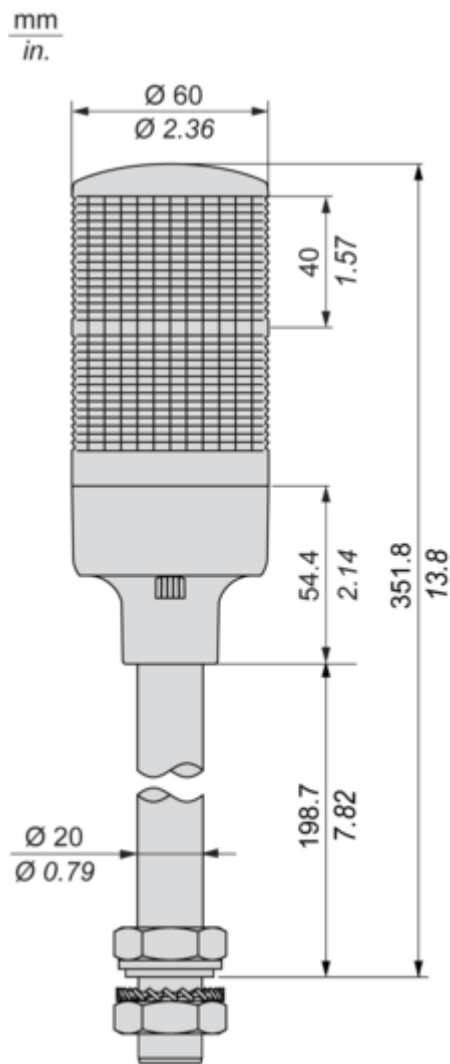

Mounting and Clearance


Mounting

---

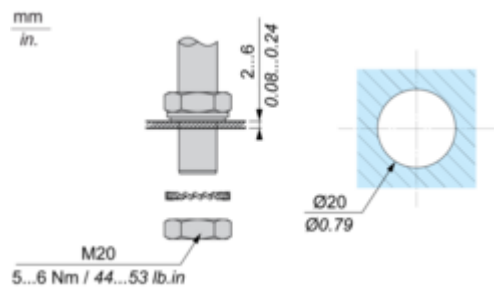

Connections and Schema

Wiring

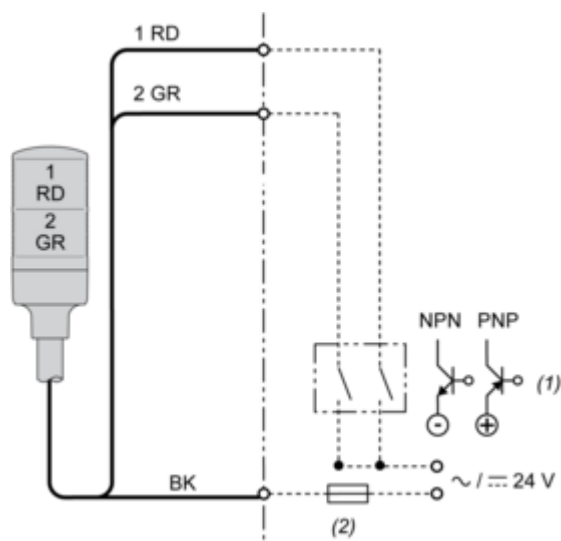

- (1) "ON" for lighting and/or applying continuous sound.  
(2) Fuse (rated current: 0.5 A)  
RD : Red  
GR : Green  
BK : Black