



# Product datasheet

Specifications

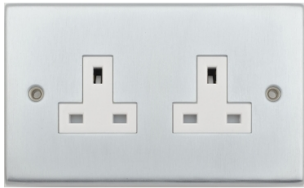

## Exclusive Decorative - socket-outlet - 13 A - 2 gangs - matt chrome

GEP3560WMC

 **Discontinued on:** 30 Oct 2019

 **Discontinued**

### Main

Range Of Product	Exclusive
Aesthetic Name	Decorative
Product Or Component Type	Socket-outlet
Device Presentation	Complete product
Outlet Poles Configuration	1P
Outlet Standard Description	3 pins
Outlet Standard	British
Colour Tint	Chrome matt
Quantity Per Set	Set of 1

### Complementary

Number Of Gangs	2 gangs
Switch Function	Unswitch
Device Mounting	Wall mounted
Rated Current	13 A at 230 V AC 50 Hz
Fixing Mode	By screws M3.5 x 30 mm
Connections - Terminals	Screw terminals
Material	Steel
Type Of Installation	Indoor
Height	95 mm
Width	155 mm
Depth	38 mm
Net Weight	0.242 kg

### Environment

Standards	BS 1363
Ip Degree Of Protection	IP20

### Contractual warranty

Warranty	18 months
----------	-----------

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

# Sustainability

**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)

## Eu Rohs Directive

Pro-active compliance (Product out of EU RoHS legal scope)

[EU RoHS Declaration](#)

---