


# Product datasheet

Specifications

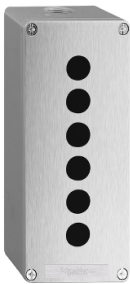

die-cast empty control station,  
XAPG, grey, Ø22, 80x175mm front  
plate, 6 cut-outs

XAPG3506

 **Discontinued on:** 1 Jul 2020

 **Discontinued**

## Main

Range Of Product	Harmony XAP
Product Or Component Type	Die-cast empty control station
Device Short Name	XAPG
Product Destination	For Ø 22 mm control and signalling units
Product Front Plate Size	80 x 175 mm
Usable Depth	74.5 mm
Number Of Cut-Out	6 cut-outs
Colour Of Base Of Enclosure	Grey (RAL 7032)
Colour Of Cover	Grey (RAL 7032)
Material	Zinc alloy
Product Mounting	Flush mounting
Ip Degree Of Protection	IP65 conforming to IEC 60529

## Complementary

Number Of Vertical Rows	2
Cable Entry	18 mm 1 hole with blanking plug for cable gland 18 mm 1 hole without blanking plug for cable gland
Net Weight	1.13 kg
Compatibility Code	XAPG

## Environment

Protective Treatment	TH
Ambient Air Temperature For Storage	-40...70 °C
Ambient Air Temperature For Operation	-25...70 °C
Electrical Shock Protection Class	Class I conforming to IEC 60536 Class I conforming to NF C 20-030

## Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	9 cm
Package 1 Width	12 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Length	19 cm
Package 1 Weight	1.275 kg

## Contractual warranty

Warranty	18 months
----------	-----------