


# Product datasheet

Specifications

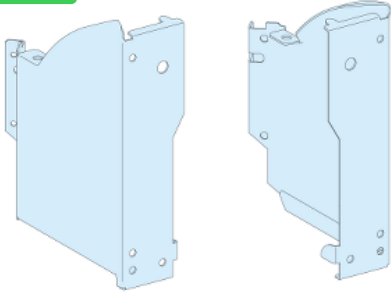

## 2 PLAIN BASES PRISMA G IP30

01051

⚠ Discontinued on: 30 September 2022

⚠ To be discontinued

### Main

Range	Prisma
Range of product	Prisma G
Product or component type	Bracket
Accessory / separate part category	Spare part
Range compatibility	Prisma (Prisma G) enclosure
Product compatibility	IP43 enclosure IP31 enclosure IP30 enclosure
Provided equipment	4 self-threading screws 1 right base bracket 1 left base bracket

### Complementary

Installation description	Floor-standing enclosure Floor-standing duct
Quantity per set	Set of 1
Height	150 mm
Net weight	1 kg
Surface finish	Matt Smooth
Protective treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)

### Environment

IP degree of protection	IP30
-------------------------	------

### Packing Units

Unit Type of Package 1	Db
Number of Units in Package 1	1
Package 1 Height	12.100 cm
Package 1 Width	21.000 cm
Package 1 Length	30.700 cm

Package 1 Weight	1.391 kg
Unit Type of Package 2	P12
Number of Units in Package 2	80
Package 2 Height	100.000 cm
Package 2 Width	80.000 cm
Package 2 Length	120.000 cm
Package 2 Weight	123.280 kg

## Offer Sustainability


Sustainable offer status	Green Premium product
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS declaration</a> Pro-active China RoHS declaration (out of China RoHS legal scope)
RoHS exemption information	<a href="#">Yes</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	<a href="#">End of Life Information</a>
Halogen content performance	Halogen free plastic parts product

## Contractual warranty

Warranty	12 months
----------	-----------

## Recommended replacement(s)

01051 is replaced by:

1x		Plinth spare part, PrismaSeT G, 2 plain base brackets (left/right) with screws, for IP30 enclosure LVS01051
----	---	--