


Product datasheet

Specifications

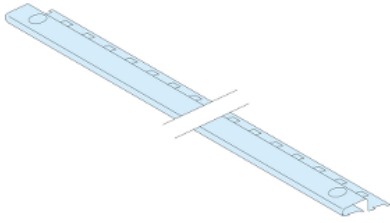

2 PLATE UPRIGHTS 33M PRISMA G IP30

01259

! Discontinued on: 30 September 2022

! To be discontinued

Main

Range	Prisma
Range of product	Prisma G
Product or component type	Front cover support upright
Accessory / separate part category	Mounting accessory Spare part
Range compatibility	Prisma (Prisma G) enclosure
IP degree of protection	IP30

Complementary

Installation description	Extension enclosure - width 600 mm Floor-standing enclosure - width 600 mm Floor-standing enclosure - width 850 mm
Number of vertical modules [50 mm]	33
Quantity per set	Set of 2
Height	35 mm
Width	1650 mm
Depth	11 mm
Net weight	1.96 kg
Material	Steel
Surface finish	Smooth Matt
Protective treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)

Packing Units

Unit Type of Package 1	Db
Number of Units in Package 1	1
Package 1 Height	1.700 cm
Package 1 Width	6.000 cm
Package 1 Length	164.000 cm

Package 1 Weight	1.960 kg
Unit Type of Package 2	PAL
Number of Units in Package 2	50
Package 2 Height	40.000 cm
Package 2 Width	120.000 cm
Package 2 Length	200.000 cm
Package 2 Weight	98.000 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Halogen content performance	Halogen free product

Recommended replacement(s)