


Product datasheet

Specifications

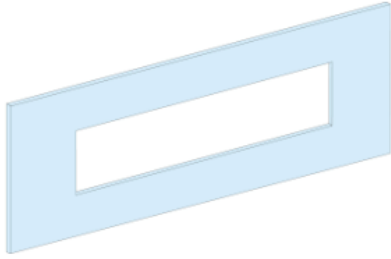

FRONT PLATE 3-4 VIGI NSX/ CVS250 VERTICAL FIXED TOGGLE WIDTH 600/650 7M

03241

Main

Range	Prisma
Range of product	Prisma G Prisma P
Product or component type	Front plate
Accessory / separate part category	Installation accessory
Range compatibility	Prisma G enclosure Prisma P cubicle
Type of front plate	Cut-out
Installed device	ComPact: fixed NSX100...160 with earth leakage protection - control: toggle - vertical installation ComPact: fixed NSX250 with earth leakage protection - control: toggle - vertical installation EasyPact: fixed CVS100...160 with earth leakage protection - control: toggle - vertical installation EasyPact: fixed CVS250 with earth leakage protection - control: toggle - vertical installation ComPact: plug-in NSX100...160 with earth leakage protection - control: toggle - vertical installation ComPact: plug-in NSX250 with earth leakage protection - control: toggle - vertical installation
Poles description	4 x 3P: mounting plate support: CVS100...160 vertical installation 3 x 4P: mounting plate support: CVS100...160 vertical installation 4 x 3P: mounting plate support: CVS250 vertical installation 3 x 4P: mounting plate support: CVS250 vertical installation 4 x 3P: mounting plate support: NSX100...160 vertical installation 3 x 4P: mounting plate support: NSX100...160 vertical installation 4 x 3P: mounting plate support: NSX250 vertical installation 3 x 4P: mounting plate support: NSX250 vertical installation
Operating position	Vertical

Complementary

Enclosure/Cubicle description	Floor-standing enclosure - width 600 mm Wall-mounted enclosure - width 600 mm Cubicle - width 650 mm depth 400 mm
Connection position	Direct connection Linergy FC
Number of vertical modules [50 mm]	7
Standards	IEC 61439-1 IEC 61439-2
Product certifications	ASEFA
Material	Steel
Surface finish	Matt Smooth
Protective treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)

Height	350 mm
Width	500 mm
Net weight	1.1 kg
Quantity per set	Set of 1
Functional unit	<p>650 mm 400 mm Prisma P cubicle EasyPact CVS100...160 with fixed toggle vertical 3P 4 direct 11</p> <p>650 mm 400 mm Prisma P cubicle EasyPact CVS100...160 with fixed toggle vertical 4P 3 direct 11</p> <p>650 mm 400 mm Prisma P cubicle EasyPact CVS250 with fixed toggle vertical 3P 4 direct 11</p> <p>650 mm 400 mm Prisma P cubicle EasyPact CVS250 with fixed toggle vertical 4P 3 direct 11</p> <p>650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed toggle vertical 3P 4 Linergy FC 8</p> <p>650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed toggle vertical 4P 3 Linergy FC 8</p> <p>650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed toggle vertical 3P 4 direct 10</p> <p>650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed toggle vertical 4P 3 direct 10</p> <p>650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in toggle vertical 3P 4 direct 11</p> <p>650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in toggle vertical 4P 3 direct 11</p> <p>650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in toggle vertical 3P 4 Linergy FC 9</p> <p>650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in toggle vertical 4P 3 Linergy FC 9</p> <p>650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed toggle vertical 3P 4 Linergy FC 9</p> <p>650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed toggle vertical 4P 3 Linergy FC 9</p> <p>650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed toggle vertical 3P 4 direct 11</p> <p>650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed toggle vertical 4P 3 direct 11</p> <p>650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in toggle vertical 3P 4 direct 12</p> <p>650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in toggle vertical 4P 3 direct 12</p> <p>650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in toggle vertical 3P 4 Linergy FC 10</p> <p>650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in toggle vertical 4P 3 Linergy FC 10</p> <p>600 mm Prisma G floor-standing enclosure EasyPact CVS100...160 with fixed toggle vertical 3P 4 direct with long terminal shield 10</p> <p>600 mm Prisma G wall-mounted enclosure EasyPact CVS100...160 with fixed toggle vertical 3P 4 direct with long terminal shield 10</p> <p>600 mm Prisma G floor-standing enclosure EasyPact CVS100...160 with fixed toggle vertical 4P 3 direct with long terminal shield 10</p> <p>600 mm Prisma G wall-mounted enclosure EasyPact CVS100...160 with fixed toggle vertical 4P 3 direct with long terminal shield 10</p> <p>600 mm Prisma G floor-standing enclosure EasyPact CVS250 with fixed toggle vertical 3P 4 direct with long terminal shield 13</p> <p>600 mm Prisma G wall-mounted enclosure EasyPact CVS250 with fixed toggle vertical 3P 4 direct with long terminal shield 13</p> <p>600 mm Prisma G floor-standing enclosure EasyPact CVS250 with fixed toggle vertical 4P 3 direct with long terminal shield 13</p> <p>600 mm Prisma G wall-mounted enclosure EasyPact CVS250 with fixed toggle vertical 4P 3 direct with long terminal shield 13</p> <p>600 mm Prisma G floor-standing enclosure ComPact NSX100...160 with fixed toggle vertical 3P 4 direct with long terminal shield 10</p> <p>600 mm Prisma G wall-mounted enclosure ComPact NSX100...160 with fixed toggle vertical 3P 4 direct with long terminal shield 10</p> <p>600 mm Prisma G floor-standing enclosure ComPact NSX100...160 with fixed toggle vertical 4P 3 direct with long terminal shield 10</p> <p>600 mm Prisma G wall-mounted enclosure ComPact NSX100...160 with fixed toggle vertical 4P 3 direct with long terminal shield 10</p> <p>600 mm Prisma G floor-standing enclosure ComPact NSX250 with fixed toggle vertical 3P 4 direct with long terminal shield 13</p> <p>600 mm Prisma G wall-mounted enclosure ComPact NSX250 with fixed toggle vertical 3P 4 direct with long terminal shield 13</p> <p>600 mm Prisma G floor-standing enclosure ComPact NSX250 with fixed toggle vertical 4P 3 direct with long terminal shield 13</p> <p>600 mm Prisma G wall-mounted enclosure ComPact NSX250 with fixed toggle vertical 4P 3 direct with long terminal shield 13</p>

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	1.14 kg
Package 1 Height	31.5 cm
Package 1 width	36 cm
Package 1 Length	51.5 cm
Unit Type of Package 2	CAR
Number of Units in Package 2	10
Package 2 Weight	11.4 kg
Package 2 Height	17 cm
Package 2 width	36.5 cm
Package 2 Length	54 cm

Unit Type of Package 3	P12
Number of Units in Package 3	160
Package 3 Weight	185.28 kg
Package 3 Height	83 cm
Package 3 width	80 cm
Package 3 Length	120 cm

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
Halogen content performance	Halogen free plastic parts product

Contractual warranty

Warranty	12 months
-----------------	-----------