


# Product datasheet

Specifications

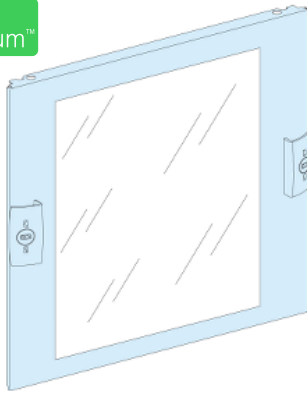

## TRANSPARENT FRONT PLATE W300 6M

03353

### Main

Range	Prisma
Range of product	Prisma G Prisma P
Product or component type	Front plate
Accessory / separate part category	Installation accessory
Range compatibility	Prisma G duct Prisma P cubicle
Type of front plate	Transparent
Installed device	TeSys: fixed GV3Pxx1 + LC1D40 to D65 - horizontal installation
Poles description	3 x 3P: modular rail support: GV3Pxx1 + LC1D40 to D65 horizontal installation

### Complementary

Enclosure/Cubicle description	Floor-standing duct - width 300 mm Wall-mounted duct - width 300 mm Cubicle duct - width 400 mm depth 400 mm
Number of vertical modules [50 mm]	6
Standards	IEC 61439-2 IEC 61439-1
Product certifications	ASEFA
Material	Glass
Surface finish	Smooth Matt
Protective treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)
Height	300 mm
Width	300 mm
Net weight	0.76 kg
Quantity per set	Set of 1
Functional unit	400 mm 400 mm Prisma P cubicle 300 mm Prisma G floor-standing duct TeSys GV3Pxx1 + LC1D40 to D65 fixed horizontal 3P 3 direct 7 300 mm Prisma G wall-mounted duct TeSys GV3Pxx1 + LC1D40 to D65 fixed horizontal 3P 3 direct 7

## Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	760 g
Package 1 Height	3 cm
Package 1 width	25 cm
Package 1 Length	30 cm
Unit Type of Package 2	BB1
Number of Units in Package 2	8
Package 2 Weight	7.39 kg
Package 2 Height	18 cm
Package 2 width	28 cm
Package 2 Length	32 cm
Unit Type of Package 3	S03
Number of Units in Package 3	8
Package 3 Weight	7.83 kg
Package 3 Height	30 cm
Package 3 width	30 cm
Package 3 Length	40 cm

## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a> Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	<a href="#">Product Environmental Profile</a>

## Contractual warranty

Warranty	12 months
----------	-----------