


Product datasheet

Specifications

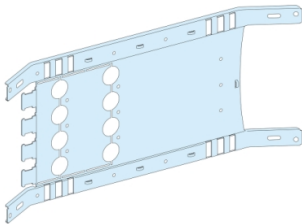

MOUNTING PLATE VIGI NSX/ CVS TOGGLE - 4P 630A HORIZONTAL WIDTH 650

03452

⚠ Discontinued on: 12 May 2023

⚠ Discontinued

Main

Range	Prisma
Range Of Product	Prisma P
Product Or Component Type	Mounting plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma P cubicle
Installation Description	Cubicle - width 650 mm depth 400 mm
Installed Device	EasyPact: fixed CVS400 without earth leakage protection - control: toggle - horizontal installation EasyPact: fixed CVS630 without earth leakage protection - control: toggle - horizontal installation EasyPact: fixed EZC400 - control: toggle - horizontal installation EasyPact: fixed EZC630 - control: toggle - horizontal installation ComPact: fixed INS320...400 - control: direct front rotary handle - horizontal installation ComPact: fixed INS500...630 - control: direct front rotary handle - horizontal installation ComPact: fixed INV320...400 - control: direct front rotary handle - horizontal installation ComPact: fixed INV500...630 - control: direct front rotary handle - horizontal installation ComPact: fixed NSX400 without earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX630 without earth leakage protection - control: toggle - horizontal installation EasyPact: fixed CVS400 with earth leakage protection - control: toggle - horizontal installation EasyPact: fixed CVS630 with earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX400 with earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX630 with earth leakage protection - control: toggle - horizontal installation

Poles Description	1 x 4P: fixed CVS400 horizontal installation 1 x 4P: fixed CVS630 horizontal installation 1 x 4P: fixed EZC400 horizontal installation 1 x 4P: fixed EZC630 horizontal installation 1 x 3P: fixed INS320...400 horizontal installation 1 x 4P: fixed INS320...400 horizontal installation 1 x 3P: fixed INS500...630 horizontal installation 1 x 4P: fixed INS500...630 horizontal installation 1 x 3P: fixed INV320...400 horizontal installation 1 x 4P: fixed INV320...400 horizontal installation 1 x 3P: fixed INV500...630 horizontal installation 1 x 4P: fixed INV500...630 horizontal installation 1 x 4P: fixed NSX400 horizontal installation 1 x 4P: fixed NSX630 horizontal installation
-------------------	--

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Number Of Vertical Modules [50 Mm]	5 module(s): CVS400 without earth leakage protection , direct in 650 mm Widecubicle 5 module(s): CVS630 without earth leakage protection , direct in 650 mm Widecubicle 5 module(s): EZC400, direct in 650 mm Widecubicle 5 module(s): EZC630, direct in 650 mm Widecubicle 5 module(s): INS320...400, direct in 650 mm Widecubicle 5 module(s): INS500...630, direct in 650 mm Widecubicle 5 module(s): INV320...400, direct in 650 mm Widecubicle 5 module(s): INV500...630, direct in 650 mm Widecubicle 5 module(s): NSX400 without earth leakage protection , direct in 650 mm Widecubicle 5 module(s): NSX630 without earth leakage protection , direct in 650 mm Widecubicle 5 module(s): CVS400 with earth leakage protection , direct in 650 mm Widecubicle 5 module(s): CVS630 with earth leakage protection , direct in 650 mm Widecubicle 5 module(s): NSX400 with earth leakage protection , direct in 650 mm Widecubicle 5 module(s): NSX630 with earth leakage protection , direct in 650 mm Widecubicle
Standards	IEC 61439-2
Product Certifications	ASEFA

Complementary

Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Surface Finish	Matt Smooth
Colour	White (RAL 9001)
Width	650 mm
Height	250 mm
Net Weight	1.76 kg

Functional Unit	650 mm 400 mm Prisma P cubicle EasyPact CVS400 without fixed toggle horizontal 4P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle EasyPact CVS630 without fixed toggle horizontal 4P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle EasyPact EZC400 fixed toggle horizontal 4P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle EasyPact EZC630 fixed toggle horizontal 4P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact INS320...400 fixed direct front rotary handle horizontal 3P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact INS320...400 fixed direct front rotary handle horizontal 4P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact INS500...630 fixed direct front rotary handle horizontal 3P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact INS500...630 fixed direct front rotary handle horizontal 4P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact INV320...400 fixed direct front rotary handle horizontal 3P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact INV320...400 fixed direct front rotary handle horizontal 4P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact INV500...630 fixed direct front rotary handle horizontal 3P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact INV500...630 fixed direct front rotary handle horizontal 4P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX400 without fixed toggle horizontal 4P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX630 without fixed toggle horizontal 4P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle EasyPact CVS400 with fixed toggle horizontal 4P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle EasyPact CVS630 with fixed toggle horizontal 4P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX400 with fixed toggle horizontal 4P 1 direct 5 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX630 with fixed toggle horizontal 4P 1 direct 5 12.5 mm
-----------------	--

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	6.000 cm
Package 1 Width	25.000 cm
Package 1 Length	58.000 cm
Package 1 Weight	1.800 kg
Unit Type Of Package 2	BB1
Number Of Units In Package 2	5
Package 2 Height	27.500 cm
Package 2 Width	31.000 cm
Package 2 Length	61.000 cm
Package 2 Weight	9.540 kg
Unit Type Of Package 3	P12
Number Of Units In Package 3	60
Package 3 Height	77.000 cm
Package 3 Width	80.000 cm
Package 3 Length	120.000 cm
Package 3 Weight	114.480 kg

Contractual warranty

Warranty	12 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes
✓	Halogen Free Plastic Parts Product	

Certifications & Standards

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information