


Product datasheet

Specifications

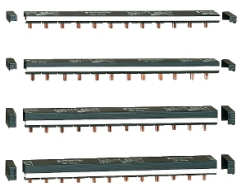

comb busbar - 4 poles - 80 A - L =
24 x 18 mm

14894

⚠ Discontinued on: 1 Nov 2020

⚠ Discontinued

Main

Product Or Component Type	Comb busbar
Accessory / Separate Part Category	Connection accessory
Poles Description	4P
Number Of Ways	12 ways N + 3 L with 18 mm pitch
Distance Between Way	72 mm
Poles Distribution	N L1 L2 L3
Connector Type	Tooth
Length In 18 Mm Modules	24

Complementary

[In] Rated Current	Double feed 100 A (40 °C) Single feed 80 A (40 °C)
[Ui] Rated Insulation Voltage	500 V conforming to IEC 664
Mounting Mode	Horizontal
9 Mm Pitches	48

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2.5 cm
Package 1 Width	2.5 cm
Package 1 Length	43 cm
Package 1 Weight	0.522 kg

Contractual warranty

Warranty	12 months
----------	-----------

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications