


# Product datasheet

Specifications

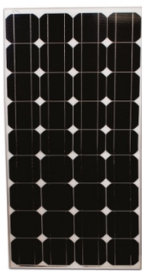

## Homaya solar panel - 12 V - 75 Wp

AEH-PV08-75W

⚠ Discontinued on: 30-Jun-2022

⚠ Discontinued

### Main

Range Of Product	Homaya
Product Or Component Type	Solar panel
Open Circuit Voltage	22.46 V

### Complementary

Short-Circuit Current	4.24 A
[Us] Rated Supply Voltage	<= 18.9 V
Maximum [In] Rated Current	3.97 A
Max Power Consumption In W	75 W
Length	505 mm
Width	30 mm
Height	1005 mm
Net Weight	8 kg

### Environment

Ambient Air Temperature For Operation	-40...85 °C
Relative Humidity	85 %

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications