


제품 데이터 시트

사양

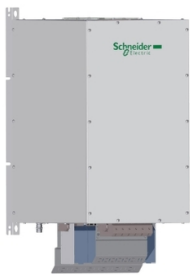

passive filter, Altivar, 369A, 460V, 60Hz, for variable speed drive

VW3A46174

❗ 판매 중단일 2020. 11. 1.

❗ 중단

기본항목

제품 또는 구성요소 타입	수동적 필터
제품 사양 응용	전류 조화의 감소

전기적/기계적 특성

범위 호환성	Altivar 61 Altivar 71
[문의] 정격 공급 전압	480 V +/- 10 %
Power Supply Frequency	60 Hz +/- 2 %
드라이브당 수량	드라이브당 필터 드라이브당 3개 variable speed drive ATV61H560 kW/800 hp 드라이브당 필터 드라이브당 3개 variable speed drive ATV61Q560 kW/800 hp 드라이브당 필터 2개 variable speed drive ATV71H250 kW/400 hp 드라이브당 필터 1개 variable speed drive ATV61H220 kW/350 hp 드라이브당 필터 1개 variable speed drive ATV71H200 kW/300 hp 드라이브당 필터 1개 variable speed drive ATV61Q200 kW/300 hp 드라이브당 필터 1개 variable speed drive ATV61Q220 kW/350 hp 드라이브당 필터 1개 variable speed drive ATV71Q200 kW/300 hp 드라이브당 필터 1개 variable speed drive ATV71Q220 kW/350 hp
[In] 정격 전류	355 A 입력 369 A 출력
상들의 네트워크 수	3 상
Thdi	5 % variable speed drive ATV61H 560 kW/800 hp 5 % variable speed drive ATV61Q 560 kW/800 hp 5 % variable speed drive ATV71H 250 kW/400 hp 5 % variable speed drive ATV61H 220 kW/350 hp 5 % variable speed drive ATV71H 200 kW/300 hp 5 % variable speed drive ATV61Q 200 kW/300 hp 5 % variable speed drive ATV61Q 220 kW/350 hp 5 % variable speed drive ATV71Q 200 kW/300 hp 5 % variable speed drive ATV71Q 220 kW/350 hp
최대 전류	1.5 x 공칭 전류 (반치폭 = 60 s)
효율성	98 %
열 손실	1406 W
Cos Phi	1 line 전류의 150 %) 0.85 line 전류의 75 %) 0.99 라인 전류의 100 %)
전기적 연결	A, B 터미널, 접속 정전용량: 2.5 mm ² X1-1...X2-3 터미널, 접속 정전용량: 25...300 mm ²
전기적 절연 클래스	클래스 F
제품 무게	229 kg

사용환경

본 데이터 시트는 Schneider Electric의 제품 및 서비스에 대한 일반적인 정보를 제공합니다. 구체적인 사양은 제품 사양서를 참조하십시오.

ip 등급	IP20 IP55 enclosure mounting)
내진동	2 mm peak to peak (f= 5...13.2 Hz) 일치되는 IEC 60068-2-6 0.7 gn (f= 13.2...150 Hz) 일치되는 IEC 60068-2-6
상대 습도	5...85 % 응축 없는
사용온도	45...60 °C °C당 전류 출력감세 3 % 있는) 5...45 °C 전류 출력감세 없는)
보관시 주변 대기 온도	-25...55 °C 원래의 포장에 스토리지 -25...65 °C during transport
사용 고도	<= 1000 m 전류 출력감세 없는 > 1000...4000 m 1000 m당 전류 출력감세 5 % 있는
표준	IEC 61000-2-4 IEC 61000-3-4 G5/4 engineering recommendation IEC 61000-3-12 IEC 61000-2-2 IEC 61000-3-2

포장 단위

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	71.000 cm
Package 1 Width	80.000 cm
Package 1 Length	120.000 cm
Package 1 Weight	253.6 kg

계약 보증

보증	18 개월
----	-------

지속 가능성

Green Premium™ 레이블은 등급 최고의 환경 성능을 갖춘 제품을 제공하기 위한 슈나이더 일렉트릭의 약속입니다. Green Premium은 순환 및 CO₂ 제품을 비롯하여 최신 규정 준수, 환경 영향에 대한 투명성 제공
제품 지속 가능성 평가를 위한 가이드는 글로벌 에코라벨 표준과 환경 선언의 해석 방법을 명확히 하는 백서입니다.

[Green Premium 자세히 알아보기 >](#)


[제품 지속 가능성 평가 가이드 >](#)

웰빙 성과

 Svhc 없는 Reach	
 유독성 중금속 없음	
 수은 없음	
 Rohs 면제 정보	예
Reach 규정	REACH 선언
Eu Rohs 지침	선제 준수(EU RoHS 법적 범위 외 제품) EU RoHS 선언
중국 Rohs 규정	중국 RoHS 선언

Dimensions Drawings

Dimensions

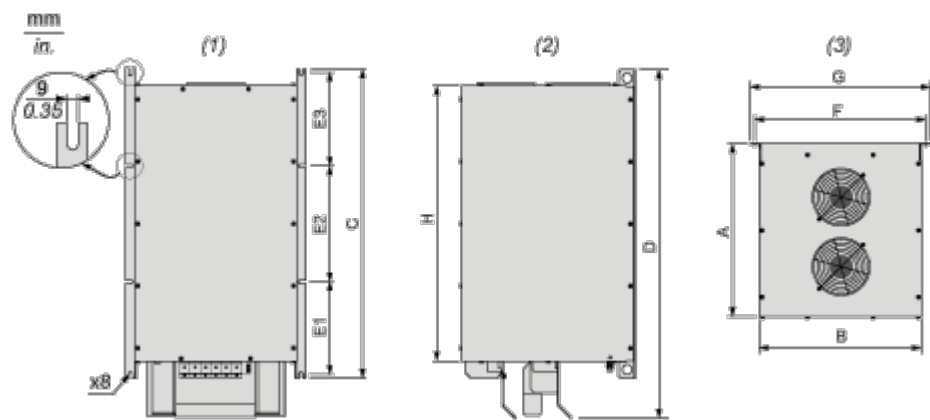

- (1) Front view
- (2) Right side view
- (3) Top view

Dimensions in mm

A	B	C	D	E1	E2	E3	F	G	H
510	420	800	900.06	240	300	240	443	468	713


Dimensions in in.

A	B	C	D	E1	E2	E3	F	G	H
20.00	16.54	31.50	35.43	9.45	11.81	9.45	17.44	18.43	28.07

Mounting and Clearance

Mounting Recommendations


Vertical Mounting Only

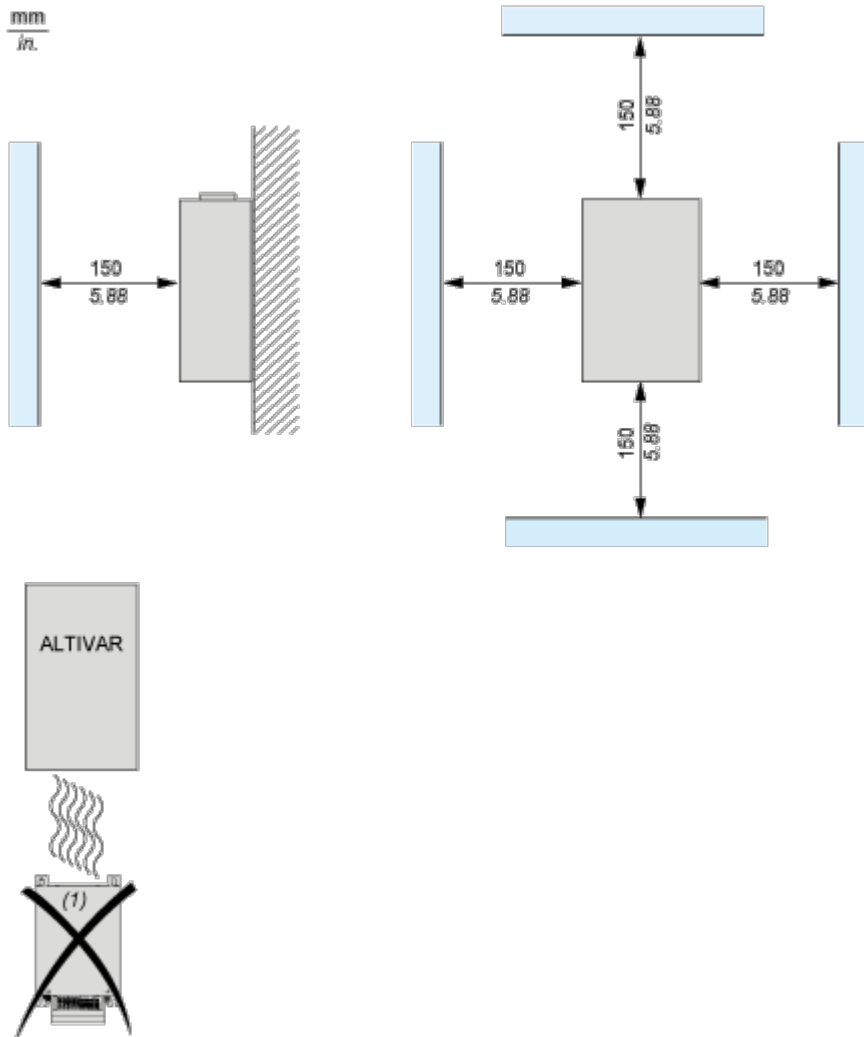

(1) Filter

Connections and Schema

Recommended Schema

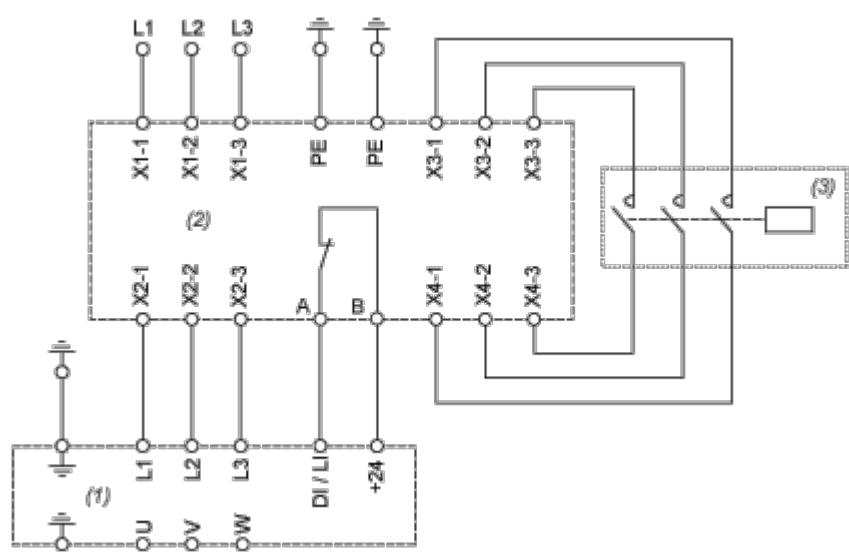

- (1) Drive
- (2) Filter
- (3) Optional