


Produkta datu lapa

Specifikācijas

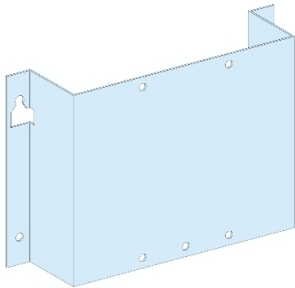

MOUNTING PLATE NSX/CVS/INS 250 V. FIXED ROT.HANDLE

03051

! Paziņojuma datums par preces pārtraukšanu 2024. gada 14. febr.

! Pārtraukts

Galvenā

Diapazons	Prisma
Produkta Sērija	Prisma G
Produkta Vai Sastāvdaļas Veids	Mounting plate
Aksesuāru / Rezerves Daļu Kategorija	Uzstādīšanas piederums
Saderība Ar	Prisma (Prisma G) duct Prisma (Prisma P) cubicle
Installation Description	Floor-standing duct 300 mm Wall-mounted duct 300 mm Cubicle 400 mm 400 mm
Installed Device	EasyPact fixed CVS100...160 without direct front rotary handle - vertikāli EasyPact fixed CVS250 without direct front rotary handle - vertikāli ComPact fixed NSX100...160 without direct front rotary handle - vertikāli ComPact fixed NSX250 without direct front rotary handle - vertikāli ComPact fixed NSX100...160 without motor mechanism - vertikāli ComPact plug-in NSX100...160 without direct front rotary handle - vertikāli ComPact plug-in NSX100...160 without motor mechanism - vertikāli ComPact fixed NSX250 without motor mechanism - vertikāli ComPact plug-in NSX250 without direct front rotary handle - vertikāli ComPact plug-in NSX250 without motor mechanism - vertikāli
Poles Description	1 x 3P fixed CVS100...160 vertikāli 1 x 4P fixed CVS100...160 vertikāli 1 x 3P fixed CVS250 vertikāli 1 x 4P fixed CVS250 vertikāli 1 x 3P fixed NSX100...160 vertikāli 1 x 4P fixed NSX100...160 vertikāli 1 x 3P plug-in NSX100...160 vertikāli 1 x 4P plug-in NSX100...160 vertikāli 1 x 3P fixed NSX250 vertikāli 1 x 4P fixed NSX250 vertikāli 1 x 3P plug-in NSX250 vertikāli 1 x 4P plug-in NSX250 vertikāli
Condition Of Using Cable Tie	Need additional plate 1 vertikāli

Ir sasniegts maksimālais salīdzināmo produktu skaits. Lūdzu, atveriet sadaļu Salīdzināt produktus #SAITE# un izdāsiēt kādu produktu, lai turpinātu.

Number Of Vertical Modules [50 Mm]	9 CVS100...160 without, direct with long terminal shield 300 mm floor-standing duct top or bottom 9 CVS100...160 without, direct with long terminal shield 300 mm wall-mounted duct top or bottom 9 CVS250 without, direct with long terminal shield 300 mm floor-standing duct top or bottom 9 CVS250 without, direct with long terminal shield 300 mm wall-mounted duct top or bottom 9 NSX100...160 without, direct with long terminal shield 300 mm floor-standing duct top or bottom 9 NSX100...160 without, direct with long terminal shield 300 mm wall-mounted duct top or bottom 9 NSX100...160 without, front connection 400 mm cubicle 9 NSX250 without, direct with long terminal shield 300 mm floor-standing duct top or bottom 9 NSX250 without, direct with long terminal shield 300 mm wall-mounted duct top or bottom 9 NSX250 without, front connection 400 mm cubicle
Standarti	IEC 61439-2
Produkta Sertifikācija	ASEFA

Papildinošs

Aizsargparklājums	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Produkta Virsmas Apdare	Matēts Smooth
Krāsa	Balts (RAL 9001)
Platums	300 mm
Augstums	300 mm
Neto Svars	0,5 kg

Functional Unit	300 mm Prisma G floor-standing duct EasyPact CVS100...160 without fixed direct front rotary handle vertikāli 3P 1 direct with long terminal shield 9 178 mm 300 mm Prisma G wall-mounted duct EasyPact CVS100...160 without fixed direct front rotary handle vertikāli 3P 1 direct with long terminal shield 9 178 mm 300 mm Prisma G floor-standing duct EasyPact CVS100...160 without fixed direct front rotary handle vertikāli 4P 1 direct with long terminal shield 9 178 mm 300 mm Prisma G wall-mounted duct EasyPact CVS100...160 without fixed direct front rotary handle vertikāli 4P 1 direct with long terminal shield 9 178 mm 300 mm Prisma G floor-standing duct EasyPact CVS250 without fixed direct front rotary handle vertikāli 3P 1 direct with long terminal shield 9 178 mm 300 mm Prisma G wall-mounted duct EasyPact CVS250 without fixed direct front rotary handle vertikāli 3P 1 direct with long terminal shield 9 178 mm 300 mm Prisma G floor-standing duct EasyPact CVS250 without fixed direct front rotary handle vertikāli 4P 1 direct with long terminal shield 9 178 mm 300 mm Prisma G wall-mounted duct EasyPact CVS250 without fixed direct front rotary handle vertikāli 4P 1 direct with long terminal shield 9 178 mm 300 mm Prisma G floor-standing duct ComPact NSX100...160 without fixed direct front rotary handle vertikāli 3P 1 direct with long terminal shield 9 178 mm 300 mm Prisma G wall-mounted duct ComPact NSX100...160 without fixed direct front rotary handle vertikāli 3P 1 direct with long terminal shield 9 178 mm 300 mm Prisma G floor-standing duct ComPact NSX100...160 without fixed direct front rotary handle vertikāli 4P 1 direct with long terminal shield 9 178 mm 300 mm Prisma G wall-mounted duct ComPact NSX100...160 without fixed direct front rotary handle vertikāli 4P 1 direct with long terminal shield 9 178 mm 400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed direct front rotary handle vertikāli 3P 1 front connection 9 178 mm 400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed direct front rotary handle vertikāli 4P 1 front connection 9 178 mm 400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed motor mechanism vertikāli 3P 1 front connection 9 178 mm 400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed motor mechanism vertikāli 4P 1 front connection 9 178 mm 400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in direct front rotary handle vertikāli 3P 1 front connection 9 178 mm 400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in direct front rotary handle vertikāli 4P 1 front connection 9 178 mm 400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in motor mechanism vertikāli 3P 1 front connection 9 178 mm 400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in motor mechanism vertikāli 4P 1 front connection 9 178 mm 300 mm Prisma G floor-standing duct ComPact NSX250 without fixed direct front rotary handle vertikāli 3P 1 direct with long terminal shield 9 178 mm 300 mm Prisma G wall-mounted duct ComPact NSX250 without fixed direct front rotary handle vertikāli 3P 1 direct with long terminal shield 9 178 mm 300 mm Prisma G floor-standing duct ComPact NSX250 without fixed direct front rotary handle vertikāli 4P 1 direct with long terminal shield 9 178 mm 300 mm Prisma G wall-mounted duct ComPact NSX250 without fixed direct front rotary handle vertikāli 4P 1 direct with long terminal shield 9 178 mm 400 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed direct front rotary handle vertikāli 3P 1 front connection 9 178 mm 400 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed direct front rotary handle vertikāli 4P 1 front connection 9 178 mm 400 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed motor mechanism vertikāli 3P 1 front connection 9 178 mm 400 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed motor mechanism vertikāli 4P 1 front connection 9 178 mm 400 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in direct front rotary handle vertikāli 3P 1 front connection 9 178 mm 400 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in direct front rotary handle vertikāli 4P 1 front connection 9 178 mm 400 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in motor mechanism vertikāli 3P 1 front connection 9 178 mm 400 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in motor mechanism vertikāli 4P 1 front connection 9 178 mm
-----------------	--

Iepakojšanas vienības

Pirmā iepakojuma Vienības Tips	PCE
Vienību Skaits 1. iepakojumā	1
1. iepakojuma Augstums	3,500 cm
1. iepakojuma Platums	14,000 cm
1. iepakojuma Garums	22,000 cm
1. iepakojuma Svars	494,000 g

Otrā Iepakojuma Vienības Tips	S04
Vienību Skaitis 2. Iepakojumā	20
2. Iepakojuma Augstums	30,000 cm
2. Iepakojuma Platums	40,000 cm
2. Iepakojuma Garums	60,000 cm
2. Iepakojuma Svars	10,583 kg
Trešā Iepakojuma Vienības Tips	P12
Vienību Skaitis 3. Iepakojumā	40
3. Iepakojuma Augstums	45,000 cm
3. Iepakojuma Platums	80,000 cm
3. Iepakojuma Garums	120,000 cm
3. Iepakojuma Svars	21,600 kg

Ilgtspējības nodaļa

Green Premium™ marķējums ir Schneider Electric apņemšanās piegādāt produktus ar savā klasē labākajiem vides rādītājiem. Green Premium apliecina atbilstību jaunākajiem noteikumiem, pārredzamību par ietekmi uz vidi, kā arī aprites un zema CO₂ produktiem.

Produktu ilgtspējības novērtēšanas rokasgrāmata ir baltā grāmata, kurā izskaidroti globālie ekomarķējuma standarti un tas, kā interpretēt vides deklarācijas.

[Rokasgrāmata produkta ilgtspējas novērtēšanai >](#)



Pārredzamība RoHS/REACH

Labklājības veikspēja

-  Nesatur Reach Svhc
-  Nesatur Toksiskus Smagos Metālus
-  Nesatur Dzīvsudrabu
-  Informācija Par Rohs Izņēmumiem [Jā](#)
-  Produkta Plastmasas Detaļas Nesatur Halogēnus

Sertifikācijas un standarti

Es Rohs Direktīva	Proaktīva atbilstība (uz izstrādājumu neattiecas ES RoHS juridiskās saistības) ES RoHS deklarācija
Ķīnas Rohs Regula	Ķīnas RoHS deklarācija Ķīnas aktīvā RoHS deklarācija (neietilpst Ķīnas RoHS juridiskajā jomā)
Vides Informācijas Publiskošana	Produkta ietekme uz vidi