


Produkta datu lapa

Specifikācijas

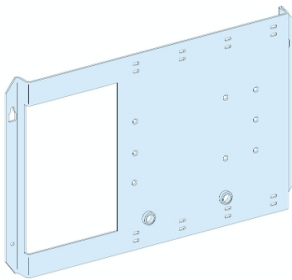

MOUNTING PLATE NSX/CVS/INS 630 HZ. FIX. TOGGLE

03070

! Paziņojuma datums par preces pārtraukšanu 2024. gada 14. febr.

! Pārtraukts

Galvenā

Diapazons	Prisma
Produkta Sērija	Prisma G
Produkta Vai Sastāvdaļas Veids	Mounting plate
Aksesuāru / Rezerves Daļu Kategorija	Uzstādīšanas piederums
Saderība Ar	Prisma (Prisma G) Sadalnes korpuss
Installation Description	Floor-standing enclosure 850 mm Floor-standing enclosure + duct 600 + 300 mm Uz sienas stiprināms sadalnes korpuss + kanāls 600 + 300 mm
Installed Device	EasyPact fixed CVS400 without toggle - horizontāli EasyPact fixed CVS630 without toggle - horizontāli EasyPact fixed EZC400 toggle - horizontāli EasyPact fixed EZC630 toggle - horizontāli ComPact fixed INS320...400 direct front rotary handle - horizontāli ComPact fixed INS500...630 direct front rotary handle - horizontāli ComPact fixed INV320...400 direct front rotary handle - horizontāli ComPact fixed INV500...630 direct front rotary handle - horizontāli ComPact fixed NSX400 without toggle - horizontāli ComPact fixed NSX630 without toggle - horizontāli
Poles Description	1 x 3P fixed CVS400 horizontāli 1 x 4P fixed CVS400 horizontāli 1 x 3P fixed CVS630 horizontāli 1 x 4P fixed CVS630 horizontāli 1 x 3P fixed EZC400 horizontāli 1 x 4P fixed EZC400 horizontāli 1 x 3P fixed EZC630 horizontāli 1 x 4P fixed EZC630 horizontāli 1 x 3P fixed INS320...400 horizontāli 1 x 4P fixed INS320...400 horizontāli 1 x 3P fixed INS500...630 horizontāli 1 x 4P fixed INS500...630 horizontāli 1 x 3P fixed INV320...400 horizontāli 1 x 4P fixed INV320...400 horizontāli 1 x 3P fixed INV500...630 horizontāli 1 x 4P fixed INV500...630 horizontāli 1 x 3P fixed NSX400 horizontāli 1 x 4P fixed NSX400 horizontāli 1 x 3P fixed NSX630 horizontāli 1 x 4P fixed NSX630 horizontāli
Condition Of Using Cable Tie	Need additional plate 2 horizontāli

Ir sasniegts maksimālais salīdzināmo produktu skaits. Lūdzu, atveriet sadaļu Salīdzināt produktus #SAITE# un izdāsiēt kādu produktu, lai turpinātu.

Number Of Vertical Modules [50 Mm]	9 CVS400 without, direct with long terminal shield 600 + 300 mm floor-standing enclosure + duct top
	9 CVS400 without, direct with long terminal shield 600 + 300 mm uz sienas stiprināms sadalnes korpuss + kanāls top
	6 CVS400 without, direct with long terminal shield 600 + 300 mm floor-standing enclosure + duct bottom
	6 CVS400 without, direct with long terminal shield 600 + 300 mm uz sienas stiprināms sadalnes korpuss + kanāls bottom
	9 CVS400 without, direct with long terminal shield 850 mm floor-standing enclosure top
	6 CVS400 without, direct with long terminal shield 850 mm floor-standing enclosure bottom
	9 CVS630 without, direct with long terminal shield 600 + 300 mm floor-standing enclosure + duct top
	9 CVS630 without, direct with long terminal shield 600 + 300 mm uz sienas stiprināms sadalnes korpuss + kanāls top
	6 CVS630 without, direct with long terminal shield 600 + 300 mm floor-standing enclosure + duct bottom
	6 CVS630 without, direct with long terminal shield 600 + 300 mm uz sienas stiprināms sadalnes korpuss + kanāls bottom
	9 CVS630 without, direct with long terminal shield 850 mm floor-standing enclosure top
	6 CVS630 without, direct with long terminal shield 850 mm floor-standing enclosure bottom
	9 EZC400, direct with long terminal shield 600 + 300 mm floor-standing enclosure + duct top
	9 EZC400, direct with long terminal shield 600 + 300 mm uz sienas stiprināms sadalnes korpuss + kanāls top
	6 EZC400, direct with long terminal shield 600 + 300 mm floor-standing enclosure + duct bottom
	6 EZC400, direct with long terminal shield 600 + 300 mm uz sienas stiprināms sadalnes korpuss + kanāls bottom
	9 EZC630, direct with long terminal shield 600 + 300 mm floor-standing enclosure + duct top
	9 EZC630, direct with long terminal shield 600 + 300 mm uz sienas stiprināms sadalnes korpuss + kanāls top
	6 EZC630, direct with long terminal shield 600 + 300 mm floor-standing enclosure + duct bottom
	6 EZC630, direct with long terminal shield 600 + 300 mm uz sienas stiprināms sadalnes korpuss + kanāls bottom
	9 INS320...400, direct with long terminal shield 600 + 300 mm floor-standing enclosure + duct top
	9 INS320...400, direct with long terminal shield 600 + 300 mm uz sienas stiprināms sadalnes korpuss + kanāls top
	6 INS320...400, direct with long terminal shield 600 + 300 mm floor-standing enclosure + duct bottom
	6 INS320...400, direct with long terminal shield 600 + 300 mm uz sienas stiprināms sadalnes korpuss + kanāls bottom
	9 INS320...400, direct with long terminal shield 850 mm floor-standing enclosure top
	6 INS320...400, direct with long terminal shield 850 mm floor-standing enclosure bottom
	9 INS500...630, direct with long terminal shield 600 + 300 mm floor-standing enclosure + duct top
	9 INS500...630, direct with long terminal shield 600 + 300 mm uz sienas stiprināms sadalnes korpuss + kanāls top
	6 INS500...630, direct with long terminal shield 600 + 300 mm floor-standing enclosure + duct bottom
	6 INS500...630, direct with long terminal shield 600 + 300 mm uz sienas stiprināms sadalnes korpuss + kanāls bottom
	9 INS500...630, direct with long terminal shield 850 mm floor-standing enclosure top
	6 INS500...630, direct with long terminal shield 850 mm floor-standing enclosure bottom
	9 INV320...400, direct with long terminal shield 600 + 300 mm floor-standing enclosure + duct top
	9 INV320...400, direct with long terminal shield 600 + 300 mm uz sienas stiprināms sadalnes korpuss + kanāls top
	6 INV320...400, direct with long terminal shield 600 + 300 mm floor-standing enclosure + duct bottom
	6 INV320...400, direct with long terminal shield 600 + 300 mm uz sienas stiprināms sadalnes korpuss + kanāls bottom
	9 INV320...400, direct with long terminal shield 850 mm floor-standing enclosure top
	6 INV320...400, direct with long terminal shield 850 mm floor-standing enclosure bottom
	9 INV500...630, direct with long terminal shield 600 + 300 mm floor-standing enclosure + duct top
	9 INV500...630, direct with long terminal shield 600 + 300 mm uz sienas stiprināms sadalnes korpuss + kanāls top
	6 INV500...630, direct with long terminal shield 600 + 300 mm floor-standing enclosure + duct bottom
	6 INV500...630, direct with long terminal shield 600 + 300 mm uz sienas stiprināms

sadalnes korpuss + kanāls bottom
9 INV500...630, direct with long terminal shield 850 mm floor-standing enclosure top
6 INV500...630, direct with long terminal shield 850 mm floor-standing enclosure
bottom
9 NSX400 without, connection block 850 mm floor-standing enclosure top
6 NSX400 without, connection block 850 mm floor-standing enclosure bottom
9 NSX400 without, connection block 600 + 300 mm floor-standing enclosure + duct
top
9 NSX400 without, connection block 600 + 300 mm uz sienas stiprināms sadalnes
korpuss + kanāls top
6 NSX400 without, connection block 600 + 300 mm floor-standing enclosure + duct
bottom
6 NSX400 without, connection block 600 + 300 mm uz sienas stiprināms sadalnes
korpuss + kanāls bottom
9 NSX400 without, direct with long terminal shield 600 + 300 mm floor-standing
enclosure + duct top
9 NSX400 without, direct with long terminal shield 600 + 300 mm uz sienas
stiprināms sadalnes korpuss + kanāls top
6 NSX400 without, direct with long terminal shield 600 + 300 mm floor-standing
enclosure + duct bottom
6 NSX400 without, direct with long terminal shield 600 + 300 mm uz sienas
stiprināms sadalnes korpuss + kanāls bottom
9 NSX400 without, direct with long terminal shield 850 mm floor-standing enclosure
top
6 NSX400 without, direct with long terminal shield 850 mm floor-standing enclosure
bottom
9 NSX630 without, connection block 850 mm floor-standing enclosure top
6 NSX630 without, connection block 850 mm floor-standing enclosure bottom
9 NSX630 without, connection block 600 + 300 mm floor-standing enclosure + duct
top
9 NSX630 without, connection block 600 + 300 mm uz sienas stiprināms sadalnes
korpuss + kanāls top
6 NSX630 without, connection block 600 + 300 mm floor-standing enclosure + duct
bottom
6 NSX630 without, connection block 600 + 300 mm uz sienas stiprināms sadalnes
korpuss + kanāls bottom
9 NSX630 without, direct with long terminal shield 600 + 300 mm floor-standing
enclosure + duct top
9 NSX630 without, direct with long terminal shield 600 + 300 mm uz sienas
stiprināms sadalnes korpuss + kanāls top
6 NSX630 without, direct with long terminal shield 600 + 300 mm floor-standing
enclosure + duct bottom
6 NSX630 without, direct with long terminal shield 600 + 300 mm uz sienas
stiprināms sadalnes korpuss + kanāls bottom
9 NSX630 without, direct with long terminal shield 850 mm floor-standing enclosure
top
6 NSX630 without, direct with long terminal shield 850 mm floor-standing enclosure
bottom

Standarti	IEC 61439-2
Produkta Sertifikācija	ASEFA

Papildinošs

Cable Entry	Izgrieztās plāksnes 0,38 mm top 217 mm Izgrieztās plāksnes 0,32 mm apakšā 67 mm
Aizsargparklājumus	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Produkta Virsmas Apdare	Smooth Matēts
Krāsa	Balts (RAL 9001)
Platums	600 mm
Augstums	250 mm
Neto Svars	2,24 kg

[illegible]

2024. gada 26.
apr.

fixed toggle horizontāli 4P 1 direct with long terminal shield 6 0,32 mm
600 + 300 mm Prisma G uz sienas stiprināms sadalnes korpuss + kanāls ComPact NSX400 without fixed toggle horizontāli 4P 1 direct with long terminal shield 6 0,32 mm
850 mm Prisma G floor-standing enclosure ComPact NSX400 without fixed toggle horizontāli 3P 1 direct with long terminal shield 9 0,38 mm
850 mm Prisma G floor-standing enclosure ComPact NSX400 without fixed toggle horizontāli 4P 1 direct with long terminal shield 9 0,38 mm
850 mm Prisma G floor-standing enclosure ComPact NSX400 without fixed toggle horizontāli 3P 1 direct with long terminal shield 6 0,32 mm
850 mm Prisma G floor-standing enclosure ComPact NSX400 without fixed toggle horizontāli 4P 1 direct with long terminal shield 6 0,32 mm
850 mm Prisma G floor-standing enclosure ComPact NSX630 without fixed toggle horizontāli 3P 1 connection block 9 0,38 mm
850 mm Prisma G floor-standing enclosure ComPact NSX630 without fixed toggle horizontāli 4P 1 connection block 9 0,38 mm
850 mm Prisma G floor-standing enclosure ComPact NSX630 without fixed toggle horizontāli 3P 1 connection block 6 0,32 mm
850 mm Prisma G floor-standing enclosure ComPact NSX630 without fixed toggle horizontāli 4P 1 connection block 6 0,32 mm
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontāli 3P 1 connection block 9 0,38 mm
600 + 300 mm Prisma G uz sienas stiprināms sadalnes korpuss + kanāls ComPact NSX630 without fixed toggle horizontāli 3P 1 connection block 9 0,38 mm
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontāli 4P 1 connection block 9 0,38 mm
600 + 300 mm Prisma G uz sienas stiprināms sadalnes korpuss + kanāls ComPact NSX630 without fixed toggle horizontāli 4P 1 connection block 9 0,38 mm
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontāli 3P 1 connection block 6 0,32 mm
600 + 300 mm Prisma G uz sienas stiprināms sadalnes korpuss + kanāls ComPact NSX630 without fixed toggle horizontāli 3P 1 connection block 6 0,32 mm
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontāli 4P 1 connection block 6 0,32 mm
600 + 300 mm Prisma G uz sienas stiprināms sadalnes korpuss + kanāls ComPact NSX630 without fixed toggle horizontāli 3P 1 direct with long terminal shield 9 0,38 mm
600 + 300 mm Prisma G uz sienas stiprināms sadalnes korpuss + kanāls ComPact NSX630 without fixed toggle horizontāli 3P 1 direct with long terminal shield 9 0,38 mm
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontāli 4P 1 direct with long terminal shield 9 0,38 mm
600 + 300 mm Prisma G uz sienas stiprināms sadalnes korpuss + kanāls ComPact NSX630 without fixed toggle horizontāli 4P 1 direct with long terminal shield 9 0,38 mm
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontāli 3P 1 direct with long terminal shield 6 0,32 mm
600 + 300 mm Prisma G uz sienas stiprināms sadalnes korpuss + kanāls ComPact NSX630 without fixed toggle horizontāli 3P 1 direct with long terminal shield 6 0,32 mm
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontāli 4P 1 direct with long terminal shield 6 0,32 mm
600 + 300 mm Prisma G uz sienas stiprināms sadalnes korpuss + kanāls ComPact NSX630 without fixed toggle horizontāli 4P 1 direct with long terminal shield 6 0,32 mm
850 mm Prisma G floor-standing enclosure ComPact NSX630 without fixed toggle horizontāli 3P 1 direct with long terminal shield 9 0,38 mm
850 mm Prisma G floor-standing enclosure ComPact NSX630 without fixed toggle horizontāli 4P 1 direct with long terminal shield 9 0,38 mm
850 mm Prisma G floor-standing enclosure ComPact NSX630 without fixed toggle horizontāli 3P 1 direct with long terminal shield 6 0,32 mm
850 mm Prisma G floor-standing enclosure ComPact NSX630 without fixed toggle horizontāli 4P 1 direct with long terminal shield 6 0,32 mm

Iepakojšanas vienības

Pirmā Iepakojuma Vienības Tips	PCE
Vienību Skaits 1. Iepakojumā	1
1. Iepakojuma Augstums	2,900 cm
1. Iepakojuma Platums	29,000 cm
1. Iepakojuma Garums	47,000 cm
1. Iepakojuma Svars	2,300 kg
Otrā Iepakojuma Vienības Tips	S04
Vienību Skaits 2. Iepakojumā	8
2. Iepakojuma Augstums	30,000 cm
2. Iepakojuma Platums	40,000 cm
2. Iepakojuma Garums	60,000 cm
2. Iepakojuma Svars	19,050 kg
Trešā Iepakojuma Vienības Tips	P12
Vienību Skaits 3. Iepakojumā	96
3. Iepakojuma Augstums	105,000 cm
3. Iepakojuma Platums	80,000 cm
3. Iepakojuma Garums	120,000 cm
3. Iepakojuma Svars	225,840 kg

Ilgtspējības nodaļa

Green Premium™ marķējums ir Schneider Electric apņemšanās piegādāt produktus ar savā klasē labākajiem vides rādītājiem. Green Premium apliecina atbilstību jaunākajiem noteikumiem, pārredzamību par ietekmi uz vidi, kā arī aprites un zema CO₂ produktiem.

Produktu ilgtspējības novērtēšanas rokasgrāmata ir baltā grāmata, kurā izskaidroti globālie ekomarķējuma standarti un tas, kā interpretēt vides deklarācijas.

[Rokasgrāmata produkta ilgtspējas novērtēšanai >](#)



Pārredzamība RoHS/REACH

Labklājības veikspēja

- ✓

Nesatur Reach Svhc
- ✓

Nesatur Toksiskus Smagos Metālus
- ✓

Nesatur Dzīvsudrabu
- ✓

Informācija Par Rohs Izņēmumiem [Jā](#)
- ✓

Produkta Plastmasas Detaļas Nesatur Halogēnus

Sertifikācijas un standarti

Es Rohs Direktīva	Proaktīva atbilstība (uz izstrādājumu neattiecas ES RoHS juridiskās saistības) ES RoHS deklarācija
Ķīnas Rohs Regula	Ķīnas RoHS deklarācija Ķīnas aktīvā RoHS deklarācija (neietilpst Ķīnas RoHS juridiskajā jomā)
Vides Informācijas Publiskošana	Produkta ietekme uz vidi