


Product datasheet

Specifications

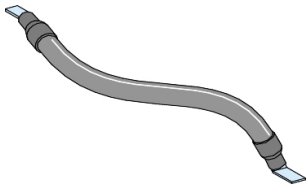

4 CONN.NG125/LINERGY DX DIST.BLOCK 125A

04047

! Discontinued on: 20 Dec 2021

! Discontinued

Main

Range	Linergy
Range Of Product	Linergy
Product Or Component Type	Flexible connection
Product Name	Linergy DX
Product Name	Prisma Prisma G enclosure Prisma Prisma P enclosure Prisma Prisma Pack 250 enclosure Linergy Linergy DX distribution block
Accessory / Separate Part Category	Current distribution accessory
Standards	IEC 61439-2 IEC 61439-1
Product Certifications	ASEFA

Complementary

Cubicle-Device Connection	Linergy DX distribution block
Installation Description	Floor-standing duct - width 300 mm Wall-mounted duct - width 300 mm Cubicle - width 650 mm Floor-standing enclosure - width 600 mm Wall-mounted enclosure - width 600 mm Cubicle - width 800 mm Pack enclosure - width 555 mm Pack enclosure - width 600 mm
Installed Device	Multi9: fixed NG125 without earth leakage protection - control: toggle Multi9: fixed NG125 with earth leakage protection - control: toggle ComPact: fixed INS40 - control: direct front rotary handle vertical installation ComPact: fixed INS63 - control: direct front rotary handle vertical installation ComPact: fixed INS100 - control: direct front rotary handle vertical installation ComPact: fixed INS125 - control: direct front rotary handle vertical installation ComPact: fixed INS160 - control: direct front rotary handle vertical installation Acti 9: fixed iC120 with earth leakage protection - control: toggle Acti 9: fixed iC120 without earth leakage protection - control: toggle Multi9: fixed NG125 NA - control: toggle ComPact: fixed NG160 NA without earth leakage protection - control: toggle Acti 9: fixed C120 with earth leakage protection - control: toggle Acti 9: fixed C120 without earth leakage protection - control: toggle ComPact: fixed NG160 with earth leakage protection - control: toggle ComPact: fixed NG160 without earth leakage protection - control: toggle ComPact: fixed NSXm without earth leakage protection - control: toggle vertical installation ComPact: fixed NSXm with earth leakage protection - control: toggle vertical installation
Condition Of Use	Additional connector needed for INS40...160 (to be ordered separately)
[Ie] Rated Operational Current	125 A

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

[In] Rated Current	125 A
Length	240 mm
Net Weight	0.52 kg
Quantity Per Set	Set of 4

[illegible]

300 mm Prisma G floor-standing duct Multi9 NG125 without fixed toggle 3P 1 direct 4
300 mm Prisma G wall-mounted duct Multi9 NG125 without fixed toggle 3P 1 direct 4
300 mm Prisma G floor-standing duct Multi9 NG125 without fixed toggle 4P 1 direct 4
300 mm Prisma G wall-mounted duct Multi9 NG125 without fixed toggle 4P 1 direct 4
600 mm Prisma G floor-standing enclosure Multi9 NG125 NA fixed toggle 3P 1 direct 5
600 mm Prisma G wall-mounted enclosure Multi9 NG125 NA fixed toggle 3P 1 direct 5
600 mm Prisma G floor-standing enclosure Multi9 NG125 NA fixed toggle 4P 1 direct 5
600 mm Prisma G wall-mounted enclosure Multi9 NG125 NA fixed toggle 4P 1 direct 5
300 mm Prisma G floor-standing duct Multi9 NG125 NA fixed toggle 3P 1 direct 4
300 mm Prisma G wall-mounted duct Multi9 NG125 NA fixed toggle 3P 1 direct 4
300 mm Prisma G floor-standing duct Multi9 NG125 NA fixed toggle 4P 1 direct 4
300 mm Prisma G wall-mounted duct Multi9 NG125 NA fixed toggle 4P 1 direct 4
600 mm Prisma G floor-standing enclosure ComPact NG160 without fixed toggle 3P 1 direct 5
600 mm Prisma G wall-mounted enclosure ComPact NG160 without fixed toggle 3P 1 direct 5
600 mm Prisma G floor-standing enclosure ComPact NG160 without fixed toggle 4P 1 direct 5
600 mm Prisma G wall-mounted enclosure ComPact NG160 without fixed toggle 4P 1 direct 5
300 mm Prisma G floor-standing duct ComPact NG160 without fixed toggle 3P 1 direct 5
300 mm Prisma G wall-mounted duct ComPact NG160 without fixed toggle 3P 1 direct 5
300 mm Prisma G floor-standing duct ComPact NG160 without fixed toggle 4P 1 direct 5
300 mm Prisma G wall-mounted duct ComPact NG160 without fixed toggle 4P 1 direct 5
600 mm Prisma G floor-standing enclosure ComPact NG160 NA without fixed toggle 3P 1 direct 5
600 mm Prisma G wall-mounted enclosure ComPact NG160 NA without fixed toggle 3P 1 direct 5
600 mm Prisma G floor-standing enclosure ComPact NG160 NA without fixed toggle 4P 1 direct 5
600 mm Prisma G wall-mounted enclosure ComPact NG160 NA without fixed toggle 4P 1 direct 5
300 mm Prisma G floor-standing duct ComPact NG160 NA without fixed toggle 3P 1 direct 5
300 mm Prisma G wall-mounted duct ComPact NG160 NA without fixed toggle 3P 1 direct 5
300 mm Prisma G floor-standing duct ComPact NG160 NA without fixed toggle 4P 1 direct 5
300 mm Prisma G wall-mounted duct ComPact NG160 NA without fixed toggle 4P 1 direct 5
650 mm Prisma P cubicle
800 mm Prisma P cubicle
600 mm Prisma G floor-standing enclosure Acti 9 C120 with fixed toggle 3P 1 direct 5
600 mm Prisma G wall-mounted enclosure Acti 9 C120 with fixed toggle 3P 1 direct 5
600 mm Prisma G floor-standing enclosure Acti 9 C120 with fixed toggle 4P 1 direct 5
600 mm Prisma G wall-mounted enclosure Acti 9 C120 with fixed toggle 4P 1 direct 5
300 mm Prisma G floor-standing duct Acti 9 C120 with fixed toggle 3P 1 direct 4
300 mm Prisma G wall-mounted duct Acti 9 C120 with fixed toggle 3P 1 direct 4
300 mm Prisma G floor-standing duct Acti 9 C120 with fixed toggle 4P 1 direct 4
300 mm Prisma G wall-mounted duct Acti 9 C120 with fixed toggle 4P 1 direct 4
600 mm Prisma G floor-standing enclosure Acti 9 iC120 with fixed toggle 3P 1 direct 5
600 mm Prisma G wall-mounted enclosure Acti 9 iC120 with fixed toggle 3P 1 direct 5
600 mm Prisma G floor-standing enclosure Acti 9 iC120 with fixed toggle 4P 1 direct 5
600 mm Prisma G wall-mounted enclosure Acti 9 iC120 with fixed toggle 4P 1 direct 5
300 mm Prisma G floor-standing duct Acti 9 iC120 with fixed toggle 3P 1 direct 4
300 mm Prisma G wall-mounted duct Acti 9 iC120 with fixed toggle 3P 1 direct 4
300 mm Prisma G floor-standing duct Acti 9 iC120 with fixed toggle 4P 1 direct 4
300 mm Prisma G wall-mounted duct Acti 9 iC120 with fixed toggle 4P 1 direct 4
600 mm Prisma G floor-standing enclosure Multi9 NG125 with fixed toggle 3P 1 direct 5
600 mm Prisma G wall-mounted enclosure Multi9 NG125 with fixed toggle 3P 1 direct 5
600 mm Prisma G floor-standing enclosure Multi9 NG125 with fixed toggle 4P 1 direct 5
600 mm Prisma G wall-mounted enclosure Multi9 NG125 with fixed toggle 4P 1 direct 5

300 mm Prisma G floor-standing duct Multi9 NG125 with fixed toggle 3P 1 direct 4
300 mm Prisma G wall-mounted duct Multi9 NG125 with fixed toggle 3P 1 direct 4
300 mm Prisma G floor-standing duct Multi9 NG125 with fixed toggle 4P 1 direct 4
300 mm Prisma G wall-mounted duct Multi9 NG125 with fixed toggle 4P 1 direct 4
600 mm Prisma G floor-standing enclosure ComPact NG160 with fixed toggle 3P 1 direct 5
600 mm Prisma G wall-mounted enclosure ComPact NG160 with fixed toggle 3P 1 direct 5
600 mm Prisma G floor-standing enclosure ComPact NG160 with fixed toggle 4P 1 direct 5
600 mm Prisma G wall-mounted enclosure ComPact NG160 with fixed toggle 4P 1 direct 5
600 mm Prisma G floor-standing enclosure ComPact NSXm without fixed toggle vertical 3P or 4P 1 connection block 7
600 mm Prisma G wall-mounted enclosure ComPact NSXm without fixed toggle vertical 3P or 4P 1 connection block 7
300 mm Prisma G floor-standing duct ComPact NSXm without fixed toggle vertical 3P or 4P 1 connection block 7
300 mm Prisma G wall-mounted duct ComPact NSXm without fixed toggle vertical 3P or 4P 1 connection block 7
600 mm Prisma G floor-standing enclosure ComPact NSXm with fixed toggle vertical 3P or 4P 1 connection block 7
600 mm Prisma G wall-mounted enclosure ComPact NSXm with fixed toggle vertical 3P or 4P 1 connection block 7
300 mm Prisma G floor-standing duct ComPact NSXm with fixed toggle vertical 3P or 4P 1 connection block 7
300 mm Prisma G wall-mounted duct ComPact NSXm with fixed toggle vertical 3P or 4P 1 connection block 7
600 mm Prisma Pack 250 Pack enclosure Acti 9 C120 without fixed toggle 3P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure Acti 9 C120 without fixed toggle 4P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure Acti 9 iC120 without fixed toggle 3P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure Acti 9 iC120 without fixed toggle 4P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure ComPact INS100 fixed direct front rotary handle vertical 3P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure ComPact INS100 fixed direct front rotary handle vertical 4P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure ComPact INS125 fixed direct front rotary handle vertical 3P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure ComPact INS125 fixed direct front rotary handle vertical 4P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure ComPact INS160 fixed direct front rotary handle vertical 3P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure ComPact INS160 fixed direct front rotary handle vertical 4P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure ComPact INS40 fixed direct front rotary handle vertical 3P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure ComPact INS40 fixed direct front rotary handle vertical 4P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure ComPact INS63 fixed direct front rotary handle vertical 3P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure ComPact INS63 fixed direct front rotary handle vertical 4P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure Multi9 NG125 without fixed toggle 3P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure Multi9 NG125 without fixed toggle 4P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure Acti 9 C120 with fixed toggle 3P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure Acti 9 C120 with fixed toggle 4P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure Acti 9 iC120 with fixed toggle 3P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure Acti 9 iC120 with fixed toggle 4P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure Multi9 NG125 with fixed toggle 3P 1 direct 6
600 mm Prisma Pack 250 Pack enclosure Multi9 NG125 with fixed toggle 4P 1 direct 6

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2.0 cm
Package 1 Width	10.5 cm
Package 1 Length	34.0 cm
Package 1 Weight	520.0 g
Unit Type Of Package 2	CAR
Number Of Units In Package 2	15
Package 2 Height	15.0 cm
Package 2 Width	30.0 cm
Package 2 Length	60.0 cm
Package 2 Weight	8.12 kg
Unit Type Of Package 3	P12
Number Of Units In Package 3	240
Package 3 Height	45.0 cm
Package 3 Width	80.0 cm
Package 3 Length	120.0 cm
Package 3 Weight	135.12 kg

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes
✓	Halogen Free Plastic Parts Product	

Certifications & Standards

Eu Rohs Directive	Compliant EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
Weee	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins