


Product datasheet

Specifications

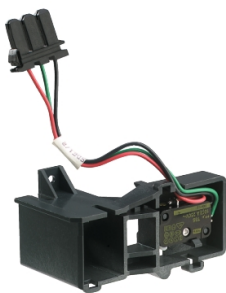

auxiliary contact - 1 SDE

47340

Price: 69,167.56 NGN

Main

Product Or Component Type	Auxiliary contact
Device Short Name	SDE
Range Compatibility	Masterpact MasterPact NT
Signal Contacts Composition	1 NO/NC

Complementary

Auxiliary Contacts Type	Standard
Mounting Mode	Fixed
[Ith] Conventional Free Air Thermal Current	5 A
Breaking Capacity (A)	AC-12: 5 A at 480 V AC 50/60 Hz AC-12: 3 A at 690 V AC 50/60 Hz AC-12: 5 A at 240/380 V AC 50/60 Hz DC-12: 0.15 A at 250 V DC DC-12: 3 A at 24/48 V DC
Minimum Load	100 mA at 24 V

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2.0 cm
Package 1 Width	18.0 cm
Package 1 Length	5.0 cm
Package 1 Weight	38.0 g

Contractual warranty

Warranty	18 months
----------	-----------

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)

Well-being performance

<div><div>✓</div><div>Reach Free Of Svhc</div></div>	
<div><div>✓</div><div>Mercury Free</div></div>	
<div><div>✓</div><div>Rohs Exemption Information</div></div>	<div>Yes</div>
<div>Reach Regulation</div>	<div>REACH Declaration</div>
<div>Eu Rohs Directive</div>	<div>Compliant with Exemptions</div>
<div>China Rohs Regulation</div>	<div><div>China RoHS declaration</div><div>Product out of China RoHS scope. Substance declaration for your information</div></div>