

Product data sheet

Specifications




Circuit breaker, EasyPact MVS, 3 Poles, 800A, 65kA, MDO, ET6, drawout, manual


MVS08H3MW6L

List Price displayed is VAT EXCLUSIVE.


Dimensions Drawings

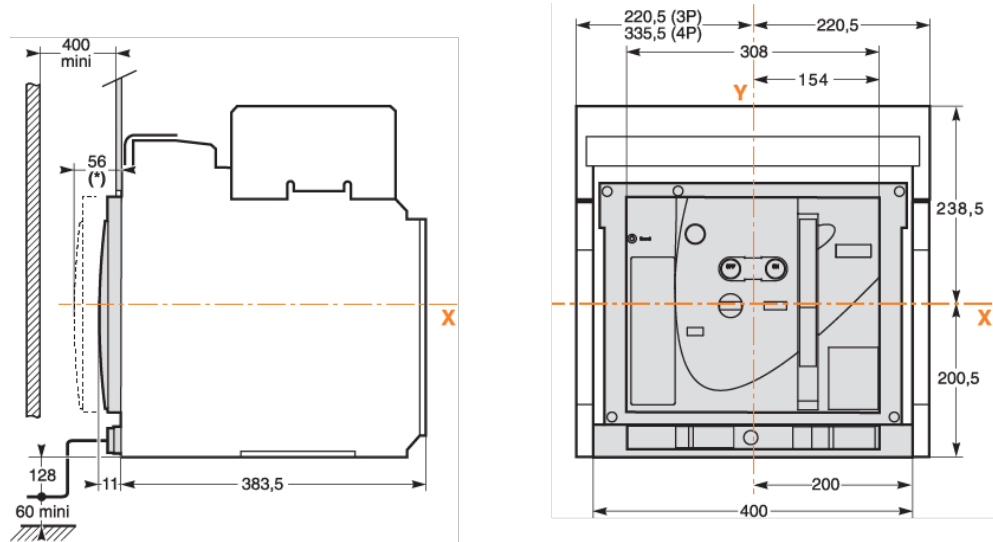

Assembly

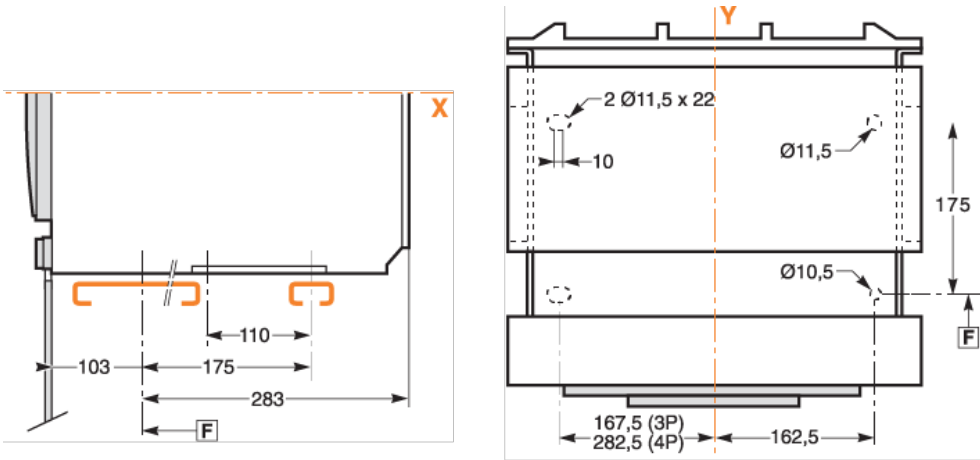


Performance Curves

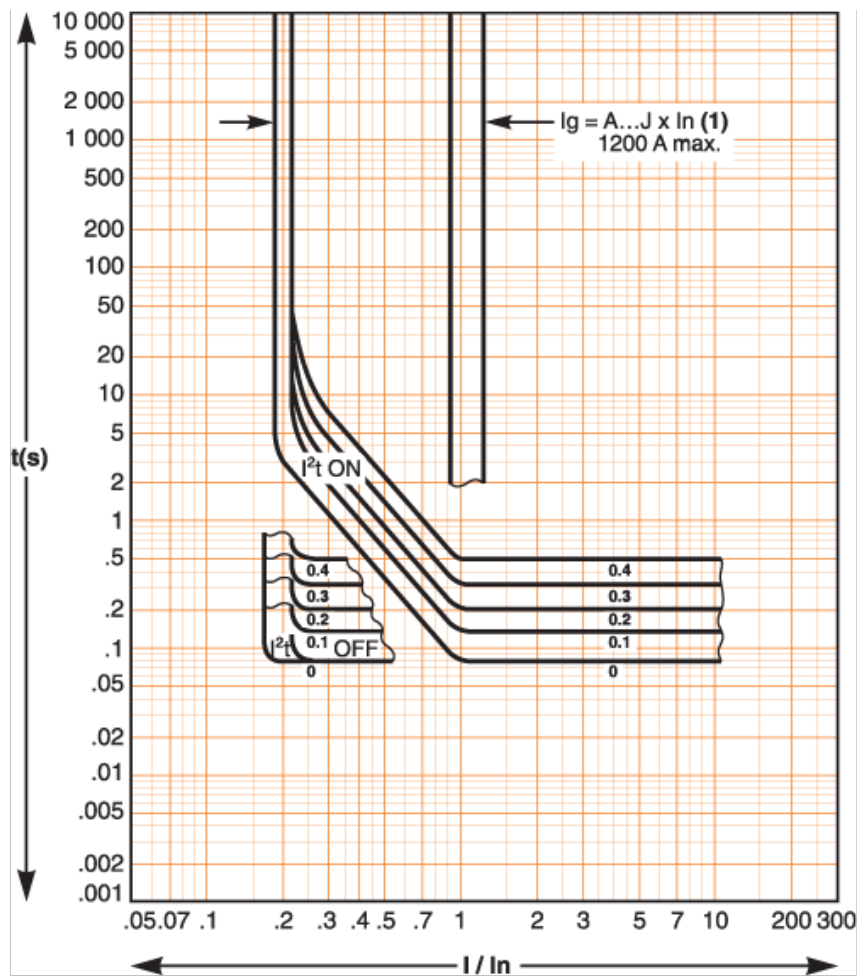

(1)

$I_g = I_n \times \dots$	A	B	C	D	E	F	G	H	J
$I_n \leq 400 \text{ A}$	0.3	0.3	0.4	0.5	0.6	0.7	0.8	0.9	1
$400 \text{ A} < I_n \leq 1000 \text{ A}$	0.2	0.3	0.4	0.5	0.6	0.7	0.8	0.9	1
$I_n \geq 1250 \text{ A}$	500	640	720	800	880	960	1040	1120	1200

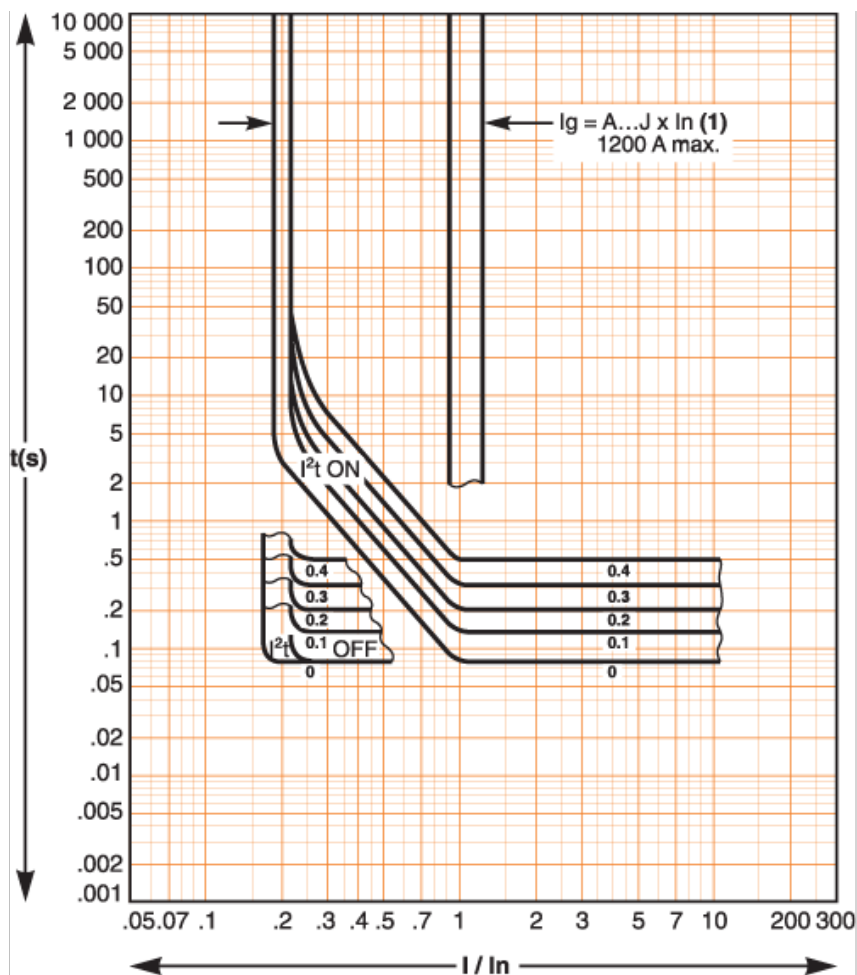

(1)

$\lg = \ln x...$	A	B	C	D	E	F	G	H	J
$\ln \leq 400 \text{ A}$	0.3	0.3	0.4	0.5	0.6	0.7	0.8	0.9	1
$400 \text{ A} < \ln \leq 1000 \text{ A}$	0.2	0.3	0.4	0.5	0.6	0.7	0.8	0.9	1
$\ln \geq 1250 \text{ A}$	500	640	720	800	880	960	1040	1120	1200