


Lista sa podacima o proizvodima

Specifikacije

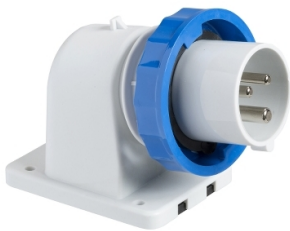

Mureva industrijski utikač - 32 A -
2P + E - 200...250 V AC - IP67

83866

Cena* bez PDV-a: 3.233,00 RSD

Osnovne informacije

Grupa Proizvoda	Mureva
Tip Proizvoda Ili Komponente	Utičnica
Kratko Ime Uređaja	Mureva plug
Kategorija Priključnice I Utikača	Niskonaponska
Broj Polova	2P + E
Tip Mreže	AC
Standard Utičnice	Industrijski

Dopunske informacije

Način Montiranja	Montaža na panel
Kategorija Priključnice I Utikača	Pod uglom od 90°
[In] Nazivna Struja	32 A
[Ue] Nazivni Napon	200...250 V
Mrežna Frekvencija	50/60 Hz
Pozicija Kontakta Uzemljenja U Smeru Kazaljke Na Satu	6 h
Materijal Utikača, Utičnice	Samogasivi konstruisan polimer
Materijal Kontakta	Pinovi: poniklovan mesing
Povezivanje - Priključci	Neodvojivi zavrtnji
Poprečni Presek Kabla	2,5...10 mm²
Masa Proizvoda	0,283 kg
Dimenzija Baze	90 x 100 mm
Visina	159 mm
Širina	90 mm
Dubina	112 mm
Boja	Siva (RAL 7035)
Boja Poklopca	Plava

Okruženje

Standardi	EN 60309-2 EN 60309-1
Ip Stepen Zaštite	IP67 u skladu sa IEC 60529

Ik Stepen Zaštite IK08 conforming to EN 62262
Sve cene koje su navedene u ovom cenovniku su informativne i neobavezujuće, bez PDV-a, isključivo u odnosu na ovlašćene distributere kompanije Schneider Electric. Svi prikazi, opisi i tehničke specifikacije i podaci u ovom cenovniku su podložni promenama od strane kompanije Schneider Electric bez prethodne najave.

Odricanje odgovornosti: Ova dokumentacija nije namenjena kao zamena i ne treba je koristiti za utvrđivanje podobnosti ili pouzdanosti ovih proizvoda za određene namene

Otpornost Na Vatru	850 °C u skladu sa IEC 60695-2-1
Relativna Vlažnost	50 % pri 40 °C 70 % pri 30 °C 90 % pri 20 °C
Nadmorska Visina Za Rad	2000 m
Temperatura Okoline Za Rad	35 °C 86400 s) -25...40 °C

Pakovanje

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	12,0 cm
Package 1 Width	17,0 cm
Package 1 Length	10,0 cm
Package 1 Weight	247,0 g
Unit Type Of Package 2	BB1
Number Of Units In Package 2	4
Package 2 Height	15,5 cm
Package 2 Width	27,0 cm
Package 2 Length	22,0 cm
Package 2 Weight	1,113 kg
Unit Type Of Package 3	S03
Number Of Units In Package 3	8
Package 3 Height	30,0 cm
Package 3 Width	30,0 cm
Package 3 Length	40,0 cm
Package 3 Weight	2,713 kg

Ugovorna garancija

Garancija	18 meseci
-----------	-----------

Održivost

Oznaka **Green Premium™** je posvećenost kompanije Schneider Electric isporuci proizvoda sa ekološkim performansama najboljim u klasi. Green Premium obećava usaglašenost sa najnovijim propisima, transparentnost u pogledu uticaja na životnu sredinu, kao i sa cirkularnim i niskonaponskim CO₂ proizvodima.

Vodič za procenu održivosti proizvoda je bela knjiga koja razjašnjava globalne standarde za oznaku ekološke prihvatljivosti i način tumačenja ekoloških izjava.

[Saznajte više o oznaci Green Premium >](#)

[Vodič za procenu održivosti proizvoda >](#)



Prozirnost



RoHS/REACH

Performanse dobrobiti



Informacije O Rohs Izuzecima

Da

Sertifikacija i standardi

Propis Reach	REACH deklaracija
Eu Rohs Direktiva	Proaktivna usaglašenost (proizvod nije u zakonskom okviru direktive EU RoHS)
Rohs Regulativa Za Kinu	RoHS deklaracija za Kinu Proizvod je izvan RoHS okvira za Kinu. Informativna deklaracija supstanci.
Izjava O Zaštiti Okoliša	Profil ekološke prihvatljivosti proizvoda
Profil Cirkularnosti	Nema potrebe za namenskim operacijama recikliranja