


# Lista sa podacima o proizvodima

Specifikacije

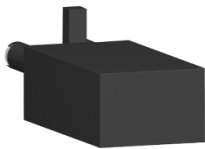

varistor - 24..60 V AC/DC - za  
RPZ/RXZ podnožja

RXM021BN

Cena\* bez PDV-a: 394,00 RSD

## Osnovne informacije

|                                  |                                                                                                                      |
|----------------------------------|----------------------------------------------------------------------------------------------------------------------|
| Grupa Proizvoda                  | Harmony Electromechanical Relays                                                                                     |
| Pribor / Posebna Kategorija      | Pribor za zaštitu                                                                                                    |
| Tip Proizvoda Ili Komponente     | Zaštitni modul                                                                                                       |
| Pribor / Posebna Namena          | Varistor                                                                                                             |
| Kompatibilnost Proizvoda         | Utičnica RPZ (1 C/O)<br>Utičnica RPZ (2 C/O)<br>Utičnica RXZ (2 C/O)<br>Utičnica RXZ (3 C/O)<br>Utičnica RXZ (4 C/O) |
| Namena Proizvoda                 | RXM relej<br>RPM relej                                                                                               |
| Napon Upravljačkog Kola          | 24...60 V AC/DC                                                                                                      |
| Prodaja Po Nedeljivim Količinama | 20                                                                                                                   |

## Pakovanje

|                              |         |
|------------------------------|---------|
| Unit Type Of Package 1       | PCE     |
| Number Of Units In Package 1 | 1       |
| Package 1 Height             | 0,9 cm  |
| Package 1 Width              | 1,2 cm  |
| Package 1 Length             | 3,0 cm  |
| Package 1 Weight             | 2,48 g  |
| Unit Type Of Package 2       | BB1     |
| Number Of Units In Package 2 | 10      |
| Package 2 Height             | 3,0 cm  |
| Package 2 Width              | 8,0 cm  |
| Package 2 Length             | 12,0 cm |
| Package 2 Weight             | 24,8 g  |
| Unit Type Of Package 3       | CAR     |
| Number Of Units In Package 3 | 500     |
| Package 3 Height             | 15,0 cm |
| Package 3 Width              | 12,7 cm |
| Package 3 Length             | 39,8 cm |
| Package 3 Weight             | 1,24 kg |

Sve cene koje su navedene u ovom cenovniku su informativne i neobavezujuće, bez PDV-a, isključivo u odnosu na ovlašćene distributere kompanije Schneider Electric. Svi prikazi, opisi i tehničke specifikacije i podaci u ovom cenovniku su podložni promenama od strane kompanije Schneider Electric bez prethodne najave.

Odricanje odgovornosti: Ova dokumentacija nije namenjena kao zamena i ne treba je koristiti za utvrđivanje podobnosti ili pouzdanosti ovih proizvoda za određene namene

# Ugovorna garancija

|           |           |
|-----------|-----------|
| Garancija | 18 months |
|-----------|-----------|

Održivost



Oznaka **Green Premium™** je posvećenost kompanije Schneider Electric isporuci proizvoda sa ekološkim performansama najboljim u klasi. Green Premium obećava usaglašenost sa najnovijim propisima, transparentnost u pogledu uticaja na životnu sredinu, kao i sa cirkularnim i niskonaponskim CO<sub>2</sub> proizvodima.

**Vodič za procenu održivosti proizvoda** je bela knjiga koja razjašnjava globalne standarde za oznaku ekološke prihvatljivosti i način tumačenja ekoloških izjava.

[Saznajte više o oznaci Green Premium >](#)

[Vodič za procenu održivosti proizvoda >](#)



Prozirnost



RoHS/REACH

Performanse dobrobiti

|   |                              |    |
|---|------------------------------|----|
| ✓ | Reach Bez Svhc               |    |
| ✓ | Bez Toksičnih Teških Metala  |    |
| ✓ | Bez Žive                     |    |
| ✓ | Informacije O Rohs Izuzecima | Da |

Sertifikacija i standardi

|                          |                                                                                                                                                                             |
|--------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Propis Reach             | <a href="#">REACH deklaracija</a>                                                                                                                                           |
| Eu Rohs Direktiva        | Proaktivna usaglašenost (proizvod nije u zakonskom okviru direktive EU RoHS)<br><a href="#">EU RoHS deklaracija</a>                                                         |
| Rohs Regulativa Za Kinu  | <a href="#">RoHS deklaracija za Kinu</a>                                                                                                                                    |
| Izjava O Zaštiti Okoliša | <a href="#">Profil ekološke prihvatljivosti proizvoda</a>                                                                                                                   |
| Weee                     | Ovaj proizvod je na tržištima Evropske unije neophodno odložiti u skladu sa specifičnim smernicama za prikupljanje otpada i nikako ne sme da dospe u kontejnere za otpatke. |
| Profil Cirkularnosti     | Nema potrebe za namenskim operacijama recikliranja                                                                                                                          |

Connections and Schema

Wiring Diagram

---

