

Lista sa podacima o proizvodima

Specifikacije



signalna lampica - LED - crvena - 120V

XB7EV04GP

Cena* bez PDV-a: 482,00 RSD

Osnovne informacije

Grupa Proizvoda	Harmony XB7
Tip Proizvoda Ili Komponente	Lampica
Kratko Ime Uređaja	XB7
Prečnik Za Montiranje	22 mm
Prodaja Po Nedeljivim Količinama	10
Oblik Glave Signalne Jedinice	Okrugla
Boja Kapica/Glave Ili Sočiva	Crvena
Svetlosni Izvor	LED
Baza Sijalice	Integrisan LED
[Us] Nazivni Napon Napajanja	120 V AC 50/60 Hz
Prezentacija Uređaja	Monolitni proizvod

Dopunske informacije

Visina	29 mm
Širina	29 mm
Dubina	54 mm
Opis Priključaka Iso N°1	(X1-X2)PL
Masa Proizvoda	0,02 kg
Montaža Uređaja	Otvor za montažu - prečnik: 22,5 mm 22.3 +0.4/0 u skladu sa IEC 60947-5-1
Centar Za Fiksiranje	>= 30 x 40 mm (nosač panela) metal 1...6 mm >= 30 x 40 mm (nosač panela) plastika 2...6 mm
Način Fiksiranja	Maticom za fiksiranje ispod glave: 2...2,4 N.m
Povezivanje - Priključci	Vijčani priključni blokovi, <= 2 x 1.5 mm² sa kablovskim završetkom u skladu sa IEC 60947-1 Vijčani priključni blokovi, 1 x 0.22...2 x 2.5 mm² bez kablovskog završetka u skladu sa IEC 60947-1
Moment Pritezanja	0,8...1,2 N.m u skladu sa IEC 60947-1
Oblik Glave Zavrtnja	Ukrštena kompatibilno sa JIS No 1 odvijač Ukrštena kompatibilno sa Philips no 1 odvijač Ukrštena kompatibilno sa pozidriv No 1 odvijač Sa prerezom kompatibilno sa matica Ø 4 mm odvijač Sa prerezom kompatibilno sa matica Ø 5.5 mm odvijač
[Ui] Nazivni Napon Izolacije	250 V (stepen zaprljanosti 3) u skladu sa IEC 60947-1
[Uimp] Nazivni Podnosivi Impulсни Napon	6 kV u skladu sa IEC 60947-1
Tip Signalizacije	Trajna

Sve cene koje su navedene u ovom cenovniku su informativne i neobavezujuće, bez PDV-a, isključivo u odnosu na ovlašćene distributere kompanije Schneider Electric. Svi prikazi, opisi i tehničke specifikacije i podaci u ovom cenovniku su podložni promenama od strane kompanije Schneider Electric bez prethodne najave.

Odricanje odgovornosti: Ova dokumentacija nije namenjena kao zamena i ne treba je koristiti za utvrđivanje podobnosti ili pouzdanosti ovih proizvoda za određene namene

Granice Napona	100...132 V AC
Struja Potrošnje	18...21 mA
Servisni Vek	70000 sati pri nazivnom naponu i 25 °C

Okruženje

Tretman Zaštite	TH
Temperatura Okoline Za Skladištenje	-40...70 °C
Temperatura Okoline Za Rad Uređaja	-25...70 °C
Kategorija Prenapona	Klasa II u skladu sa IEC 60536
Ip Stepen Zaštite	IP20 u skladu sa IEC 60529 (zadnji deo) IP65 u skladu sa IEC 60529 (prednji deo)
Nema Stepen Zaštite	NEMA 4 u skladu sa UL 50 E NEMA 12 u skladu sa UL 50 E
Standardi	IEC 60947-5-1 UL 508 IEC 60947-1 CSA C22.2 No 14 JIS C8201-5-1 JIS C8201-1
Otpornost Na Vibracije	5 gn (f= 2...500 Hz) u skladu sa IEC 60068-2-6
Otpornost Na Udare	50 gn (trajanje = 11 milisekundi) za ubrzanje polovine sinusne periode u skladu sa IEC 60068-2-27
Elektromagnetna Kompatibilnost	Emisija polja smetnji klasa B conforming to IEC 55011

Pakovanje

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2,800 cm
Package 1 Width	2,800 cm
Package 1 Length	5,500 cm
Package 1 Weight	20,000 g
Unit Type Of Package 2	BB1
Number Of Units In Package 2	10
Package 2 Height	5,000 cm
Package 2 Width	13,500 cm
Package 2 Length	17,000 cm
Package 2 Weight	200,000 g
Unit Type Of Package 3	S01
Number Of Units In Package 3	100
Package 3 Height	15,000 cm
Package 3 Width	15,000 cm
Package 3 Length	40,000 cm
Package 3 Weight	2,330 kg

Ugovorna garancija

Garancija

18 months

Održivost

Oznaka **Green Premium™** je posvećenost kompanije Schneider Electric isporuci proizvoda sa ekološkim performansama najboljim u klasi. Green Premium obećava usaglašenost sa najnovijim propisima, transparentnost u pogledu uticaja na životnu sredinu, kao i sa cirkularnim i niskonaponskim CO₂ proizvodima.

Vodič za procenu održivosti proizvoda je bela knjiga koja razjašnjava globalne standarde za oznaku ekološke prihvatljivosti i način tumačenja ekoloških izjava.

[Saznajte više o oznaci Green Premium >](#)

[Vodič za procenu održivosti proizvoda >](#)



Prozirnost



RoHS/REACH

Performanse dobrobiti


✓	Reach Bez Svhc	
✓	Bez Toksičnih Teških Metala	
✓	Bez Žive	
✓	Informacije O Rohs Izuzecima	Da

Sertifikacija i standardi

Propis Reach	REACH deklaracija
Eu Rohs Direktiva	Proaktivna usaglašenost (proizvod nije u zakonskom okviru direktive EU RoHS) EU RoHS deklaracija
Rohs Regulativa Za Kinu	RoHS deklaracija za Kinu
Izjava O Zaštiti Okoliša	Profil ekološke prihvatljivosti proizvoda
Weee	Ovaj proizvod je na tržištima Evropske unije neophodno odložiti u skladu sa specifičnim smernicama za prikupljanje otpada i nikako ne sme da dospe u kontejnere za otpatke.
Profil Cirkularnosti	Informacije o kraju radnog veka

Pilot Light with Screw Terminal

Dimensions

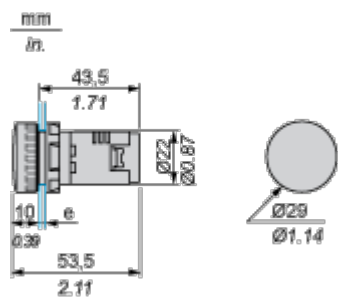


e Support panel thickness: 1 to 6 mm/0.4 to 0.24 in. (metal), 2 to 6 mm/0.8 to 0.24 in. (plastic).

Mounting and Clearance


Mounting

Diameter of Finished Fixing Holes

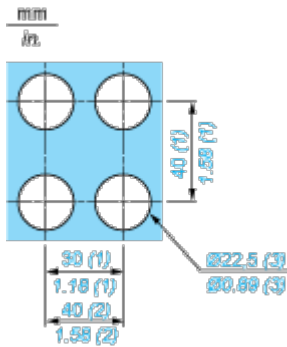


- (1) Minimum value.
- (2) 40 mm/1.58 in. for Emergency switching off pushbutton only.
- (3) Standard value: Ø 22.3 (0; + 0.4) mm/Ø 0.88 (0; + 0.02) in.

Faston Clip Connection

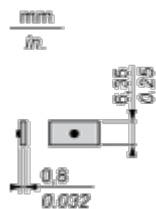


“U” Type Tag Connection

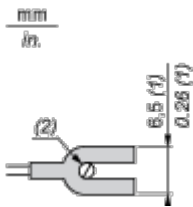

- (1) 6.5 mm/0.26 in. recommended, 7 mm/0.28 in. max.
- (2) M3 screw clamp terminal.

Connections and Schema

Wiring Diagram

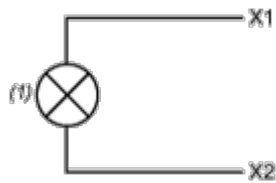

(1) LED