

Lista sa podacima o proizvodima

Specifikacije



signalna lampica Ø8 - IP40 - žuta - LED- 12V - Faston

XVLA125

Cena* bez PDV-a: 699,00 RSD

Osnovne informacije

Grupa Proizvoda	Harmony XVL
Tip Proizvoda Ili Komponente	LED lampica sa crnom osnovom
Ime Komponente	XVL
Prečnik Za Montiranje	8 mm
Svetlosni Izvor	Ispupčeni LED
Boja Bloka	Žuta
Tip Zaštite	Integrisani balast otpornik Ugrađena sa diodom
[Us] Nazivni Napon	12 V
Ip Stepen Zaštite	IP40 u skladu sa IEC 60529 IP40 u skladu sa NF C 20-010

Dopunske informacije

Tip Kola Napajanja	DC
Povezivanje - Priključci	Izvod za Faston konektore: 2.8 x 0.5 mm Izvod za lemljene konektore
Struja Potrošnje	18 mA
[Ui] Nazivni Napon Izolacije	50 V u skladu sa IEC 60947-1
Životni Vek Sijalice	100000 sati
Nazivno Ograničenje Napona	0.8...1.1 Un
Opis Priključaka Iso N°1	(X1-X2)PL
Visina	12 mm
Širina	12 mm
Dubina	34 mm
Masa Proizvoda	0,003 kg

Okruženje

Sertifikacija Proizvoda	UL CSA
Tretman Zaštite	TC
Temperatura Okoline Za Rad Uređaja	-25...70 °C
Temperatura Okoline Za Skladištenje	-40...70 °C

Kategorija Prenapona Klasa 3 u skladu sa IEC 60536
Klasa 3 u skladu sa NF C 20-030
Sve cene koje su navedene u ovom cenovniku su informativne i neobavezujuće, bez PDV-a, isključivo u odnosu na ovlašćene distributere kompanije Schneider Electric. Svi prikazi, opisi i tehničke specifikacije i podaci u ovom cenovniku su podložni promenama od strane kompanije Schneider Electric bez prethodne najave.

Odricanje odgovornosti: Ova dokumentacija nije namenjena kao zamena i ne treba je koristiti za utvrđivanje podobnosti ili pouzdanosti ovih proizvoda za određene namene

Pakovanje

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2,0 cm
Package 1 Width	5,0 cm
Package 1 Length	6,0 cm
Package 1 Weight	3,0 g
Unit Type Of Package 2	BB1
Number Of Units In Package 2	10
Package 2 Height	2,5 cm
Package 2 Width	12,0 cm
Package 2 Length	12,0 cm
Package 2 Weight	33,0 g
Unit Type Of Package 3	S01
Number Of Units In Package 3	100
Package 3 Height	15,0 cm
Package 3 Width	15,0 cm
Package 3 Length	40,0 cm
Package 3 Weight	475,0 g

Ugovorna garancija

Garancija	18 meseci
-----------	-----------

Održivost

Oznaka **Green Premium™** je posvećenost kompanije Schneider Electric isporuci proizvoda sa ekološkim performansama najboljim u klasi. Green Premium obećava usaglašenost sa najnovijim propisima, transparentnost u pogledu uticaja na životnu sredinu, kao i sa cirkularnim i niskonaponskim CO₂ proizvodima.

Vodič za procenu održivosti proizvoda je bela knjiga koja razjašnjava globalne standarde za oznaku ekološke prihvatljivosti i način tumačenja ekoloških izjava.

[Saznajte više o oznaci Green Premium >](#)

[Vodič za procenu održivosti proizvoda >](#)



Prozirnost



RoHS/REACH

Performanse dobrobiti


 Bez Žive	
 Informacije O Rohs Izuzecima	Da

Sertifikacija i standardi

Propis Reach	REACH deklaracija
Eu Rohs Direktiva	Proaktivna usaglašenost (proizvod nije u zakonskom okviru direktive EU RoHS)
Rohs Regulativa Za Kinu	RoHS deklaracija za Kinu
Izjava O Zaštiti Okoliša	Profil ekološke prihvatljivosti proizvoda
Weee	Ovaj proizvod je na tržištima Evropske unije neophodno odložiti u skladu sa specifičnim smernicama za prikupljanje otpada i nikako ne sme da dospe u kontejnere za otpatke.
Profil Cirkularnosti	Nema potrebe za namenskim operacijama recikliranja

LED Pilot Light

Dimensions

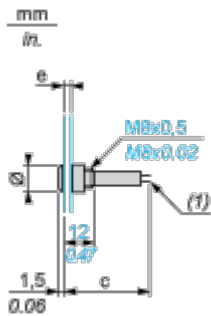

(1) Tags for Faston connectors or soldered connections


e panel thickness: 1 to 8 mm/0.03 to 0.31 in.

C		Ø	
mm	in.	mm	in.
32	1.26	12	0.47

Mounting and Clearance

LED Pilot Light

Panel Drilling

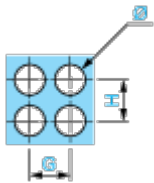

Ø min		G min		H min	
mm	in.	mm	in.	mm	in.
8.2	0.32	12.5	0.49	12.5	0.49