


Product datasheet

Specifications

Category 3 50 pair UTP Cable 305m

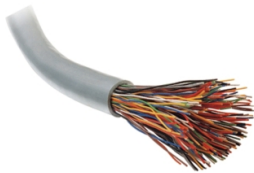

DXYCAT3UT50P

⚠ Discontinued on: Jan 23, 2021 AD

⚠ Discontinued

Main

Product Or Component Type	Copper cable
Cable Shielding Type	UTP
Communication Network Category	3
Colour Tint	Grey

Complementary

Type Of Cable	50 pairs cable
Nominal Velocity Propagation	69 %
Capacitance Unbalance	3.28 pF / 1 m
Cable Outer Diameter	15.8 mm
Cable Length	305 m
Awg Gauge	AWG 24
Thickness	Insulation: 0.2 mm Jacket: 1.2 mm
Pulling Force	40 N
Material	PVC (polyvinyl chloride): jacket

Environment

Standards	ISO/IEC 11801 ANSI/TIA-568-A
-----------	---------------------------------

Contractual warranty

Warranty	18 months
----------	-----------

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Sustainability




Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)

Well-being performance

	Toxic Heavy Metal Free	
	Mercury Free	
	Rohs Exemption Information	Yes
<hr/>		
Eu Rohs Directive		Under investigation
<hr/>		
China Rohs Regulation		China RoHS declaration
<hr/>		
Weee		The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins
<hr/>		