


# Product datasheet

Specifications

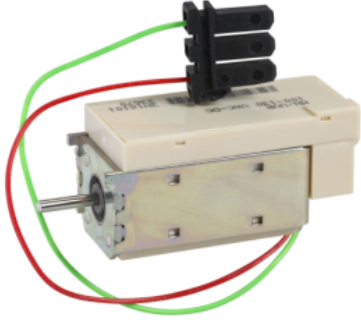

## Communicating opening voltage release MX, MasterPact NT/NW, 277VAC, spare part

33037

### Main

Range	MasterPacT
Range of product	MasterPact NT MasterPact NW
Device short name	MX com XF com
Product or component type	Voltage release
Device application	Control
Voltage release type	Opening coil Closing coil
Control type	Communicating
[Uc] control circuit voltage	277 V AC 50/60 Hz
Circuit breaker mounting mode	Fixed Drawout
Range compatibility	Masterpact (MasterPact NT) Masterpact (MasterPact NW)

### Complementary

Operating threshold	0.7...1.1 x Un opening
Response time	55 ms +/- 10 % for MasterPact NT 70 ms +/- 10 % for MasterPact NW 50 ms +/- 10 % for Compact NS630b...1600 50 ms +/- 10 % for Compact NS1600b...3200
Supply holding power	4.5 VA
Accessory / separate part category	Spare part for MasterPact NT Spare part for MasterPact NW

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	6.0 cm
Package 1 Width	3.5 cm
Package 1 Length	8.4 cm
Package 1 Weight	155.0 g
Unit Type of Package 2	BB1

Number of Units in Package 2	10
Package 2 Height	8.8 cm
Package 2 Width	13.0 cm
Package 2 Length	18.5 cm
Package 2 Weight	1.598 kg
Unit Type of Package 3	S03
Number of Units in Package 3	20
Package 3 Height	30.0 cm
Package 3 Width	30.0 cm
Package 3 Length	40.0 cm
Package 3 Weight	4.1 kg

## Offer Sustainability

REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information
RoHS exemption information	Yes

## Contractual warranty

Warranty	18 months
----------	-----------

## Recommended replacement(s)