


Product datasheet

Specifications

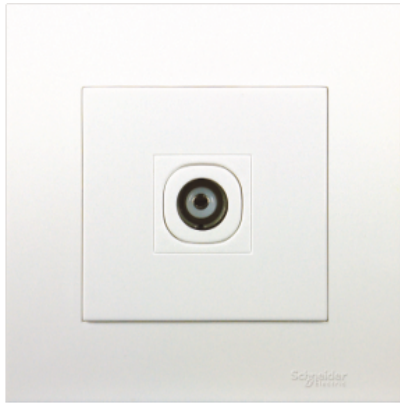

1 GANG TV CO-AXIAL OUTLET

KB31TV_WE

Main

Range	Vivace
Device short name	KB31
Product or component type	TV socket
Device application	Media device support
Device presentation	Complete mechanism

Complementary

Number of gangs	1 gang
Number of outputs	1
Colour tint	White
Material	Polycarbonate: surround Polycarbonate: grid plate Polycarbonate: base
Projecting depth	8 mm
Device mounting	Flush
Mounting support	Wall mounted
Fixing mode	By screw M3.5
Fixing center	60.3 mm
Embedding depth	35 mm
Connections - terminals	Clamp terminal
Tightening torque	0.4 N.m
Width	87 mm
Height	87 mm

Environment

Ambient air temperature for operation	-5...40 °C
Relative humidity	0...95 %
Environmental characteristic	Indoor use

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	8.6 cm
Package 1 Width	5 cm
Package 1 Length	8.6 cm
Package 1 Weight	86.9 g
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Height	15 cm
Package 2 Width	19 cm
Package 2 Length	10 cm
Package 2 Weight	939 g
Unit Type of Package 3	CAR
Number of Units in Package 3	100
Package 3 Height	21 cm
Package 3 Width	31.5 cm
Package 3 Length	50 cm
Package 3 Weight	8936 g

Offer Sustainability

REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
RoHS exemption information	Yes

Recommended replacement(s)