


Product datasheet

Specifications

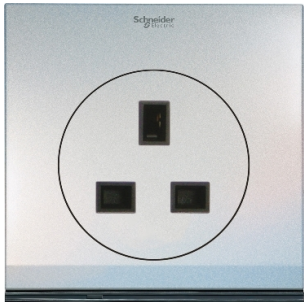

250V 1 Gang 13A BS Socket, Pearl White

US426_XPW

⚠ Discontinued on: 20 Jun 2022

⚠ Discontinued

Main

Product Or Component Type	Socket
Number Of Gangs	1 gang
Rated Current	13 A at 250 V AC 50 Hz

Complementary

Load Type	Resistive
Number Of Cables	3 cable(s) 2.5 mm ² 1 cable(s) 2.5 mm ² 2 cable(s) 2.5 mm ² 1 cable(s) 4 mm ²
Fixing Mode	By screws
Wiring Device Mounting	Flush
Distance Between Centers	60.3 mm
Width	87 mm
Height	87 mm
Depth	16.2 mm

Environment

Ambient Air Temperature For Operation	-5...40 °C
Relative Humidity	0...95 %
Environmental Characteristic	No UV resistant
Operating Altitude	<= 2000 m
Standards	BS 1363-2 SS 145 MS 589

Contractual warranty

Warranty	18 months
----------	-----------

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications