


Product datasheet

Specifications

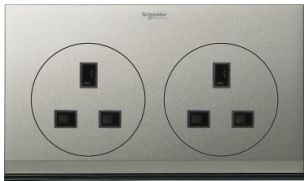

250V Twin Gang 13A BS Socket Module, Brushed Silver

UST426_XBS

⚠ Discontinued on: 20 Jun 2022

⚠ Discontinued

Main

Product Or Component Type	Socket
Number Of Gangs	2 gangs
Rated Current	13 A at 250 V AC 50 Hz

Complementary

Load Type	Resistive
Number Of Cables	3 cable(s) 2.5 mm ² 1 cable(s) 2.5 mm ² 2 cable(s) 2.5 mm ² 1 cable(s) 4 mm ² 2 cable(s) 4 mm ²
Fixing Mode	By screws
Wiring Device Mounting	Flush
Distance Between Centers	120.6 mm
Width	87 mm
Height	147 mm
Depth	16.1 mm

Environment

Ambient Air Temperature For Operation	-5...40 °C
Relative Humidity	0...95 %
Environmental Characteristic	No UV resistant
Operating Altitude	<= 2000 m
Standards	MS 589 SS 145 BS 1363-2

Contractual warranty

Warranty	18 months
----------	-----------

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications