


Product datasheet

Specifications

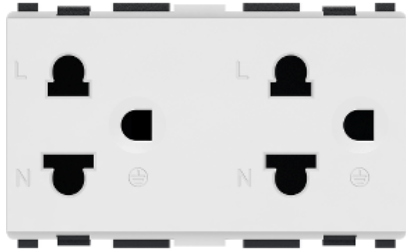

Universal socket outlet, S-Flexi, 16A 250V 3 pin duplex, white

F1426UEST2M

⚠ Discontinued on: 01 October 2021

⚠ Discontinued

Main

Range	S-Flexi
Product or component type	Socket-outlet
Device application	Power supply

Complementary

Colour tint	White
Quantity per set	1
Type of packing	Plastic bag
Material	PC (polycarbonate)
[In] rated current	16 A
[Ue] rated operational voltage	250 V AC 50...60 Hz
Network number of phases	1 phase
Outlet standard	IEC 60884-1
Number of gangs	1 gang
Socket number	2
Installation direction	Horizontal/vertical
Device mounting	Flush
Mounting support	Direct mounting on box
Height	70.3 mm
Width	46.5 mm
Depth	30.6 mm
Fixing center	83.5 mm
Connections - terminals	3 x 2.5...4 mm ² screw terminal

Environment

Standards	IEC 60884-1
Ambient air temperature for operation	-5...40 °C

Ambient air temperature for storage	-5...60 °C
-------------------------------------	------------

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3.1 cm
Package 1 Width	7 cm
Package 1 Length	4.3 cm
Package 1 Weight	59.688 g
Unit Type of Package 2	CAR
Number of Units in Package 2	320
Package 2 Height	21 cm
Package 2 Width	33 cm
Package 2 Length	62.2 cm
Package 2 Weight	20630 g
Unit Type of Package 3	PAL
Number of Units in Package 3	15360
Package 3 Height	118 cm
Package 3 Width	120 cm
Package 3 Length	100 cm
Package 3 Weight	990256.3 g

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information

Recommended replacement(s)