


Product datasheet

Specifications

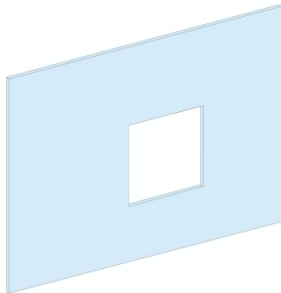

FRONT PLATE NSX630 HORIZONTAL FIXED TOGGLE W600 6M

03296

Discontinued on: 9 Aug 2023

Discontinued

EAN Code: 3303430032960

Main

Range	Prisma
Range Of Product	Prisma G
Product Or Component Type	Front plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma G enclosure
Type Of Front Plate	Cut-out
Installed Device	ComPact: fixed NSX400 without earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX630 without earth leakage protection - control: toggle - horizontal installation Enerlin'X: fixed FDM121 - control: remote control - vertical installation
Poles Description	1 x 3P: mounting plate support: NSX400 horizontal installation 1 x 4P: mounting plate support: NSX400 horizontal installation 1 x 3P: mounting plate support: NSX630 horizontal installation 1 x 4P: mounting plate support: NSX630 horizontal installation
Operating Position	Horizontal

Complementary

Enclosure/Cubicle Description	Floor-standing enclosure + duct - width 600 + 300 mm Wall-mounted enclosure + duct - width 600 + 300 mm
Connection Position	Connection block
Number Of Vertical Modules [50 Mm]	6
Standards	IEC 61439-1 IEC 61439-2
Product Certifications	ASEFA
Surface Finish	Matt Smooth
Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)
Height	300 mm
Net Weight	1.12 kg
Quantity Per Set	Set of 1

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Functional Unit	600 + 300 mm Prisma G floor-standing enclosure + duct Enerlin'X FDM121 fixed remote control vertical 1 600 + 300 mm Prisma G wall-mounted enclosure + duct Enerlin'X FDM121 fixed remote control vertical 1 600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX400 without fixed toggle horizontal 3P 1 connection block 9 600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX400 without fixed toggle horizontal 3P 1 connection block 9 600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX400 without fixed toggle horizontal 4P 1 connection block 9 600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX400 without fixed toggle horizontal 4P 1 connection block 9 600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX400 without fixed toggle horizontal 3P 1 connection block 6 600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX400 without fixed toggle horizontal 3P 1 connection block 6 600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX400 without fixed toggle horizontal 4P 1 connection block 6 600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX400 without fixed toggle horizontal 4P 1 connection block 6 600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX400 without fixed toggle horizontal 3P 1 direct with long terminal shield 9 600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX400 without fixed toggle horizontal 3P 1 direct with long terminal shield 9 600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX400 without fixed toggle horizontal 4P 1 direct with long terminal shield 9 600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX400 without fixed toggle horizontal 4P 1 direct with long terminal shield 9 600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX400 without fixed toggle horizontal 3P 1 direct with long terminal shield 6 600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX400 without fixed toggle horizontal 3P 1 direct with long terminal shield 6 600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX400 without fixed toggle horizontal 4P 1 direct with long terminal shield 6 600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX400 without fixed toggle horizontal 4P 1 direct with long terminal shield 6 600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontal 3P 1 connection block 9 600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX630 without fixed toggle horizontal 3P 1 connection block 9 600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontal 4P 1 connection block 9 600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX630 without fixed toggle horizontal 4P 1 connection block 9 600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontal 3P 1 connection block 6 600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX630 without fixed toggle horizontal 3P 1 connection block 6 600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontal 4P 1 connection block 6 600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX630 without fixed toggle horizontal 4P 1 connection block 6 600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontal 3P 1 direct with long terminal shield 9 600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX630 without fixed toggle horizontal 3P 1 direct with long terminal shield 9 600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontal 4P 1 direct with long terminal shield 9 600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX630 without fixed toggle horizontal 4P 1 direct with long terminal shield 9 600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontal 3P 1 direct with long terminal shield 6 600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX630 without fixed toggle horizontal 3P 1 direct with long terminal shield 6 600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX630 without fixed toggle horizontal 4P 1 direct with long terminal shield 6 600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX630 without fixed toggle horizontal 4P 1 direct with long terminal shield 6
-----------------	--

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	3.000 cm
Package 1 Width	31.000 cm

Package 1 Length	51.000 cm
Package 1 Weight	1.120 kg
Unit Type Of Package 2	CAR
Number Of Units In Package 2	10
Package 2 Height	17.000 cm
Package 2 Width	32.000 cm
Package 2 Length	53.000 cm
Package 2 Weight	11.500 kg
Unit Type Of Package 3	P12
Number Of Units In Package 3	180
Package 3 Height	79.000 cm
Package 3 Width	80.000 cm
Package 3 Length	120.000 cm
Package 3 Weight	207.000 kg

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes
✓	Halogen Free Plastic Parts Product	

Certifications & Standards

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile