

# Product datasheet

Specifications



## die-cast empty control station - XAPM - Ø 22 - zinc alloy - 4 openings

Local distributor code: 2201328 XAPM2204H29

! Discontinued on: 30 June 2022

! To be discontinued

### Main

|                             |   |
|-----------------------------|---|
| Range of product            | Harmony XAP   |
| Product or component type   | Die-cast empty control station  |
| Device short name           | XAPM  |
| Product destination         | For Ø 22 mm control and signalling units  |
| Product front plate size    | 80 x 130 mm   |
| Usable depth                | 49 mm   |
| Number of cut-out           | 4 cut-outs  |
| Colour of base of enclosure | Blue  |
| Colour of cover             | Blue  |
| Material                    | Zinc alloy  |
| Cable entry                 | 1 hole with blanking plug for ISO 429248 cable gland, clamping capacity: 20 mm<br>1 hole without blanking plug for ISO 429248 cable gland, clamping capacity: 20 mm |
| Device mounting             | Flush   |
| IP degree of protection     | IP65 conforming to IEC 60529<br>IP69 conforming to NF C 20-010<br>IP69K   |

### Complementary

|                         |        |
|-------------------------|--------|
| Number of vertical rows | 2      |
| Net weight              | 0.6 kg |

### Environment

|                                       |  |
|---------------------------------------|--|
| Protective treatment                  | TC   |
| Ambient air temperature for storage   | -40...70 °C  |
| Ambient air temperature for operation | -40...70 °C  |
| Overvoltage category                  | Class I conforming to IEC 60536<br>Class I conforming to NF C 20-030 |

### Packing Units

|                        |     |
|------------------------|-----|
| Unit Type of Package 1 | PCE |
|------------------------|-----|

|                              |          |
|------------------------------|----------|
| Number of Units in Package 1 | 1        |
| Package 1 Weight             | 695.9 g  |
| Package 1 Height             | 9 cm     |
| Package 1 width              | 9.5 cm   |
| Package 1 Length             | 15.5 cm  |
| Unit Type of Package 2       | S03      |
| Number of Units in Package 2 | 12       |
| Package 2 Weight             | 8.864 kg |
| Package 2 Height             | 30 cm    |
| Package 2 width              | 30 cm    |
| Package 2 Length             | 40 cm    |


## Offer Sustainability

|                            |   |
|----------------------------|---|
| Sustainable offer status   | Green Premium product   |
| REACH Regulation           | <a href="#">REACH Declaration</a>   |
| REACH free of SVHC         | Yes   |
| EU RoHS Directive          | Pro-active compliance (Product out of EU RoHS legal scope)<br><a href="#">EU RoHS Declaration</a> |
| Toxic heavy metal free     | Yes   |
| Mercury free               | Yes   |
| RoHS exemption information | <a href="#">Yes</a>   |
| China RoHS Regulation      | <a href="#">China RoHS declaration</a>  |
| Environmental Disclosure   | <a href="#">Product Environmental Profile</a>   |
| Circularity Profile        | <a href="#">End of Life Information</a>   |

## Contractual warranty

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

**Dimensions and Fixing**

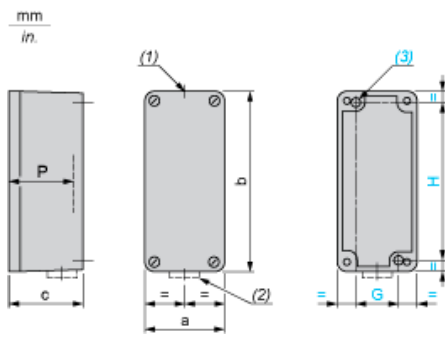


- (1) 1 hole, without blanking plug, for cable gland with 14 mm/0.55 in. maximum clamping capacity
  - (2) 1 hole, with blanking plug (protrusion 6 mm/0.23 in.), for cable gland with 14 mm/0.55 in. maximum clamping capacity
  - (3) 2 x Ø 5.6 mm/0.22 in. holes, depth 20 mm/0.78 in.
- P** Usable depth

| a  |      | b   |      | c    |      | G  |      | H   |      | P  |      |
|----|------|-----|------|------|------|----|------|-----|------|----|------|
| mm | in.  | mm  | in.  | mm   | in.  | mm | in.  | mm  | in.  | mm | in.  |
| 80 | 3.15 | 130 | 5.12 | 51.5 | 2.03 | 50 | 1.97 | 115 | 4.53 | 49 | 1.93 |

Refer to the product characteristics to get the number of cut-outs.

**Cut-out interaxis dimensions (vertical mounting)**

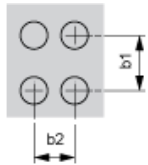

- b1** Vertical interaxis: 40 mm/1.57 in.
- b2** Horizontal interaxis: 30 mm/1.18 in.