

# Product data sheet

Specifications

**SQUARE D**



Manual Starter, integral horsepower, NEMA M0, 600 VAC, 2 pole, 2 HP at 230 VAC, single phase, no indicator, NEMA 1

2510MBG1

Product availability : Stock - Normally stocked in distribution facility

**Price\* : 277.34 USD**

## Main

Product	Manual Starter
Type	M
NEMA Size	M-0

## Complementary

Control Unit	Push-button
Pilot Light	No indicator
Horsepower Rating	1 hp 115 V AC, 1 phase 2 hp 230 V AC, 1 phase
Voltage Rating	600 V AC
Number of Poles	2P
Starter Type	Non reversing
Electrical Connection	Pressure wire clamp
Overload Relay Type	Melting alloy
Number of Thermal Units Required	1
Wire Gauge	AWG 14...AWG 8 copper
Auxiliary Contacts	Without
Height	8.63 in (219.20 mm)
Width	5 in (127.00 mm)
Depth	4.13 in (104.90 mm)

## Environment

Certifications	CSA LR60905 class 3211 05 UL listed file E42243 CCN NLRV
NEMA Enclosure Rating	NEMA 1 painted sheet steel

## Ordering and shipping details

Category	21103-2510,2511,2512 M,T
----------	--------------------------

\* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Discount Schedule	CP1
GTIN	785901792529
Returnability	Yes
Country of origin	MX

## Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	4.49 in (11.4 cm)
Package 1 Width	5.71 in (14.5 cm)
Package 1 Length	9.21 in (23.4 cm)
Package 1 Weight	4.03 lb(US) (1.83 kg)

## Offer Sustainability


California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information.
PVC free	Yes

## Contractual warranty

Warranty	18 months
----------	-----------

Approximate Dimensions

---

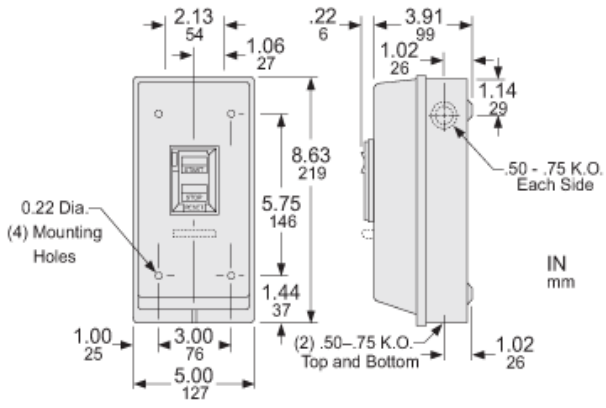

Recommended replacement(s)